


Isobar® Premium Surge Protectors



							Data Line Protection						
Model	Outlet Qty. (NEMA/IEC Type)	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Isolated Filter Banks Qty.	Tel/ Modem (RJ11)	Coaxial (Type F)	Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Isobar Audio/Video Surge Protectors—Metal Housing													
HT10DBS	10 (5-15R) ⁽⁶⁾	8 ft.	Right Angle	3840	6	2	1 line	3 line	1 line	3	\$500,000	Yes	A
ISOBAR6DBS	6 (5-15R)	6 ft.	Right Angle	2850	3	3	1 line	2 line	—	3	\$250,000	Yes	A
Isobar Surge Protectors—Metal Housing													
ISOBAR825ULTRA	8 (5-15R)	25 ft.	Right Angle	3840	4	4	—	—	—	3	\$50,000	Yes	B
ISOTEL8ULTRA	8 (5-15R)	12 ft.	Right Angle	3840	4	4	1 line	—	—	3	\$50,000	Yes	B
ISOBAR8ULTRA	8 (5-15R)	12 ft.	Right Angle	3840	4	4	—	—	—	3	\$50,000	Yes	B
IB8RM ⁽⁷⁾	8 (5-15R)	12 ft.	Right Angle	3840	4	4	—	—	—	—	\$50,000	Yes	B
ISOTEL6ULTRA	6 (5-15R)	6 ft.	Right Angle	3330	4	3	2 line	—	—	3	\$50,000	Yes	B
ISOBAR6ULTRA	6 (5-15R)	6 ft.	Right Angle	3330	4	3	—	—	—	3	\$50,000	Yes	B
ISOBAR6	6 (5-15R)	6 ft.	Right Angle	3330	4	3	—	—	—	3	\$50,000	Yes	B
ISOTEL4ULTRA	4 (5-15R)	6 ft.	Right Angle	3330	2	2	1 line	—	—	3	\$50,000	Yes	B
ISOBAR4ULTRA	4 (5-15R)	6 ft.	Right Angle	3330	2	2	—	—	—	3	\$50,000	Yes	B
IBAR4	4 (5-15R)	6 ft.	Right Angle	3330	2	2	—	—	—	—	\$50,000	Yes	B
ISOBAR2-6	2 (5-15R)	6 ft.	Right Angle	1410	1	1	—	—	—	—	\$25,000	Yes	B
Isobar Surge Protectors with 2 USB-A Charging Ports (3.1A Total)—Metal Housing													
IBAR6ULTRAUSBB	6 (5-15R)	10 ft.	Right Angle	3840	3	4	—	—	—	3	\$50,000	Yes	C
IBAR4ULTRAUSBB	4 (5-15R)	8 ft.	Right Angle	3330	2	3	—	—	—	3	\$50,000	Yes	C
Isobar Direct Plug-In Surge Protectors—Metal Housing													
ULTRABLOK	2 (5-15R)	Direct Plug-In		1410	1	1	—	—	—	3	\$10,000	Yes	D
ISOBLOK2-0	2 (5-15R)	Direct Plug-In		1410	1	1	—	—	—	3	\$10,000	Yes	D
Isobar Hospital-Grade Surge Protector—Metal Housing													
ISOBAR6ULTRAHG	6 (5-15R HG)	15 ft.	Straight 5-15P HG	3330	3	1	—	—	—	3	—	Yes	B
Isobar 230V Surge Protectors—Metal Housing													
ISOBAR4/220	4 (5-15R)	6 ft.	Right Angle	330	2	2	—	—	—	—	—	Yes	B
EURO-4	4 (C13)	6 ft.	C14 inlet ⁽⁸⁾	680	2	2	—	—	—	—	—	Yes	B

All models are certified to meet UL 1449 standards; additional certifications vary by model. All models are rated for 120V AC (50/60 Hz) operation, except ISOBAR4/220 and EURO-4, which are rated for 230V AC (50/60 Hz) operation. Plugs are NEMA 5-15P, unless otherwise indicated. All models have a circuit breaker (either separate or integrated into the on/off switch). Models have an illuminated on/off switch. ISOBAR6ULTRAHG has a switch with a snap-tight cover that reduces the risk of accidental shutoff. Most models have keyhole mounting slots. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) 3 LED models = "Line OK," "Protected" and "Fault." (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit triplite.eaton.com for exact model features. (6) HT10DBS has color-coordinated outlet/plug labels to coordinate outlets with equipment cords. (7) IB8RM has a switch on a 9 ft. cord for remote outlet control. (8) EURO-4 has a detachable C13-to-C14 cable.

FIND IT FAST! Try our interactive surge protector selector guide at triplite.eaton.com/SPselector



Isobar® Premium Surge Protectors	1
Protect It!® Surge Protectors	2-6
Safe-IT™ Antimicrobial Surge Protectors	7
Rack-Mount Surge Protectors	8

Specialty Surge Protectors (Safety, Eco, Network)	8-9
Power It!™ Power Strips	9-11
Safe-IT Antimicrobial Chargers	11
Safety Series Power Strips	11

Surge Protectors—Plastic Housing




For housing styles E-W, see pages 3-5.

						Data Line Protection & USB Charging								
Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing														
TLP128TTUSB	12	8 ft.	Right Angle	4320	7	RJ11 1 in/2 out, Coax 1 in/1 out, 2 USB-A Charging Ports (2.1A Total)			PR, GR	—	Black	\$150,000	Yes	A
TLP1208SAT	12	8 ft.	Right Angle	2880	8	—	1 in/1 out	1 in/2 out ⁽⁶⁾	PR, GR	Built-In	Black	\$250,000	Yes	B
TLP1208TELT	12	8 ft.	Right Angle	2880	8	1 in/2 out	1 in/1 out	—	PR, GR	Built-In	Black	\$150,000	Yes	B
TLP1208TEL	12	8 ft.	Right Angle	2160	8	1 in/2 out	—	—	PR, GR	Built-In	Black	\$150,000	Yes	B
TLP1010USB ⁽⁷⁾	10	10 ft.	Straight	4500	10	2 USB-A Charging Ports (2.4A Total)			PR, GR	—	Black	\$150,000	Yes	C
TLP1008TELT	10	8 ft.	Right Angle	3345	8	1 in/2 out	1 in/1 out	—	PR, GR	Built-In	Black	\$150,000	Yes	B
TLP1008TEL	10	8 ft.	Right Angle	2395	8	1 in/2 out	—	—	PR, GR	Built-In	Black	\$150,000	Yes	B
TLP1006B	10	6 ft.	Right Angle	2880	10	—	—	—	PR, GR	Built-In	Black	\$100,000	Yes	D
TLP1006USB ⁽⁷⁾	10	6 ft.	Straight	1350	10	2 USB-A Charging Ports (2.4A Total)			PR, GR	—	Black	\$100,000	Yes	C
TLP810NET	8	10 ft.	Right Angle	3240	6	1 in/1 out	1 in/1 out	1 in/1 out	PR ⁽⁹⁾ , GR	Built-In	Black	\$250,000	Yes	B
TLP808TELT	8	8 ft.	Right Angle	2160	6	1 in/2 out	1 in/1 out	—	PR ⁽⁹⁾ , GR	Built-In	Black	\$150,000	Yes	B
TLP808TEL	8	8 ft.	Right Angle	2160	6	1 in/2 out	—	—	PR, GR	Built-In	Light Gray	\$150,000	Yes	B
TLP825	8	25 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Light Gray	\$75,000	Yes	B
TLP808	8	8 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Light Gray	\$75,000	Yes	B
TLP808B	8	8 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Black	\$75,000	Yes	B

Continued on next page

Surge Protectors—Plastic Housing (continued)



						Data Line Protection & USB Charging								
 Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing (continued)														
TLP806TEL	8	6 ft.	Right Angle	2160	5	1 in/1 out	—	—	PR, GR	—	Black	\$150,000	Yes	E
TLP864USBB	8	6 ft.	Straight	1800	4	4 USB-A Charging Ports (4.2A Total)			PR	—	Black	\$50,000	Yes	F
TLP88TUSBB	8	8 ft.	Right Angle	1200	6	RJ11 1 in/2 out, 2 USB-A Charging Ports (2.1A Total)			PR	Built-In	Black	\$75,000	Yes	G
TLP88USBB	8	8 ft.	Right Angle	1200	6	2 USB-A Charging Ports (2.1A Total)			PR	Built-In	Black	\$25,000	Yes	G
SK6-6 (SUPER8)	8	8 ft.	Right Angle	1080	4	—	—	—	PR, GR, OK	8	Light Gray	\$35,000	Yes	H
SUPER7TEL15	7	15 ft.	Right Angle	2520	5	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	I
SUPER7TEL	7	7 ft.	Right Angle	2520	5	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	I
SUPER725B	7	25 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Black	\$75,000	Yes	I
SUPER7	7	7 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Light Gray	\$75,000	Yes	I
SUPER7B	7	7 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Black	\$75,000	Yes	I
TLP706TELC	7	6 ft.	Right Angle	1440	4	1 in/1 out	—	—	PR, GR	Built-In	Black	\$50,000	Yes	J
SUPER6TEL12	7	12 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR	—	Light Gray	\$50,000	Yes	I
SUPER6TEL	7	6 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR	—	Light Gray	\$50,000	Yes	I
TLP707TEL	7	7 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR, GR	Built-In	Silver	\$50,000	Yes	K
TLP76RBTTEL	7	6 ft.	Straight	1080	4	1 in/1 out	—	—	PR	—	Black	\$50,000	Yes	L
TLP74R	7	4 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	L
TLP74RB	7	4 ft.	Straight	1080	4	—	—	—	PR	—	Black	\$25,000	Yes	L
TLP725	7	25 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	M
TLP712	7	12 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	M
TLP712B	7	12 ft.	Straight	1080	4	—	—	—	PR	—	Black	\$25,000	Yes	M
STRIKER	7	6 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$20,000	Yes	M
TLP616USB⁽¹⁰⁾	7	6 ft.	Right Angle	900	2	2 USB-A Charging Ports (2.4A Total)			PR	—	White	\$5,000	Yes	N
TR-6FM	6	6 ft.	Right Angle	3040	3	1 in/1 out	—	—	PR, FA, OK	6	Light Gray	\$50,000	Yes	O
TR-6	6	6 ft.	Right Angle	2420	3	—	—	—	PR, FA, OK	4	Light Gray	\$50,000	Yes	O
TLP606UCTOWER	6	8 ft.	Right Angle	1800	3	1 USB-C (3A), 3 USB-A (3.1A Total)			PR	—	Black	\$10,000	Yes	P
TLP606RNET⁽⁸⁾	6	6 ft.	Right Angle	1440	4	1 in/1 out (Combo)	1 in/1 out	—	PR, GR	—	Black	\$150,000	Yes	Q
TLP606SSTELB	6	6 ft.	Right Angle	1440	3	1 in/1 out	—	—	PR	—	Black	\$75,000	Yes	R
TLP606DMUSB⁽¹¹⁾	6	6 ft.	Straight	2100	4	2 USB Charging Ports (2.1A Total)			PR, GR	—	Black	\$40,000	Yes	S
TLP608RUSBB⁽⁸⁾	6	8 ft.	Straight	1080	6	2 USB Charging Ports (3.4A Total)			PR, GR	—	Black	\$50,000	Yes	T

Continued on next page

Surge Protectors—Plastic Housing (continued)





For housing styles X-RR, see pages 5-6.

						Data Line Protection & USB Charging								
 	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Pack-aging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing (continued)														
TLP648USBC ⁽¹¹⁾	6	8 ft.	Straight	1080	2	1 USB-C (3A), 2 USB-A (4.8A Total)			PR	—	Light Gray	\$50,000	Yes	U
TLP66USBR	6	6 ft.	Straight	1080	4	4 USB-A Charging Ports (3.4A Total)			PR	—	Black	\$50,000	Yes	V
TLP608	6	8 ft.	Right Angle	990	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	W
TLP608TEL	6	8 ft.	Straight	990	3	1 in/1 out	—	—	PR	—	Light Gray	\$20,000	Yes	W
TLP606USB	6	6 ft.	Straight	990	3	2 USB Charging Ports (2.1A Total)			PR	—	Light Gray	\$20,000	Yes	W
TLP606USBB	6	6 ft.	Straight	990	3	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$20,000	Yes	W
TLP64USBRA15	6	15 ft.	Right Angle	900	4	4 USB-A Charging Ports (4.2A Total)			PR	—	White	\$25,000	Yes	F
TLP664USBB	6	6 ft.	Straight	900	4	4 USB-A Charging Ports (4.2A Total)			PR	—	Black	\$25,000	Yes	F
TLP615	6	15 ft.	Straight	790	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	W
TLP615B	6	15 ft.	Straight	790	3	—	—	—	PR	—	Black	\$20,000	Yes	W
TLP606	6	6 ft.	Straight	790	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	W
TLP606B	6	6 ft.	Straight	790	3	—	—	—	PR	—	Black	\$20,000	Yes	W
TLP604TEL	6	4 ft.	Straight	790	3	1 in/1 out	—	—	PR	—	Light Gray	\$20,000	Yes	W

Continued on next page

Surge Protectors—Plastic Housing (continued)

						Data Line Protection & USB Charging									
 	Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Pack-aging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing (continued)															
TLP604	6	4 ft.	Straight	790	3	—				PR	—	Light Gray	\$20,000	Yes	W
TLP6B	6	6 ft.	Straight	360	3	—				PR	—	Black	\$10,000	Yes	W
TLP602	6	2 ft.	Straight	180	3	—				—	—	Light Gray	\$2,500	Yes	W
SPIKESTIK	6	6 ft.	Straight	540	3	—				PR	6	Light Gray	\$20,000	Yes	X
TLP66USB	5	6 ft.	Right Angle	1200	5	3 USB-A Charging Ports (3.1A Total)				PR, GR	—	White	\$7,500	Yes	Y
TLP406USBUFFO	4	6 ft.	Right Angle	1800	4	4 USB-A Charging Ports (4.2A Total)				PR, GR	—	Black	\$2,500	Yes	Z
TLP48USBCUFFO	4	8 ft.	Straight	1080	4	3 USB-A (4.8A Total) and 1 USB-C (3A) Charging Ports, Built-In Micro-USB Cord				PR	—	Gray	\$100,000	Yes	AA
TLP404	4	4 ft.	Straight	450	2	—				PR	—	Light Gray	\$1,000	Yes	W
TLP36USB	3	6 ft.	Straight	540	3	4 USB-A Charging Ports (4.8A Total)				PR	—	Black	\$10,000	Yes	BB
TLP366CUBEUSBB	3 ⁽¹²⁾	6 ft.	Right Angle	540	2	6 USB-A Charging Ports (7.2A Total)				PR	—	Black	\$50,000	Yes	CC
TLP206USB	2	6 ft.	Right Angle	450	1	2 USB-A Charging Ports (2.1A Total)				PR	—	Black	\$1,000	Yes	DD
TLP104USB	1	4 ft.	Right Angle	450	1	2 USB-A Charging Ports (2.1A Total)				PR	—	Black	\$1,000	Yes	DD
Protect It! Direct Plug-In Surge Protectors—Plastic Housing															
SWIVEL6 ⁽⁸⁾	6	Direct Plug-In		1500	4	—				PR, GR	—	Black	\$20,000	Yes	EE
SWIVEL6USB ⁽⁸⁾	6	Direct Plug-In		1200	2	2 USB-A Charging Ports (3.1A Total)				PR, GR	—	Black	\$20,000	Yes	EE
TLP6SLUSBB	6	Direct Plug-In		1050	2	2 USB-A Charging Ports (3.4A Total)				PR, GR	—	Black	\$20,000	Yes	FF
SK6-0	6	Direct Plug-In		540	4	—				PR	—	Light Gray	\$10,000	Yes	GG
SK6-0B	6	Direct Plug-In		540	4	—				PR	—	Black	\$10,000	Yes	GG
SK62USBC	6	Direct Plug-In		490	4	1 USB-A and 1 USB-C Charging Ports (4A Total)				PR	—	Black	\$20,000	Yes	HH
SK5TEL-0	5	Direct Plug-In		1080	4	1 in/1 out		—	—	PR, GR	—	Light Gray	\$15,000	Yes	GG
TLP4BK	4	Direct Plug-In		720	3	—		—	—	PR, GR	—	Black	\$10,000	Yes	II
SK40RUSBB ⁽⁸⁾	4	Direct Plug-In		1080	4	2 USB-A Charging Ports (3.4A Total)				PR	—	Black	\$25,000	Yes	JJ
SK3-0	3	Direct Plug-In		660	2	—		—	—	PR, GR	—	Light Gray	\$5,000	Yes	GG
SK30USB	3	Direct Plug-In		540	2	2 USB-A Charging Ports (2.1A Total)				PR	—	Black	\$5,000	Yes	KK
Protect It! Permanent-Mount (UL 962A) Surge Protectors—Plastic Housing															
TLP310DMUSB ⁽¹³⁾	3	10 ft.	Straight	900	2	2 USB-A Charging Ports (2.4A Total)		1 in/1 out		—	—	Black	\$20,000	Yes	LL
TLP310USBC ⁽¹¹⁾	3	10 ft.	Straight	510	3	2 USB-A Charging Ports (3.1A Total)				—	—	Black	\$20,000	Yes	MM
TLP310USBCW ⁽¹¹⁾	3	10 ft.	Straight	510	3	2 USB-A Charging Ports (3.1A Total)				—	—	White	\$20,000	Yes	MM
TLP310USBS ⁽¹⁴⁾	3	10 ft.	Straight	510	3	2 USB-A Charging Ports (3.1A Total)				—	—	Black	\$20,000	Yes	NN
Protect It! Desktop USB Charging Station with Two-Outlet Surge Protector—Plastic Housing															
TLP26USBB	2	6 ft.	Right Angle	1080	1	4 USB-A Charging Ports (4.8A Total)				PR, GR	—	Black	\$50,000	Yes	OO


Continued on next page

Surge Protectors—Plastic Housing (continued)

						Data Line Protection & USB Charging								
Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Mobile Surge Protectors—Plastic Housing														
TRAVELER3USB	3	18 in.	Right Angle	1050	2	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$25,000	Yes	PP
TRAVELER	2	Direct Plug-In (Retractable)		1050	2	1 in/1 out	—	—	PR, GR	—	Black	\$50,000	Yes	QQ
TRAVELER100BT	2	Direct Plug-In (Retractable)		1050	2	—	—	1 in/1 out	PR, GR	—	Black	\$50,000	Yes	QQ
TRAVELCUBE	1	Direct Plug-In		1080	1	1 in/2 out	—	—	PR, GR	—	Light Gray	\$10,000	Yes	RR
SPIKECUBE	1	Direct Plug-In		600	1	—	—	—	PR, GR	—	Light Gray	\$5,000	Yes	RR

All models are certified to meet UL 1449 standards; additional certifications vary by model. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R, unless otherwise indicated. Plugs are NEMA 5-15P, unless otherwise indicated. Most models include a 15A circuit breaker. Most models have an illuminated on/off switch or button, except TLP1008TELT, TLP1008TEL, TLP1006B, SUPER series models (not SUPER8), TLP606SSTELB, TLP648USBC, TLP66USB, TLP48USBCUFO, TLP606UCTOWER and TLP406USBUFO have an unlighted switch or button. Bench-mount models have a switch with a snap-tight cover. Direct plug-in models, permanent-mount models, TLP36USB, TLP366CUBEUSBB, TLP206USB, TLP104USB, TLP26USBB and mobile models do not have a switch or button. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded, PW = Power, FA = Fault, OK = Line OK. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart. (7) Swivel light bars with on/off switch provide 1000 lumens each. (8) SWIVEL6 and SWIVEL6USB have 3 fixed outlets and 3 outlets (one group of 3 outlets) that rotate 90°. TLP606RNET has 2 fixed outlets and 4 outlets that rotate 90°. TLP608RUSBB has 6 outlets that rotate 90°. SK40RUSBB has 4 outlets that rotate 90°. (9) Includes an audible alarm that sounds if the "Protected" LED goes out. (10) TLP616USB has a detachable plug that is a USB charger with an AC outlet. (11) Clamps to a flat surface. (12) Third outlet is usable when the top portion (USB wall charger) is removed. (13) Fits in 2 1/2" dia. cutouts. (14) Includes mounting brackets.

Surge Protectors—Metal Housing

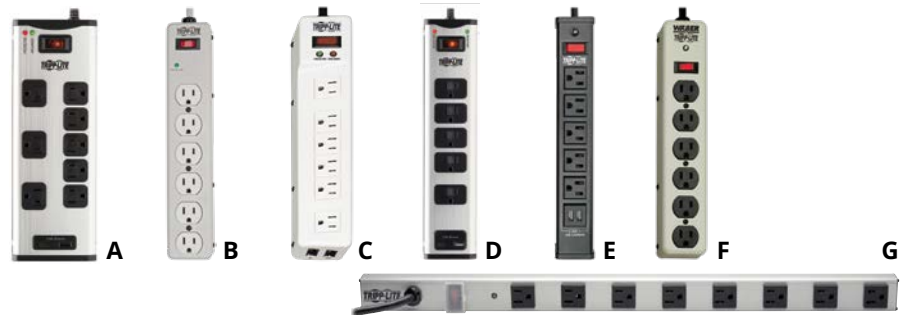

						Data Line Protection & USB Charging								
Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Surge Protectors—Metal Housing														
TLM88USBC	8	8 ft.	Straight	2100	1	1 USB-A, 1 USB-C Charging Ports (3.9A Total)			PR, GR	Built-In	Silver	\$25,000	Yes	A
TLM606HJ	6	6 ft.	Straight	1340	3	—	—	—	PR	—	Light Gray	\$75,000	Yes	B
TLM626TEL15	6	15 ft.	Straight	1340	4	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	C
TLM626	6	6 ft.	Straight	1340	4	—	—	—	PR, GR	—	Light Gray	\$75,000	Yes	C
TLM506USBC	5	6 ft.	Straight	2100	1	1 USB-A, 1 USB-C Charging Ports (3.9A Total)			PR, GR	Built-In	Silver	\$25,000	Yes	D
TLM526USBB	5	6 ft.	Straight	450	3	2 USB-A Charging Ports (3.4A Total)			—	—	Black	\$10,000	Yes	E
TLM446USBB	4	6 ft.	Straight	450	4	4 USB-A Charging Ports (4.2A Total)			—	—	Black	\$10,000	Yes	E

Industrial Surge Protectors—Metal Housing

DG206	6	6 ft.	Straight	1050	3	—	—	—	PR	—	Light Gray	—	No	F
PM6NS	6	6 ft.	Straight	900	3	—	—	—	PR	—	Light Gray	—	No	F

Commercial Surge Protector—Metal Housing

PM6SN1	6	6 ft.	Straight	900	3	—	—	—	PR	—	Light Gray	—	No	F
--------	---	-------	----------	-----	---	---	---	---	----	---	------------	---	----	---

Bench/Cabinet-Mount Surge Protectors—Metal Housing

SS7619-15	24	15 ft.	Straight	1650	24	—	—	—	PR	6	Silver	—	No	G
SS7415-15	16	15 ft.	Straight	1650	16	—	—	—	PR	6	Silver	—	No	G
SS3612	12	15 ft.	Straight	1050	12	—	—	—	PR	6	Silver	—	No	G
SS361220	12 ⁽⁶⁾	15 ft.	Straight	1650	12	—	—	—	PR	6	Silver	—	No	G
SS240806	8	6 ft.	Straight	1050	8	—	—	—	PR	6	Silver	—	No	G
SS480806	8	6 ft.	Straight	1650	8	—	—	—	PR	6	Silver	—	No	G

All models are certified to meet UL 1449 standards; additional certifications vary by model. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R, unless otherwise indicated. Plugs are NEMA 5-15P, unless otherwise indicated. Most models include a 15A circuit breaker. All models have an illuminated on/off switch. Bench-mount models have a switch with a snap-tight cover. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit triplite.eaton.com for exact model features. (6) SS361220 has a NEMA 5-20P plug, 10 NEMA 5-15R outlets and 2 NEMA 5-15/20R outlets.

Safe-IT Surge Protectors

Safe-IT™
AntiMICROBIAL
PRODUCTS





Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	USB Charging Ports	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Safe-IT Surge Protectors—Antimicrobial Plastic Housing												
TLP608DMUAM ⁽⁶⁾	6	8 ft.	Straight	2100	3	2 USB-A Charging Ports (2.4A Total)	PR, GR	—	Black	\$40,000	Yes	A
TLP648UCBAM ⁽⁶⁾	6	8 ft.	Straight	1080	2	1 USB-C (3A) and 2 USB-A (2.4 Total) Charging Ports	PR	—	Black	\$50,000	Yes	B
TLP68UBAM ⁽⁷⁾	6	8 ft.	Straight	1080	4	4 USB-A Charging Ports (3.4A Total)	PR	—	Black	\$50,000	Yes	C
TLP610BUAM	6	10 ft.	Straight	990	2	2 USB-A Charging Ports (2.4A Total)	PR	—	Black	\$25,000	Yes	D
TLP610COILAM	6	10 ft. Coiled	Right Angle	300	—	—	—	—	Black	\$10,000	Yes	E
TLP410UCUFOAM ⁽⁸⁾	4	10 ft.	Straight	1080	4	1 USB-C (3A) and 3 USB-A (4.8A Total) Charging Ports, Built-In Micro-USB Cord	PR	—	White	\$100,000	Yes	F
TLP368CUBEUAM	3 ⁽⁹⁾	8 ft.	Right Angle	540	2	6 USB-A Charging Ports (Top 4, 4.8A Total; Bottom 2, 2.4A Total)	PR	—	Black	\$50,000	Yes	G
TLP38UAM	3	8 ft.	Straight	540	3	4 USB-A Charging Ports (4.8A Total)	PR	—	Black	\$10,000	Yes	H
TLP28PD57WCAM	2	8 ft.	Right Angle	300	2	1 USB-C (3A) and 2 USB-A (4.8A Total) Charging Ports (57W Max)	—	—	White	\$25,000	Yes	I
TLP26PD30WCAM	2	6 ft.	Right Angle	300	2	1 USB-C (3A) and 2 USB-A (4.8A Total) Charging Ports (30W Max)	—	—	White	\$25,000	Yes	I
TLP12POAM ⁽¹⁰⁾	1	10 ft.	Right Angle	1000	1	2 USB-A Charging Ports (4.2A Total)	—	—	Black	\$15,000	Yes	J
Safe-IT Direct Plug-In Surge Protectors—Antimicrobial Plastic Housing												
SK5BUCAM ⁽⁸⁾	5	Direct Plug-In		1050	4	1 USB-C and 1 USB-A (3.9A Total)	PR	—	Black	\$25,000	Yes	K
SK3BUAM	3	Direct Plug-In		1050	1	2 USB-A Charging Ports (2.4A Total)	PR	—	Black	\$5,000	Yes	L
Safe-IT Surge Protectors—Metal Housing with Antimicrobial Coating												
TLM610CPAM	6	10 ft.	Straight	1000	3	1 USB-C (60W) and 4 USB-A (2x 2.4A, 2x 2.1A) Charging Ports; 3 Wireless Charging Pockets (3x 3.1A)	—	—	Black	\$50,000	No	M
TLM210CAM	2	10 ft.	Right Angle	1000	2	2 USB-C (x2 60W) and 4 USB-A (2x 2.4A, 2x 2.1A) Charging Ports	—	—	Black	\$50,000	No	N

All models are certified to meet UL 1449 standards; additional certifications vary by model. All models have antimicrobial protection that aids in resisting the growth of bacteria, viruses, fungi, mold and mildew. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R, unless otherwise indicated. Plugs are NEMA 5-15P, unless otherwise indicated. Most models include a 15A circuit breaker. TLP608DMUAM, TLP610BUAM and TLP610COILAM have an illuminated on/off switch. TLP648UCBAM, TLP68UBAM and TLP410UCUFOAM have an unlighted switch. TLP28PD57WCAM and TLP26PD30WCAM have a power button. TLP368CUBEUAM, TLP38UAM, TLP12POAM, direct plug-in models and models with a metal housing do not have a switch. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features. (6) Clamps to a flat surface. (7) Retractable USB charger clamps to a flat surface. (8) TLP410UCUFOAM has 4 rotating outlets and accommodates a smart speaker. SK5BUCAM has 1 fixed outlet and 4 outlets (two groups of 2) that rotate 90°. (9) Third outlet is usable when the top portion (USB wall charger) is removed. (10) Fits in 3" dia. cutouts.

Rack-Mount Surge Protectors




		Outlet Qty. (NEMA Type)											A
Model	Front	Rear	Cord Length	Plug Type	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Isolated Filter Banks Qty.	Diagnostic LEDs ⁽³⁾	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾	
Isobar Rack-Mount Premium Surge Protectors (1U)—Metal Housing													
ISOBAR12ULTRA	2 (5-15R)	10 (5-15R)	15 ft.	5-15P	Straight	3840	6	2	3	\$25,000	No	A	
IBAR12	2 (5-15R)	10 (5-15R)	15 ft.	5-15P	Straight	3840	6	2	3	\$25,000	No	A	
IBAR12-20ULTRA	2 (5-15R)	10 (5-20R)	15 ft.	5-20P	Straight	3840	6	1	3	\$25,000	No	A	
IBAR12-20T	2 (5-15R)	10 (5-20R)	15 ft.	L5-20P	Straight	3840	6	1	3	\$25,000	No	A	

Protect It! Rack-Mount Surge Protector (1U)—Metal Housing

DRS-1215	6 (5-15R)	8 (5-15R)	15 ft.	5-15P	Straight	3000	7	0	1	—	No	A
----------	-----------	-----------	--------	-------	----------	------	---	---	---	---	----	---

All models are certified to meet UL 1449 standards; additional certifications vary by model. All models are rated for 120V AC (50/60 Hz) operation. All models have a circuit breaker(s), illuminated on/off switch with snap-tight cover and removable mounting flanges. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) 1 LED model = "Protected." 3 LED models = "Line OK," "Protected" and "Fault." (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features.

Safety Series & Eco-Surge Surge Protectors

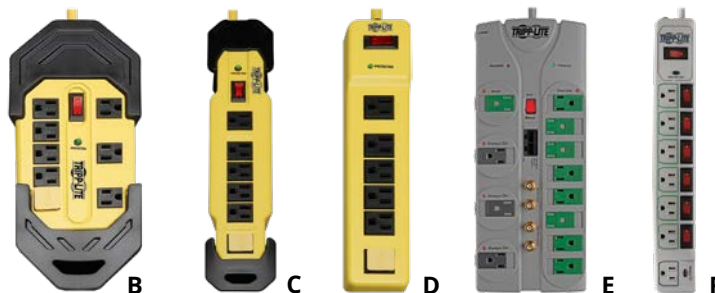


Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Diagnostic LEDs ⁽³⁾	Special Features	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Safety Series Surge Protectors—Metal Housing												
TLM825SA	8	25 ft.	Straight	3900	6	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$100,000	Yes	B
TLM812SA	8	12 ft.	Straight	1500	6	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$50,000	Yes	B
TLM615SA	6	15 ft.	Straight	2700	4	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$75,000	Yes	C
TLM609SA	6	9 ft.	Straight	1500	4	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$50,000	Yes	C
TLM626SA	6	6 ft.	Straight	900	4	PR	—	4	Yellow	\$10,000	Yes	D

ECO-Surge Energy-Saving Surge Protectors—Plastic Housing

TLP1210SATG ⁽⁶⁾	12	10 ft.	Right Angle	3600	8	PR, GR	Master Device Outlet Control	Built-In	Gray	\$250,000	Yes	E
TLP808NETG ⁽⁷⁾	8	8 ft.	Right Angle	2160	6	PR, GR	Master Device Outlet Control	Built-In	Gray	\$150,000	Yes	E
TLP76MSG	7	6 ft.	Straight	1080	4	PR	6 Individually Switched Outlets	—	Gray	\$25,000	Yes	F
TLP76MSGB	7	6 ft.	Straight	1080	4	PR	6 Individually Switched Outlets	—	Black	\$25,000	Yes	F

All models are certified to meet UL 1449 standards; additional certifications vary by model. Safety series models comply with OSHA safety color code standards. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R. Plugs are NEMA 5-15P. All models have a 15A circuit breaker and an illuminated on/off switch. Models have keyhole mounting. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features. (6) TLP1210SATG includes coaxial (Type F, 2 in/2 out) and tel/Ethernet (RJ45, 1 in/1 out) line protection. (7) TLP808NETG includes tel/Ethernet (RJ45, 1 in/1 out) line protection.

DataShield™ In-Line Surge Protectors

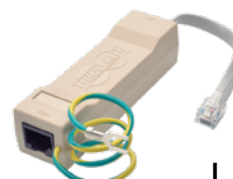

Model	Input Connection	Output Connection	Description	Clamping Voltage (RMS)	Circuit Breaker	Housing Material	Housing Color	Retail Packaging	Housing Style ⁽⁵⁾
DB9 ⁽⁸⁾	DB9 Serial	DB9 Serial	Protects DB9 serial ports	18V	340A	Plastic	Putty	No	G
DNET1	RJ45 Male	RJ45 Female	Protects network and phone lines (10/100Base-T, token ring applications)	7.5V	750A	Plastic	Putty	No	H
DSUT1CSU	RJ45 Male	RJ45 Female	Protects T1 and ISDN (RJ11/45/48) lines	60V	200A	Plastic	Putty	No	H
DTEL2	RJ11/RJ45 Male	RJ11/RJ45 Female	Protects up to 2 network or phone lines	260V	250A	Plastic	Putty	No	I

(5) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features. (8) Reversible for use with male or female captive DB9 ports.

In-Line Surge Protectors



Model	Input Connection	Output Connection	Signal Range	Description	Housing Color	Retail Packaging	Housing Style ⁽⁵⁾
In-Line Network Surge Protectors—Metal Housing							
B110-SP-CAT	RJ45 Female	RJ45 Female	300 ft.	Protects network equipment (2 needed to protect both source and device); 10 Gbps	Black	No	A
B110-SP-10G	RJ45 Female	RJ45 Female	330 ft.	Protects network equipment (2 needed to protect both source and device); 10 Gbps	Black	No	B
In-Line PoE Surge Protector—Metal Housing							
B110-SP-POE	RJ45 Female	RJ45 Female	300 ft.	Protects PoE equipment (2 needed to protect both source and device); 1 Gbps	Black	No	A
In-Line HDMI Surge Protector—Metal Housing							
B110-SP-HDMI	HDMI Female	HDMI Female	3 ft.	Protects HDMI equipment (2 needed to protect source and device); 4K	Black	No	C
Outdoor In-Line Surge Protectors—Plastic Housing							
B110-SP-CAT-OD	RJ45 Female	RJ45 Female	328 ft.	Protects edge network devices (2 needed to protect source and device); IP66 rated	Light Gray	No	D
B110-SP-CAT-OD2	RJ45 Female	RJ45 Female	328 ft.	Protects edge network devices (2 needed to protect source and device); IP68 rated	White	No	E

(5) Photos represent housing style only. Refer to the specification chart or visit triplite.eaton.com for exact model features.

Power Strips




For additional models, see next page.

Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Illuminated On/Off Switch ⁽²⁾	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Power It! Home/Office Power Strips—Plastic Housing									
PS725B	7 (5-15R)	25 ft.	5-15P (Straight)	4	15A	Yes	Black	Yes	A
PS712B	7 (5-15R)	12 ft.	5-15P (Straight)	4	15A	Yes	Black	Yes	A
PS615	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	A
PS66B	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Black	Yes	A
PS410	4 (5-15R)	10 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	A
Industrial Power Strip—Plastic Housing									
PS6	6 (5-15R)	4 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	A
Power It! Home/Office Power Strips—Metal Housing									
TLM1015NC	10 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	5	15A	Yes	Light Gray	Yes	B
TLM915NC	9 (5-15R)	15 ft.	5-15P (Straight)	5	15A	Yes	Light Gray	Yes	C
TLM615NC	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	D
TLM615NCRA	6 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	6	15A	Yes	Light Gray	Yes	D
TLM615NC20	6 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	3	20A	Yes	Light Gray	Yes	D
TLM606NC	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	D
TLM406NC	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	D
TLM306NC	3 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	D

Continued on next page

Power Strips (continued)

 Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Illuminated On/Off Switch ⁽²⁾	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Bench/Cabinet-Mount Power Strips—Metal Housing									
PS7224	24 (5-15R)	15 ft.	5-15P (Straight)	24	15A	Yes	Silver	No	F
PS7224-20	22 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	24	20A	Yes	Silver	No	F
PS7224-20HW	22 (5-15R), 2 (5-20R) ⁽⁵⁾	—	Hardwire	24	—	Switchless	Putty	No	G
PS7224-20T	22 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	L5-20P (Straight)	24	20A	Yes	Silver	No	F
PS6020	20 (5-15R)	15 ft.	5-15P (Straight)	20	15A	Yes	Silver	No	F
PS4816	16 (5-15R)	15 ft.	5-15P (Straight)	16	15A	Yes	Silver	No	F
PS4816B	16 (5-15R)	15 ft.	5-15P (Straight)	16	15A	Yes	Black	No	F
PS3612	12 (5-15R)	15 ft.	5-15P (Straight)	12	15A	Yes	Silver	No	F
PS3612B	12 (5-15R)	15 ft.	5-15P (Straight)	12	15A	Yes	Black	No	F
PS3612-20HW	10 (5-15R), 2 (5-20R) ⁽⁵⁾	—	Hardwire	12	—	Switchless	Putty	No	G
PS361206	12 (5-15R)	6 ft.	5-15P (Straight)	12	15A	Yes	Silver	No	F
PS361220	10 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	12	20A	Yes	Silver	No	F
PS3612RA	12 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	12	15A	Yes	Silver	No	F
PS2408	8 (5-15R)	15 ft.	5-15P (Straight)	8	15A	Yes	Silver	No	F
PS2408B	8 (5-15R)	15 ft.	5-15P (Straight)	8	15A	Yes	Black	No	F
PS240810	8 (5-15R)	10 ft.	5-15P (Straight)	8	15A	Yes	Silver	No	F
PS2408RA	8 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	8	15A	Yes	Silver	No	F
PS2406RA08B	6 (5-15R) ⁽⁴⁾	8 ft.	5-15P (Right Angle)	6	15A	Yes	Black	No	F
PS120406	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Silver	No	F
PS120410	4 (5-15R)	10 ft.	5-15P (Straight)	2	15A	Yes	Silver	No	F
PS120420	2 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	2	20A	Yes	Silver	No	F
PS240406	4 (5-15R)	6 ft.	5-15P (Straight)	4	15A	Yes	Silver	No	F
PS2404RA06B	4 (5-15R) ⁽⁴⁾	6 ft.	5-15P (Right Angle)	4	15A	Yes	Black	No	F
Industrial Power Strips—Metal Housing									
UL800CB-15	10 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	5	15A	Yes	Black	No	B
UL17CB-15	9 (5-15R)	15 ft.	5-15P (Right Angle)	4	15A	Yes	Dark Gray	No	C
UL24CB-15	6 (5-15R)	15 ft.	5-15P (Right Angle)	3	15A	Yes	Dark Gray	No	D
UL24RA-15	6 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	3	15A	Yes	Dark Gray	No	D
UL620-15	6 (5-15/20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	3	20A	Yes	Dark Gray	No	D
6SP	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Dark Gray	No	D
6NX6	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
6SPDX-15	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
6SPDX	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
602-15	5 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Switchless	Light Gray	No	E
602	5 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Switchless	Dark Gray	No	E
UL603CB-6	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Dark Gray	No	D
4SPDX	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D
3SP	3 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D
3SP9	3 (5-15R)	9 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D
Rack-Mount AC Charger Power Strip (1U)—Metal Housing									
PS1916D1U	16 (5-15R Dongles)	15 ft.	5-15P (Straight)	16	15A	Yes	Black	No	H

All models are certified to meet UL standards; additional certifications vary by model. All models are compatible with standard 120V operation. Most models have keyhole slots, flanges or adjustable brackets for mounting. **(1)** Transformer capacity varies with transformer size. **(2)** Most models have a snap-tight cover that reduces the risk of accidental shutoff. Visit triplite.eaton.com for exact model features. **(3)** Photos represent housing style only. Refer to the specification chart or visit triplite.eaton.com for exact model features. **(4)** Right-angle outlets. **(5)** NEMA 5-20R outlets support NEMA 5-15P and NEMA 5-20P plugs.

Continued on next page

Power Strips (continued)

For housing style H, see previous page.



Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Illuminated On/Off Switch ⁽²⁾	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Rack-Mount Power Strips (1U)—Metal Housing									
RS-1215	6 Front, 6 Rear (5-15R)	15 ft.	5-15P (Straight)	6	15A	Yes	Black	No	I
RS-1215-RA	6 Front, 6 Rear (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	12	15A	Yes	Black	No	I
RS-1215-20	6 Front, 6 Rear (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	12	20A	Yes	Black	No	I
RS-1215-20T	6 Front, 6 Rear (5-15/20R) ⁽⁵⁾	15 ft.	L5-20P (Straight)	12	20A	Yes	Black	No	I
RS-0615-F	6 Front (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Black	No	I
RS-0615-R	6 Rear (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Black	No	I

All models are certified to meet UL standards; additional certifications vary by model. All models are compatible with standard 120V operation. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) Transformer capacity varies with transformer size. (2) Most models have a snap-tight cover that reduces the risk of accidental shutoff. Visit tripplite.eaton.com for exact model features. (3) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features. (4) Right-angle outlets. (5) NEMA 5-20R outlets support NEMA 5-15P and NEMA 5-20P plugs.

Safe-IT Antimicrobial Chargers



Safe-IT™
AntiMICROBIAL
PRODUCTS

Model	Outlet Qty. (NEMA Type)	Charging Ports	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Safe-IT Power Strip with USB Charging — Antimicrobial Plastic Housing									
PS26PD32WCAM	2 (5-15R)	1 USB-C PD 3.0 (3A) and 2 USB-A (4.8A Total) Charging Ports	6 ft.	5-15P (Right Angle)	2	10A	White	Yes	J
Safe-IT Universal Travel Charger—Antimicrobial Plastic Housing									
SK2UTRAVAM	2 (5-15R)	2 USB-A Charging Ports (3.4A Total)	Direct Plug-In	5-15P ⁽⁴⁾	—	10A	Black	Yes	K
Safe-IT In-Desk Power and Charging Docks—Antimicrobial Plastic Housing									
PS22POPAM ⁽⁵⁾	2 (5-15R)	2 USB-A Charging Ports (4.5A Total)	6 ft.	5-15P (Right Angle)	—	15A	Black	Yes	L
PS222DATAM ⁽⁶⁾	2 (5-15R)	2 USB-A Charging Ports (4.5A Total)	10 ft.	5-15P (Right Angle)	2	15A	Black	Yes	M

All models are certified to meet UL standards; additional certifications vary by model. All models are compatible with standard 120V operation. Models do not have an on/off switch. (1) Transformer capacity varies with transformer size. (3) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features. (4) Includes 5 plug adapters (North America, Japan, U.K., Europe, China). (5) Fits in 3" dia. cutouts. (6) PS222DATAM includes 2 USB-A data ports, a USB-B port and HDMI, phone and Ethernet couplers. It requires a 7.95" x 4.06" opening.

Safety Series Power Strips



Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Outlet Safety Covers	Illuminated On/Off Switch	Cord Clip and Cord Wrap with Hanger	Housing Style ⁽³⁾
Power It! Safety Series Power Strips with GFCI Plug—Include retail packaging									
TLM825GF	8 (5-15R)	25 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	N
TLM812GF	8 (5-15R)	12 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	N
TLM609GF	6 (5-15R)	9 ft.	5-15P (Straight)	4	15A	4	Yes	Yes	O
Power It! Safety Series Power Strips—Include retail packaging									
TLM815NS	8 (5-15R)	15 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	N
TLM626NS	6 (5-15R)	6 ft.	5-15P (Straight)	4	15A	4	Yes	No	P

Housings are yellow. All models are certified to meet UL standards and comply with OSHA safety color code standards. All models are compatible with standard 120V operation. Outlets have right-angle design. All models have a metal housing and keyhole mounting slots. (1) Transformer capacity varies with transformer size. (3) Photos represent housing style only. Refer to the specification chart or visit tripplite.eaton.com for exact model features.

FIND IT FAST! Try our interactive surge protector selector guide at tripplite.eaton.com/PSselector

