



TAA-compliant fiber optic network cables

Eaton's Tripp Lite series family of fiber optic cables includes models that comply with the federal Trade Agreements Act (TAA). These TAA-compliant fiber cables are eligible for General Services Administration (GSA) Schedule contracts, making them an option for government and military agencies and contractors.

As the amount of traffic in data networks grows, so does the need for devices and fiber cables to support higher bandwidths. Compared to copper cables, fiber cables support faster transmission speeds over longer distances for high-bandwidth applications in medium or large enterprises, financial institutions and hyperscale or colocation data centers.

Key features

Fast transmission speeds

With options for networks as fast as 400 Gbps, the TAA-compliant cables support high-density patching between data center main distribution frames (MDFs) and intermediate distribution frames (IDFs). The cables are backward compatible with slower networks, so they can help future-proof existing installations for an eventual upgrade.

Pre-terminated for convenience

Cables are pre-terminated, eliminating the need for specialty splicing tools and guesswork from installers. MPO connectors are pre-keyed for Type A or Type B polarity and have a slim boot to enable one-handed installation and removal of the cable.

Resilient cable jackets

Cables with an OFNP (optical fiber non-conductive plenum) jacket are highly fire-resistant, making them ideal for plenum areas such as drop ceilings and raised floors. In case of combustion, cables with an LSZH (low-smoke zero-halogen) jacket limit the amount of toxic smoke emitted, making them suitable for poorly vented areas.

TAA-compliant for GSA Schedule purchases

The cables are compliant with the federal Trade Agreements Act (TAA), making them eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.



EATON

Powering Business Worldwide

Connectors



12F MPO/MPO F/F
(Aqua)



12F MPO/MPO F/F
(Magenta)




LC/LC Duplex
(Aqua)

Specifications

Catalog number	Optical mode	Polarity	Connectors	Cable jacket rating	Length	Color
TAA-compliant MPO/MPO (F/F) 50/125 multimode fiber cables, Type B polarity						
N845B-01M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	1 m (3.3 ft.)	Aqua
N845B-02M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	2 m (6.6 ft.)	Aqua
N845B-03M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	3 m (9.8 ft.)	Aqua
N845B-04M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	4 m (13.1 ft.)	Aqua
N845B-05M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	5 m (16.4 ft.)	Aqua
N845B-10M-12TAA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	10 m (32.8 ft.)	Aqua
N845B-01M-12MTA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	1 m (3.3 ft.)	Magenta
N845B-02M-12MTA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	2 m (6.6 ft.)	Magenta
N845B-03M-12MTA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	3 m (9.8 ft.)	Magenta
N845B-04M-12MTA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	4 m (13.1 ft.)	Magenta
N845B-05M-12MTA	OM4	Type B	12F MPO/MPO (F/F)	OFNP	5 m (16.4 ft.)	Magenta
TAA-compliant MPO/MPO (F/F) 50/125 multimode fiber cables, Type A polarity						
N845A-01M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	1 m (3.3 ft.)	Aqua
N845A-02M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	2 m (6.6 ft.)	Aqua
N845A-03M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	3 m (9.8 ft.)	Aqua
N845A-04M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	4 m (13.1 ft.)	Aqua
N845A-05M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	5 m (16.4 ft.)	Aqua
N845A-10M-12TAA	OM4	Type A	12F MPO/MPO (F/F)	OFNP	10 m (32.8 ft.)	Aqua
TAA-compliant LC/LC duplex 50/125 multimode fiber cables						
N820-01M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	1 m (3.3 ft.)	Aqua
N820-02M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	2 m (6.6 ft.)	Aqua
N820-03M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	3 m (9.8 ft.)	Aqua
N820-04M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	4 m (13.1 ft.)	Aqua
N820-05M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	5 m (16.4 ft.)	Aqua
N820-06M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	6 m (19.7 ft.)	Aqua
N820-07M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	7 m (23 ft.)	Aqua
N820-10M-TAA	OM3	Cross-over	LC/LC duplex	OFNP	10 m (32.8 ft.)	Aqua
N820-01M-OM4TAA	OM4	Cross-over	LC/LC duplex	LSZH	1 m (3.3 ft.)	Aqua
N820-02M-OM4TAA	OM4	Cross-over	LC/LC duplex	LSZH	2 m (6.6 ft.)	Aqua
N820-03M-OM4TAA	OM4	Cross-over	LC/LC duplex	LSZH	3 m (9.8 ft.)	Aqua
N820-05M-OM4TAA	OM4	Cross-over	LC/LC duplex	LSZH	5 m (16.4 ft.)	Aqua
N820-10M-OM4TAA	OM4	Cross-over	LC/LC duplex	LSZH	10 m (32.8 ft.)	Aqua

Cables have a lifetime limited warranty. Due to continuous improvement programs, all specifications are subject to change without notice.

To learn more about
TAA-compliant fiber cables,
visit TrippLite.Eaton.com

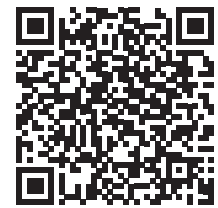

Eaton
1000 Eaton Boulevard
Cleveland, OH 44122
United States
Eaton.com

©2024 Eaton
All Rights Reserved
Printed in USA
BR153208EN/24-08-141
November 2024

Eaton is a registered trademark.

All other trademarks are property
of their respective owners.

Follow us on social media to get the
latest product and support information.

