




Find the Right Power Cord or Extension Cord for Any Equipment

Keep this handy Power Connection Guide. It will help you choose the perfect solution to replace, upgrade or extend the power cord for your isolation transformer, computer, UPS system, PDU or IT equipment. Hospital-grade models are highlighted in gray.

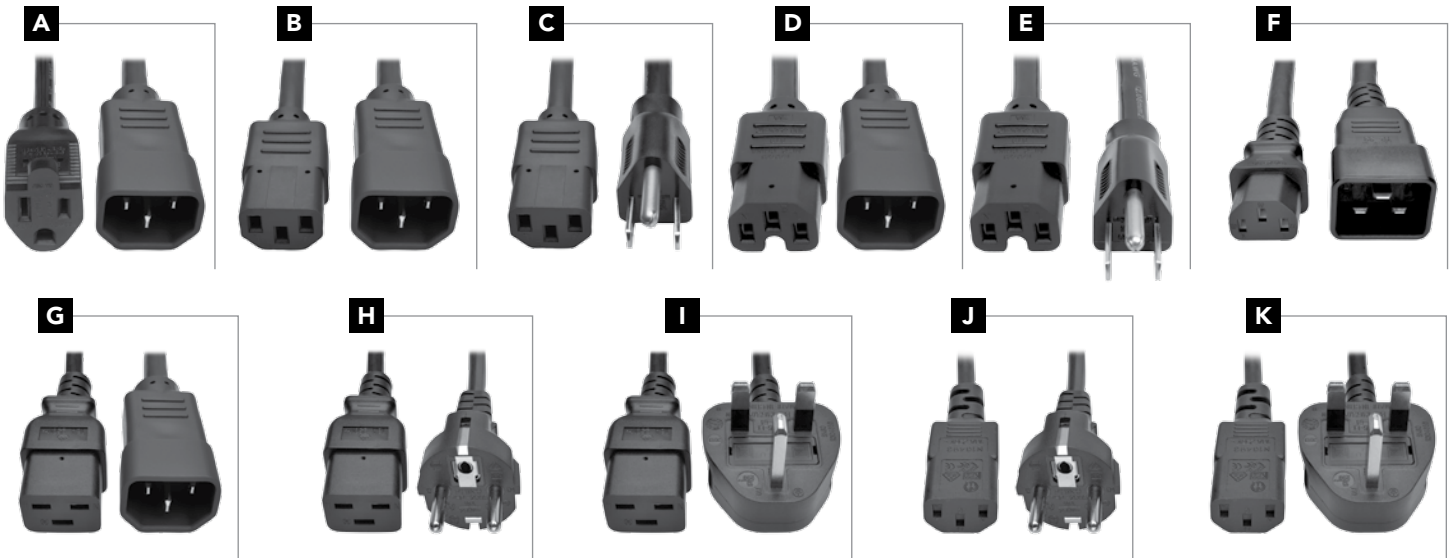

Model Number	Description	Length
A. 5-15R to C14		
P002-001-10A	125V, 10A, 18 AWG, SJT	1 ft. (0.3 m)
P002-002	125V, 13A, 16 AWG, SJT	2 ft. (0.6 m)
P002-002-10A	125V, 10A, 18 AWG, SJT	2 ft. (0.6 m)
B. C13 to C14		
P004-001	100-250V, 10A, 18 AWG, SJT	1 ft. (0.3 m)
P004-002*	100-250V, 10A, 18 AWG, SJT	2 ft. (0.6 m)
P004-002-13A	100-250V, 13A, 16 AWG, SJT	2 ft. (0.6 m)
P004-002-13LA	Left-Angle C13, 100-250V, 10A, 18 AWG, SJT	2 ft. (0.6 m)
P004-002-13RA	Right-Angle C13, 100-250V, 10A, 18 AWG, SJT	2 ft. (0.6 m)
P004-002-5	100-250V, 10A, 18 AWG, SJT, 5 Pack	2 ft. (0.6 m)
P004-003*	100-250V, 10A, 18 AWG, SJT	3 ft. (0.9 m)
P004-003-13A	100-250V, 13A, 16 AWG, SJT	3 ft. (0.9 m)
P004-004**	100-250V, 10A, 18 AWG, SJT	4 ft. (1.2 m)
P004-004-13A	100-250V, 13A, 16 AWG, SJT	4 ft. (1.2 m)
P004-005-13A	100-250V, 13A, 16 AWG, SJT	5 ft. (1.5 m)
P004-006*	100-250V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P004-006-13A	100-250V, 13A, 16 AWG, SJT	6 ft. (1.8 m)
P004-006-2C13	Y-Split (x2) C13, 100-250V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P004-008	100-250V, 10A, 18 AWG, SJT	8 ft. (2.4 m)
P004-010	100-250V, 10A, 18 AWG, SJT	10 ft. (3 m)
P004-015	100-250V, 10A, 18 AWG, SJT	15 ft. (4.5 m)
P005-002*	100-250V, 15A, 14 AWG, SJT	2 ft. (0.6 m)
P005-002-14LA	Left-Angle C14, 100-250V, 15A, 14 AWG, SJT	2 ft. (0.6 m)
P005-003*	100-250V, 15A, 14 AWG, SJT	3 ft. (0.9 m)
P005-006*	100-250V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P005-006-14LA	Left-Angle C14, 100-250V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P005-006-14RA	Right-Angle C14, 100-250V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P005-010	100-250V, 15A, 14 AWG, SJT	10 ft. (3 m)
P005-010-14LA	Left-Angle C14, 100-250V, 15A, 14 AWG, SJT	10 ft. (3 m)
P005-010-14RA	Right-Angle C14, 100-250V, 15A, 14 AWG, SJT	10 ft. (3 m)
P005-12N	100-250V, 15A, 14 AWG, SJT	1 ft. (0.3 m)
P005-18N	100-250V, 15A, 14 AWG, SJT	18 in. (0.5 m)

See other side for more solutions.

Model Number	Description	Length
C. C13 to 5-15P		
P006-001	125V, 10A, 18 AWG, SJT	1 ft. (0.3 m)
P006-002-13A	125V, 13A, 16 AWG, SJT	2 ft. (0.6 m)
P006-003	125V, 10A, 18 AWG, SJT	3 ft. (0.9 m)
P006-003-HG10	125V, 10A, Hospital Grade	3 ft. (0.9 m)
P006-003-HG13CL	125V, 13A, Hospital Grade with Clear Plugs	3 ft. (0.9 m)
P006-004**	125V, 10A, 18 AWG, SJT	4 ft. (1.2 m)
P006-006	125V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P006-006-13LA	Left-Angle C13, 125V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P006-006-13RA	Right-Angle C13, 125V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P006-006-2	Y-Split (x2) C13, 125V, 10A, 18 AWG, SJT	6 ft. (1.8 m)
P006-006-515MF	Piggyback 5-15P/R, 125V, 13A, 16 AWG, SJT	6 ft. (1.8 m)
P006-006-HG10	125V, 10A, Hospital Grade	6 ft. (1.8 m)
P006-006-HG13CL	125V, 13A, Hospital Grade with Clear Plugs	6 ft. (1.8 m)
P006-008-13A	125V, 13A, 16 AWG, SJT	8 ft. (2.4 m)
P006-010	125V, 10A, 18 AWG, SJT	10 ft. (3 m)
P006-010-13RA	Right-Angle C13, 125V, 10A, 18 AWG, SJT	10 ft. (3 m)
P006-010-HG10	125V, 10A, Hospital Grade	10 ft. (3 m)
P006-010-HG13CL	125V, 13A, Hospital Grade with Clear Plugs	10 ft. (3 m)
P006-014-13RA	Right-Angle C13, 125V, 10A, 18 AWG, SJT	14 ft. (4.3 m)
P006-015	125V, 10A, 18 AWG, SJT	15 ft. (4.5 m)
P006-015-HG10	125V, 10A, Hospital Grade	15 ft. (4.5 m)
P006-015-HG13CL	125V, 13A, Hospital Grade with Clear Plugs	15 ft. (4.5 m)
P006-020	125V, 10A, 18 AWG, SJT	20 ft. (6 m)
P006-025	125V, 10A, 18 AWG, SJT	25 ft. (7.6 m)
P006-025-HG15	125V, 15A, Hospital Grade	25 ft. (7.6 m)
P006-C08-HG10	125V, 10A, Hospital Grade, Coiled Cord	8 ft. (2.4 m) Coiled
P007-002	125V, 15A, 14 AWG, SJT	2 ft. (0.6 m)
P007-003	125V, 15A, 14 AWG, SJT	3 ft. (0.9 m)
P007-006	125V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P007-010	125V, 15A, 14 AWG, SJT	10 ft. (3 m)
P007-012	125V, 15A, 14 AWG, SJT	12 ft. (3.7 m)
P010-012	125V, 10A, 18 AWG, SVT	12 ft. (3.7 m)
P030-002-5	125V, 10A, 18 AWG, SJT, 5 Pack	2 ft. (0.6 m)
D. C15 to C14		
P018-002*	100-250V, 15A, 14 AWG, SJT	2 ft. (0.6 m)
P018-003*	100-250V, 15A, 14 AWG, SJT	3 ft. (0.9 m)
P018-006*	100-250V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P018-010	100-250V, 15A, 14 AWG, SJT	10 ft. (3 m)
E. C15 to 5-15P		
P019-004	100-250V, 15A, 14 AWG, SJT	4 ft. (1.2 m)
P019-008	100-250V, 15A, 14 AWG, SJT	8 ft. (2.4 m)
P019-008-C15RA	Right Angled C15, 125V, 15A, 14 AWG, SJT	8 ft. (2.4 m)
F. C13 to C20		
P032-002-2C13	Y-Split (x2) C13, 100-250V, 15A, 14 AWG, SJTW	2 ft. (0.6 m)
P032-003	100-250V, 15A, 12 AWG, SJTW	3 ft. (0.9 m)
P032-007	100-250V, 15A, 12 AWG, SJTW	7 ft. (2.1 m)
G. C19 to C14		
P047-002	100-250V, 15A, 14 AWG, SJT	2 ft. (0.6 m)
P047-004	100-250V, 15A, 14 AWG, SJT	4 ft. (1.2 m)
P047-006	100-250V, 15A, 14 AWG, SJT	6 ft. (1.8 m)
P047-006-10A	100-250V, 10A, 14 AWG, SJT	6 ft. (1.8 m)
P047-010	100-250V, 15A, 14 AWG, SJT	10 ft. (3 m)
H. C19 to SCHUKO CEE 7/7		
P050-008	250V, 16A, H05VV-F3G 1.5mm ^{SO}	8 ft. (2.4 m)
I. C19 to BS1363 UK		
P052-008	250V, 13A, H05VV-F3G 1.5mm ^{SO}	8 ft. (2.4 m)
J. C13 to SCHUKO CEE 7/7		
P054-006	250V, 10A, H05VV-F3G 1.0mm ^{SO}	6 ft. (1.8 m)
P054-008	250V, 10A, H05VV-F3G 1.0mm ^{SO}	8 ft. (2.4 m)
K. C13 to BS1363 UK		
P056-006-10A	250V, 10A, H05VV-F3G 1.0mm ^{SO}	6 ft. (1.8 m)

* Standard color is black. Alternative colors available: Blue, Green, Red, Orange & White. ** Standard color is black. Alternative colors available: Blue, Green, Red & Yellow.
Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Find All Tripp Lite Cable Solutions: triplite.com/cable-finder

Don't see what you need?
Contact our Cable Product Specialists
773.869.1234 · presaleshelp@triplite.com



Tripp Lite World Headquarters: 1111 W. 35th Street, Chicago IL 60609 USA