



Our Line of Rack Solutions Has Expanded!

Best Value

Lower costs combined with feature-rich designs and elements most other brands consider accessories, including vertical PDU mounting brackets, full-load rated casters, leveling feet and baying kits.

Versatile


Guaranteed compatibility with all standard 19-inch rack equipment. Multiple rack types from 2U to 48U support a wide range of applications.

Time-Saving

Toolless keyhole mounting makes installing PDUs and cable managers quick and easy. Easy-view index system simplifies vertical rail adjustment.

Heavy-Duty

Steel frames support up to 3,000 pounds static or up to 2,250 pounds dynamic.

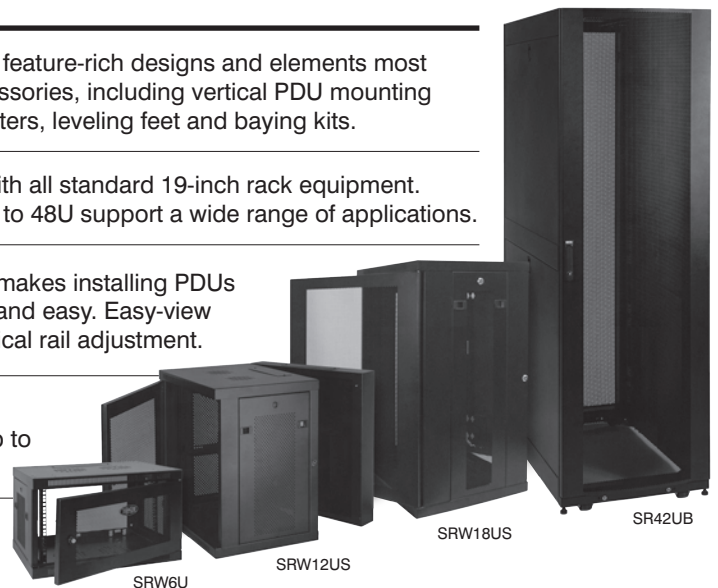

SmartRack™ Enclosures, Wall-Mount Enclosures and Open Frame Racks are backed by a **5-YEAR PRODUCT WARRANTY.**

Rack Types (With Model Prefix or Suffix)

- **Standard (-UB Suffix)** Black enclosures include removable doors and side panels.
- **White (-UW Suffix)** Standard enclosures that are white in color and include removable doors and side panels.
- **Wall-Mount (SRW- Prefix)** Compact enclosures and open frame racks mount to walls or any location with limited floor space. Models with an -S Suffix include a hinged/swinging wall bracket for easy service access.
- **Open Frame Racks** 2-post and 4-post open frame racks provide economical equipment organization for applications that do not require a secure cabinet.
- **Shock Pallet (-UBSP1 Suffix)** Include pallet with 1,250 lb (SP1) capacity and loading ramps for equipment pre-installation and reshipment to the final installation site.
- **Knockdown (-UBKD Suffix)** Ship flat in several sections for easy transport and assembly in tight spaces.
- **Expansion (-UBEXP Suffix)** Like standard models, but without side panels. -ND Suffix indicates models with no doors. -NR indicates models with no roof. -3 indicates built-in, heavy-duty 3" casters.
- **Deep (-UBDP Suffix), Wide (-UBWD Suffix), Deep & Wide (-UBDPWD Suffix)** Extra width and/or depth supports deeper server cabinets and blade chassis, while keeping PDUs and cables from obstructing airflow.
- **Shallow Depth (-UBSD Suffix)** Smaller footprint accommodates tight areas.

Model	Size	Type	Capacity
Wall-Mount Enclosures			
SRWF5U	5U	Low-Profile, Vertical	63.5 kg
SRW6U	6U	Non-Swinging	90.7 kg
SRW9U	9U	Non-Swinging	90.7 kg
SRW12U	12U	Non-Swinging	90.7 kg
SRW10US	10U	Swinging	90.7 kg
SRW12US	12U	Swinging	90.7 kg
SRW12US33	12U	Swinging, 33" Depth	113.4 kg
SRW12USG	12U	Swinging, Plexiglas® Door	90.7 kg
SRW12USNEMA	12U	Swinging, NEMA 12-Rated	90.7 kg
SRW18US	18U	Swinging	113.4 kg
SRW26US	26U	Swinging	113.4 kg
Wall-Mount Open Frame Racks			
SRWO8U22	8-22U	Adjusts to 8, 12 or 22U	68 kg
SRWO12US	12U	Pivoting Frame	68 kg
Open Frame Racks			
SR2POST	45U	2-Post Rack	363 kg
SR2POST25	25U	2-Post Rack	363 kg
SR4POST	45U	4-Post Rack	453.6 kg
SR4POST1224	45U	4-Post Rack, 12-24 Thread Mounting Holes	453.6 kg
SR4POST13	13U	4-Post Rack	453.6 kg
SR4POST25	25U	4-Post Rack	453.6 kg
SR42UBEXPND	42U	4-Post Rack, Heavy-Duty	1,360 kg
SR42UBEXPNDNR	42U	4-Post Rack, Heavy-Duty, No Roof	1,360 kg
SR42UBMDEXPND	42U	4-Post Rack, Heavy-Duty, Mid-Depth	1,360 kg
SR42UBMDEXPNDNR3	42U	4-Post Rack, Heavy-Duty, Mid-Depth, No Roof, 3" Casters	1,360 kg
SR42UWEXPNDNR	42U	4-Post Rack, Heavy-Duty, No Roof, White	1,360 kg
SR42UWEXPNDNR3	42U	4-Post Rack, Heavy-Duty, No Roof, White, 3" Casters	1,360 kg
SR45UBEXPND	45U	4-Post Rack, Heavy-Duty	1,360 kg
SR45UBEXPNDNR3	45U	4-Post Rack, Heavy-Duty, No Roof, 3" Casters	1,360 kg
SR45UBDPEXPND	45U	4-Post Rack, Heavy-Duty, Extended Depth	1,360 kg
SR48UBEXPND	48U	4-Post Rack, Heavy-Duty	1,360 kg
SR48UBEXPNDNR3	48U	4-Post Rack, Heavy-Duty, No Roof, 3" Casters	1,360 kg

See Reverse for Rack Enclosures



Our Line of Rack Solutions Has Expanded!

Rack Types (With Model Prefix or Suffix) continued

- **Mid Depth (-UBMD Suffix)** Footprint falls between shallow depth and standard models for a precise fit.
- **Colocation (-UBCL Suffix)** Include two secure compartments (upper and lower) and separate, lockable doors.
- **Thermal Duct (-UBTD Suffix)** Include adjustable overhead duct for superior heat removal and cooling efficiency.
- **Industrial (-EIS Suffix)** NEMA 12 (IP54)-rated to protect equipment from falling dirt, dust, drips, splashes and accidental contact with personnel.
- **Seismic (-Z4 Suffix)** Enhanced stability and protection with a Zone 4 seismic rating. The enclosure features welded construction, providing more security for use in unstable environments.
- **TAA Compliant (-TAA Suffix)** Compliant with all TAA regulations.
- **Cable Manager (-VRT Suffix)** Built-in vertical cable manager included.
- **10-32 Hardware (-1032 Suffix)** Include 10-32 thread mounting holes.

Perfect Your Application with Rack Accessories from Tripp Lite!

Our full line of accessories includes:

- Cooling solutions and accessories, including air conditioning, heat removal and airflow management
- Cable management accessories
 - Security and monitoring accessories
 - Rack shelves
- Mounting and power accessories

Model	Size	Type	Capacity
Enclosures			
SR12UB	12U	Compact	113.4 kg
SR25UB	25U	Standard	1,360 kg
SR25UBSP1	25U	Shock Pallet	1,360 kg
SR42UB	42U	Standard	1,360 kg
SR42UBG	42U	Plexiglas Door	1,360 kg
SR42UBKD	42U	Knockdown	1,360 kg
SR42UBEXP	42U	No Side Panels	1,360 kg
SR42UBSP1	42U	Shock Pallet	1,360 kg
SR42UBSD	42U	Shallow Depth	1,360 kg
SR42UB1032	42U	10-32 Thread Mounting Holes	1,360 kg
SR42UBSD1032	42U	Shallow Depth, 10-32 Thread Mounting Holes	1,360 kg
SR42UBDP	42U	Extended Depth	1,360 kg
SR42UBWD	42U	Extended Width	1,360 kg
SR42UBWDSP1	42U	Extended Width, Shock Pallet	1,360 kg
SR42UBDPWD	42U	Extended Depth, Extended Width	1,360 kg
SR42UBWDVRT	42U	Extended Width, Vertical Cable Manager	1,360 kg
SR42UBMD	42U	Mid-Depth	1,360 kg
SR42UBMDEXP	42U	Mid-Depth, No Side Panels	1,360 kg
SR42UBCL	42U	Co-location	1,360 kg
SR42UBTAA	42U	TAA-Compliant	1,360 kg
SR42UW	42U	Standard, White	1,360 kg
SR42UWSP1	42U	White, Shock Pallet	1,360 kg
SR45UB	45U	Standard	1,360 kg
SR45UBND	45U	No Doors	1,360 kg
SR45UBMD	45U	Mid-Depth	1,360 kg
SR45UBMDND	45U	Mid-Depth, No Doors	1,360 kg
SR45UBMDEXPND	45U	Mid-Depth, No Doors, No Side Panels	1,360 kg
SR45UBEXP	45U	No Side Panels	1,360 kg
SR45UBSP1	45U	Shallow Pallet	1,360 kg
SR45UBSD	45U	Short Depth	1,360 kg
SR45UBDP	45U	Extended Depth	3,000 lb
SR45UBDPEXPC	45U	Extended Depth, No Side Panels, Combination Locks	1,360 kg
SR45UBDPND	45U	Extended Depth, No Doors	1,360 kg
SR45UBWD	45U	Extended Width	1,360 kg
SR45UBWDSP1	45U	Extended Width, Shock Pallet	1,360 kg
SR45UBDPWD	45U	Extended Depth, Extended Width	1,360 kg
SR45UBDPWDC	45U	Extended Depth, Extended Width, Combination Locks	1,360 kg
SR45UBWDVRT	45U	Extended Width, Vertical Cable Manager	1,360 kg
SR48UB	48U	Standard	1,360 kg
SR48UBCL	48U	Co-location	1,360 kg
SR48UBDPWD	48U	Extended Depth, Extended Width	1,360 kg
SR48UBEXP	48U	No Side Panels	1,360 kg
SR48UBSP1	48U	Shock Pallet	1,360 kg
SR48UBWD	48U	Extended Width	1,360 kg

For detailed product information and ordering help, visit www.tripplite.com or contact:

Tripp Lite Middle East
+971.4.887.1633
salesint@tripplite.com

Tripp Lite South Africa
+27.82.8099.043
andre_viljoen@tripplite.com



See Reverse for Wall-Mount and Open Frame Racks