



NEW PRODUCT ANNOUNCEMENT


SmartRack® Wall-Mount Rack Enclosure Cabinets

Wall-Mount Racks with Built-In Cable Managers

Model: SRW9UDPVRT



Model: SRW6UDPGVRT

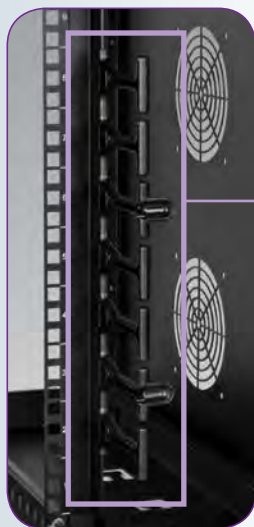

Internal vertical cable managers reduce cable clutter to promote better airflow and organization.

Tripp Lite's new SmartRack wall-mount rack enclosure cabinets are the first to feature built-in vertical finger ducts for cable management. The cable managers, along with cable pass-throughs and cable tie cutouts, provide orderly routing of cables from standard 19-inch rack equipment. The reduced cable clutter promotes better airflow in high-density installations and makes equipment replacement easier. Built-in cable management also saves the expense of adding external cable managers to the cabinet.

Key Benefits

ENHANCED CABLE MANAGEMENT

- Vertical cable managers with finger ducts keep cables neatly routed to reduce clutter.
- Cable pass-throughs and access openings on the top and bottom of the cabinet facilitate cable management.
- Cable tie cutouts allow cable bundles to be secured to the top or bottom of the cabinet.

EFFECTIVE VENTILATION

- Improved cable management promotes efficient airflow.
- Top, bottom and side ports support installation of ventilation fans, such as Tripp Lite's SRFANWM (sold separately).

SECURE ORGANIZATION

- Locking front door and side panels help keep equipment secure.
- Cabinets support PCI DSS compliance for payment card processing.

SIMPLE EQUIPMENT MOUNTING

- Side panels are removable for convenient access to equipment.
- Mounting rails are adjustable and have square and round (threaded) mounting holes. Rack spaces are numbered for easy installation.
- Equipment mounting hardware is included.

SPACE FOR MORE EQUIPMENT

- Cabinets are switch-depth-plus to accommodate equipment up to 20.5 inches deep.
- 9U cabinets have brackets to accommodate an additional 4U of vertically mounted equipment.

QUICK DEPLOYMENT

- Cabinets ship fully assembled and ready for wall-mount installation with user-supplied hardware.


Perfect for:

Network switches, patch panels and related equipment in locations with limited floor space.


Feature Focus




Side

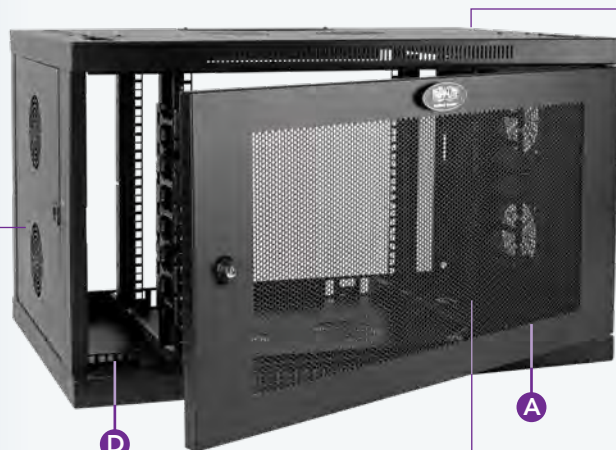


Model: SRW9UDPVRT (Front)

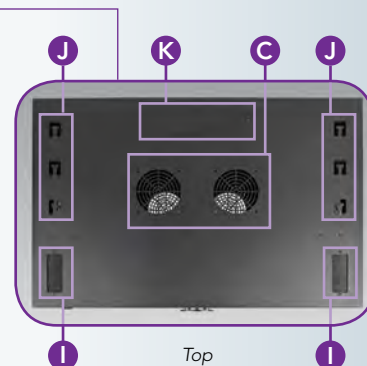

Top

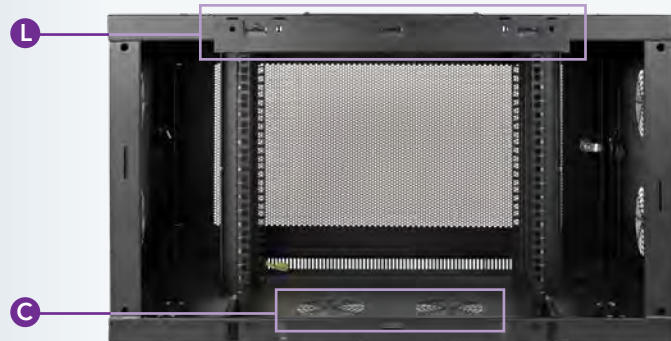

Model: SRW9UDPVRT (Back)

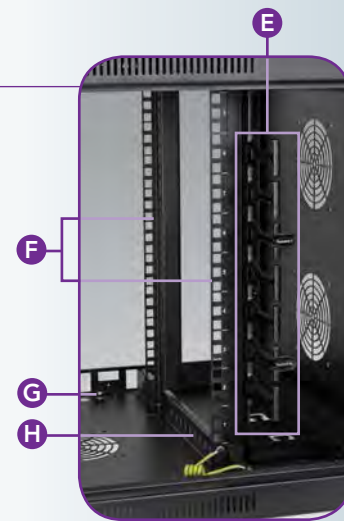

A Key-Locking Front Door

(Includes two keys; SRW6UDPGVRT and SRW9UDPGVRT have a clear acrylic window)

B Locking, Removable Side Panels

C Ventilation Fan Ports

(Configuration varies by model)

D 2U Equipment Mounting Brackets

(9U models only)

E Vertical Cable Managers with Finger Ducts

F Vertical Mounting Rails (Adjustable)

G Ground Stud

H Horizontal Rails

I Cable Pass-Throughs with Brush Strips

J Cable Tie Cutouts

K Cable Access Hole Cover (Removable)

L Mounting Plate



SPECIFICATIONS

Model	SRW6UDPVRT	SRW6UDPGVRT	SRW9UDPVRT	SRW9UDPGVRT
Rack Height	6U		9U	
Front Door Style	Ventilated	Clear Acrylic Window	Ventilated	Clear Acrylic Window
Maximum Device Depth	20.5 in. (52.07 cm)			
Weight Capacity	200 lb. (90.7 kg)			
Unit Dimensions (H x W x D)	14.58 x 29.62 x 21.71 in. (37.03 x 75.24 x 55.15 cm)		19.83 x 29.62 x 21.71 in. (50.37 x 75.24 x 55.15 cm)	
Unit Weight	43 lb. (19.5 kg)	44.5 lb. (20.2 kg)	51.8 lb. (23.5 kg)	53.1 lb. (24.1 kg)
Material of Construction	Steel with Black Powder-Coated Finish			
Limited Warranty	5 Years			

Models meet EIA/ECA-310-E standards. All meet IP20 when mounted to wall. RoHS and PCI DSS compliant.

Learn more about Tripp Lite's full line of SmartRack solutions at www.tripplite.com.



1111 W. 35th Street, Chicago, IL 60609 • 773.869.1773 • www.tripplite.com

© 2019 Tripp Lite. All trademarks are the property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.