

Conveniently power, charge and protect all your devices



*Surge protectors can accommodate 10 AC-powered devices
and two USB devices at once.*

Perfect for:

Protecting lab equipment, industrial tools and other electronics against power surges, spikes and line noise.

Protect It!® surge protectors with light bars keep a variety of devices, from power tools to sensitive electronics, safely and conveniently powered and charged. With 10 NEMA outlets and two USB charging ports, they provide up to 4500 joules of protection as well as EMI/RFI line noise filtering, helping critical electrical equipment last longer and perform at its best.

The built-in light bars on these surge protectors illuminate poorly lit spaces, making it easier to connect devices under desks and behind heavy-duty machinery. They have 6 ft. or 10 ft. input cords and can be mounted on walls or desks, giving installers the flexibility they need for optimal equipment placement. Professionals in electrical, industrial and construction trades will appreciate the reliability and time-saving features these surge protectors offer.

Key benefits

ROBUST PROTECTION

- 10 surge protection outlets have a 1350 or 4500 joule rating for defending devices against damaging power surges and spikes.
- Line noise filtering removes EMI (electromagnetic interference) and RFI (radio frequency interference) to preserve data and hardware longevity and improve performance quality.
- Integrated 15A resettable circuit breakers help prevent equipment damage due to overloads.

USB CHARGING

- Two USB-A ports provide 2.4A of charging power for cell phones and other electronics.

HEAVY-DUTY COMPATIBILITY

- Widely spaced, right-angle outlets can easily accommodate bulky transformers.

CONVENIENT INSTALLATION

- Two built-in, swiveling light bars make installation and the connection of devices in poorly lit spaces easier.
- 6 ft. or 10 ft. input cords add flexibility to surge protector placement.
- Rear mounting keyholes allow desk or wall mounting, which saves work space and provides optimal placement for connections.

INFORMATIVE OPERATION

- Diagnostic LEDs indicate at a glance whether the wall outlet is grounded and equipment is protected.
- Two lighted on/off switches allow one-touch control over the light bars and all equipment connected to the surge protector.

RELIABLE COVERAGE

- Surge protectors are covered by a Lifetime Limited Warranty and include up to \$150,000 Ultimate Lifetime Insurance.

Feature focus

A Input cord

6 ft. (TLP1006USB) or 10 ft. (TLP1010USB) input cord with a NEMA 5-15P plug provides more options for surge protector placement.

B x10 outlets

10 surge-protected outlets safeguard connected devices; outlet right-angle positioning and wide spacing accommodates bulky transformers without covering adjacent outlets.



C USB charging ports


Two USB-A charging ports provide 2.4A charging.

D Toggle switches

Lighted on/off toggle switches allow one-touch control of outlets and light bars.


E LED indicators

LED lights indicate at a glance whether the wall outlet is grounded and a connected device is protected.

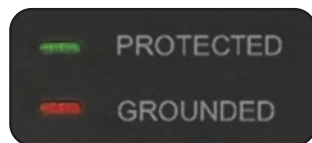

F Light bars

2 swivel light bars each provide 1000 lumens of bright white light (20W total).

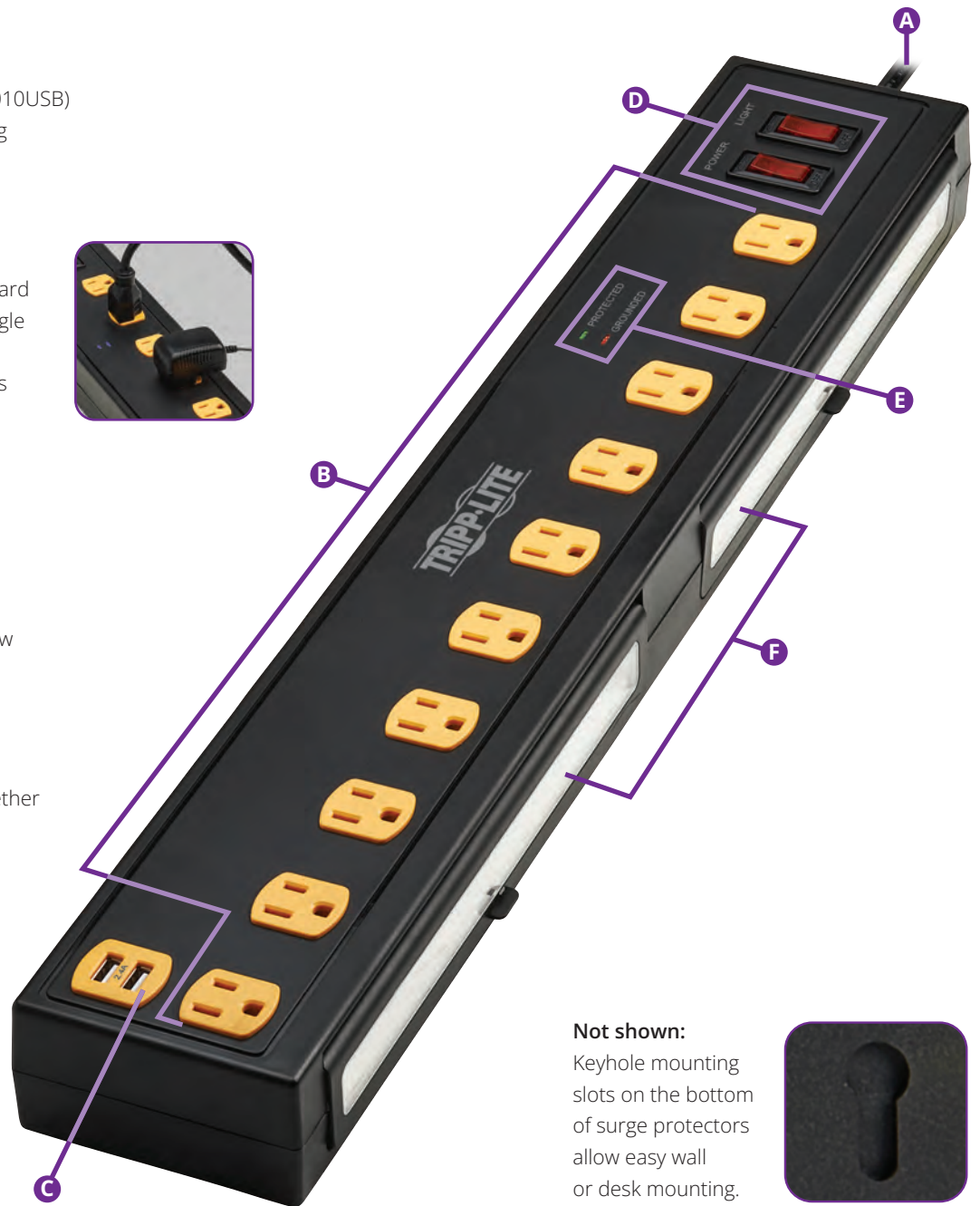

Not shown:

Keyhole mounting slots on the bottom of surge protectors allow easy wall or desk mounting.



SPECIFICATIONS

Model	Outlets	Cord length	Plug style	Joules	EMI/RFI filtering	USB ports/charging capacity	Lifetime limited warranty	Ultimate Lifetime Insurance
TLP1006USB	(10) NEMA 5-15R	6 ft.	NEMA 5-15P	1350	Yes	(2) USB-A/2.4A	Yes	\$100,000
TLP1010USB	(10) NEMA 5-15R	10 ft.	NEMA 5-15P	4500	Yes	(2) USB-A/2.4A	Yes	\$150,000

Models are rated for 120V AC (60 Hz) operation.

Learn more about our full line of surge protectors at tripplite.eaton.com

TRIPP-LITE
by **EATON**

1000 Eaton Boulevard | Cleveland, OH 44122
773.869.1773 | tripplite.eaton.com