


Facility Power

Edge / IIoT Data Center



POWER

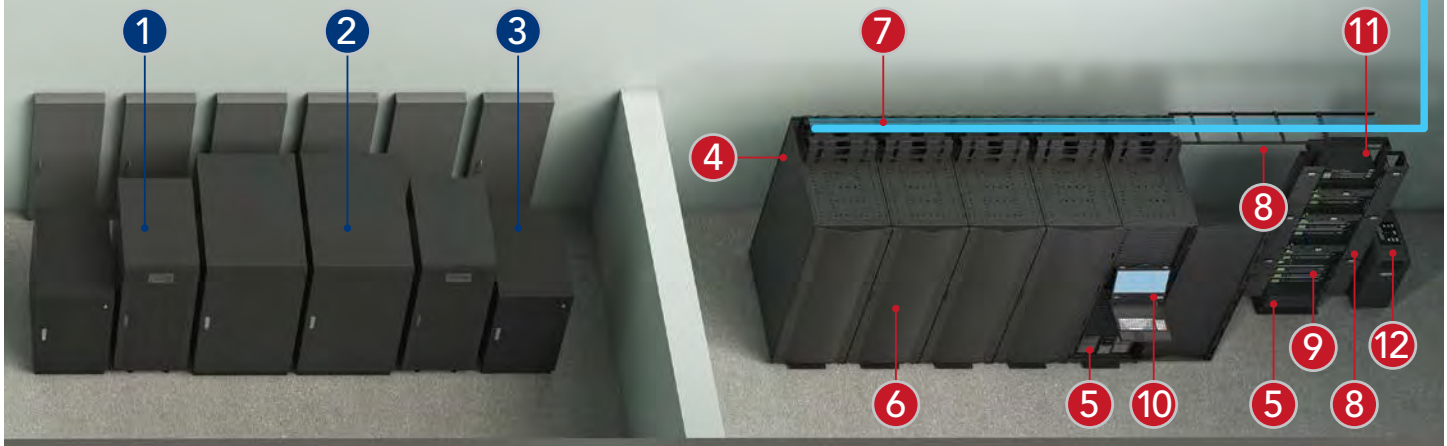

1 3-Phase UPS Systems

- Up to 600 kVA of continuous power for critical systems
- Smallest footprint, Energy Star® 2.0 certified 10 to 100 kVA 208V 3-phase UPS

2 3-Phase Battery Cabinets

- Support for multiple hours of backup runtime

3 3-Phase Transformers

- Variety of 480V and 600V transformers

4 Network-Grade Rack PDUs



- Single-phase, 3-phase, horizontal and vertical models
- With or without current monitoring, network interface, outlet control and ATS

5 Single-Phase UPS Systems

- Up to 20 kVA of protected power with battery backup



ENCLOSURES



6 Floor-Standing Rack Enclosures

- 12U to 48U; NEMA 12 (IP54)-rated and seismic-certified models available

CABLES & CONNECTIVITY

7 IP68-Rated Connectivity Solutions

- Cat6, fiber, USB and HDMI cables and couplers
- Waterproof junction boxes



8 Cable Managers

- Cable organization and routing inside or outside racks



PoE SOLUTIONS

9 PoE Network Switches



- Up to 24 Gigabit Ethernet ports and 300W PoE budget
- 1U combo models with built-in PDU available

ADDITIONAL SOLUTIONS

10 KVM Switches

- Multi-server control from a single console with or without built-in LCD and IP network access
- 1U rack-mount, desktop and secure models available



11 Console Servers



- Secure in-band and out-of-band remote access to serial- and network-connected devices

12 Air Conditioning Units

- Up to 33,000 BTU of remotely manageable, close-coupled cooling
- Portable, rack-mount, wall-mount and in-row options



© 2020 Tripp Lite. All trademarks are the property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.

For more information, contact:

Pre-Sales Tech Support

773.869.1773 • presaleshelp@tripplite.com



1111 W. 35th Street
Chicago, IL 60609
773.869.1234
tripplite.com