


4-Port HDMI/USB KVM Switch with Audio/Video and USB Peripheral Sharing

MODEL NUMBER: B004-HUA4-K

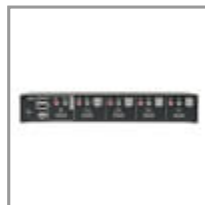

Controls 4 HDMI-enabled desktop, laptop or notebook computers using one HDMI monitor and one USB keyboard/mouse.

Features

Connects 4 HDMI-Enabled Devices to a Single HDMI Monitor, Keyboard and Mouse This compact four-port KVM switch lets you access, control, boot and reboot four computers or other devices with HDMI ports at the same time. In addition to desktop and notebook computers, the switch also connects up to four media centers, gaming systems, Blu-ray and DVD players, cable and satellite boxes and DVRs, and other HDMI-enabled devices. All four computers share one HDMI monitor, USB keyboard and USB mouse, which saves space on your desk or workspace.

Switching Between Computers Is Fast and Easy Use the front-panel push buttons or hotkey commands for quick and easy toggling between computers. Or you can use Auto Scan mode to scan all four connected computers in five-second intervals automatically. Orange LEDs indicate which computer is currently selected.

Cables Are Included for Fast and Simple Setup Connect your HDMI monitor, keyboard, mouse, and speakers to the switch's console ports. Then, use the included HDMI, USB-B and 3.5 mm audio cables to connect your computers to the KVM switch. The plug-and-play KVM switch requires no software or drivers, so you can connect and use it immediately. The B004-HUA4-K works with all major operating systems, including Windows, Mac and Linux.

USB Hub Lets You Share Peripherals between Computers The built-in two-port USB 2.0 hub allows you to share USB peripherals, such as printers, hard drives, scanners, webcams and flash drives, between the four connected computers. Because the USB ports operate independently, you can print documents from one computer while working on a different computer. The hub is backward compatible with USB 1.1 devices. Green LEDs indicate which computer is using the connected USB device.

Transmits Crystal-Clear 1080p Video and Digital Audio The B004-HUA4-K KVM switch supports high-definition video resolutions up to 1920 x 1200 (including 1080p) at 60 Hz, 2.1-channel surround sound audio, and USB 2.0 data transfer rates up to 480 Mbps. With independent audio switching, you can listen to music or other audio from one computer while working on a different computer. The front-panel audio jacks have priority over the rear-panel jacks.

Highlights

- Supports HD resolutions up to 1920 x 1200 (@ 60 Hz) for crystal-clear 1080p video
- Manual push buttons and hotkey commands allow easy toggling between computers
- Built-in 2-port USB 2.0 hub lets you share USB peripherals among connected computers
- 3.5 mm stereo jacks provide 2.1-channel surround sound audio input to each computer
- Widely compatible KVM switch works with Windows, Mac and Linux operating systems

Applications

- Share the keyboard, mouse and HDMI display of a desktop computer with multiple laptop computers
- Connect up to 4 gaming consoles, media centers and other A/V devices for a home theater system with 1080p resolution
- Improve productivity at work with 4-way system control
- Save money and space by sharing USB peripherals, such as a printer and external hard drive, among all computers

System Requirements

Console Requirements

- Monitor with HDMI connector (should support the highest resolution of any connected



computer)

- USB keyboard/mouse
- Microphone/speakers with 3.5 mm mini stereo connectors

(optional)

Computer Requirements

- HDMI connector
- USB-A connector
- 3.5 mm mini stereo jacks (optional)
- Windows, Mac, Novell, UNIX or Linux operating system

Package Includes

- B004-HUA4-K 4-Port HDMI/USB KVM Switch
- (4) HDMI/USB KVM cable kits, 6 ft.
- Firmware upgrade cable
- External power supply w/NEMA 1-15P plug & 5 ft. cord (Input: 100–240V, 50/60 Hz, 0.5A; Output: 5.3V 2.4A)
- Owner's manual

Specifications

| OVERVIEW | |
|--|--------------------------|
| UPC Code | 037332226129 |
| INPUT | |
| External Power Supply Input Specs (V / Hz / A) | 100-240V~50/60 Hz, 0.5A |
| External Power Supply Output Specs (V / A) | 5.3V, 2.4A |
| External Power Supply Cord Length (ft.) | 5 |
| External Power Supply Plug(s) | NEMA 1-15P North America |
| External Power Supply Certifications | FCC; TUV; UL; cUL |



| USER INTERFACE, ALERTS & CONTROLS | |
|--|---|
| LED Indicators | ORANGE (ON LINE), GREEN (USB LINK) |
| PHYSICAL | |
| Color | Black |
| Unit Dimensions (hwd / in.) | 1.8 x 10.3 x 2.8 |
| Unit Dimensions (hwd / mm) | 46 x 261 x 72 |
| Unit Packaging Type | Box |
| Unit Weight (kg) | 2.40 |
| Unit Weight (lbs.) | 5.3 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 32 to 122°F (0 to 50°C) |
| Storage Temperature Range | -4 to 140°F (-20 to 60°C) |
| Relative Humidity | 0 to 80% RH, Non-Condensing |
| COMMUNICATIONS | |
| IP Remote Access | No |
| CONNECTIONS | |
| Ports | 4 |
| PC/Server Connections | HDMI; USB |
| Side A - Connector 1 | (2) 3.5MM (FEMALE); HDMI (FEMALE); (2) USB A (FEMALE) |
| Side A - Connector 2 | (8) 3.5MM (FEMALE); (4) HDMI (FEMALE); (4) USB B (FEMALE) |
| Side A - Connector 3 | USB A (FEMALE) |
| Side B - Connector 1 | (2) 3.5MM (FEMALE); USB A (FEMALE) |
| Computer Keyboard and Mouse Interface | USB |
| Computer Monitor Interface | HDMI |
| Console Keyboard and Mouse Interface | USB |
| Console Monitor Interface | HDMI |
| FEATURES & SPECIFICATIONS | |
| Autoscan (Y,N) | Y |
| Autoscan Duration | 5 seconds (Default) |
| Number of Users | 1 |
| NIAP-Certified Secure | No |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|-------------------------------------|----------------------------|
| Port Selection | Hotkey; Pushbutton |
| Max Supported Video Resolution | 1920 x 1200 @60Hz |
| HDMI Specification | 1.3 |
| HDCP Specification | 1.4 |
| USB Hub Ports | Yes |
| Number of USB Hub Ports | 2 |
| USB Specification | USB 2.0 (up to 480 Mbps) |
| Audio Specification | 2.1-channel surround sound |
| Cat5 KVM Switch | No |
| Technology | HDMI; USB 2.0 (High Speed) |
| CERTIFICATIONS | |
| Certifications | Tested to FCC, RoHS, REACH |
| WARRANTY | |
| Product Warranty Period (Worldwide) | 3-year limited warranty |

© 2019 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>