


2-Port USB/DVI Cable KVM Switch with Audio, Cables and USB Peripheral Sharing

MODEL NUMBER: B032-DUA2

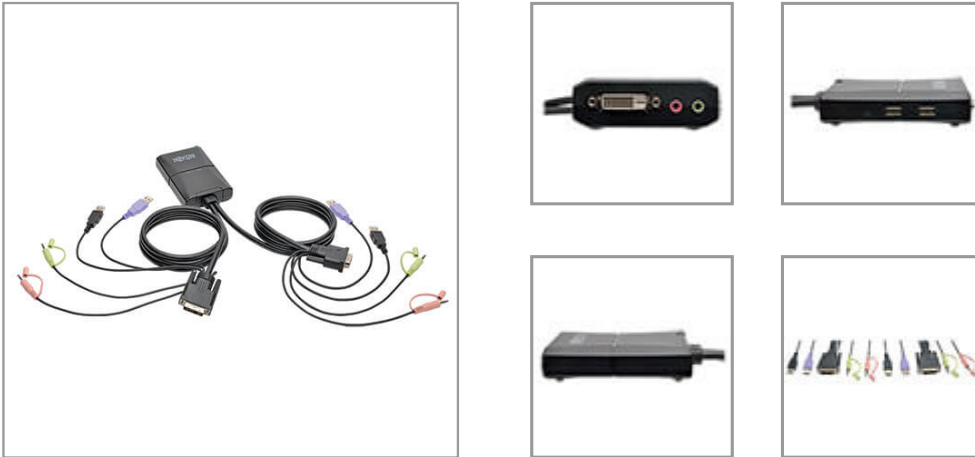

Control 2 computers using one DVI monitor, USB keyboard and USB mouse. Connect a USB 2.0 hub (sold separately) to share USB peripherals, such as printers and hard drives, between computers.

Features

Access and Control 2 Computers with One Keyboard/Mouse/Monitor

- Recommended for home, office, gaming and multimedia applications
- Switch between computers using remote port selector, hotkeys or mouse wheel
- Supports video resolutions up to 1920 x 1200 (1080p)
- Supports 2.1-channel surround sound with full bass
- Listen to audio files on one computer while accessing the other
- Compliant with EDID and HDCP
- Built-in 4-ft. (1.22 m) DVI, USB and audio cables

Independent USB 2.0 Peripheral Sharing

- Adding an optional USB hub (sold separately) to the USB console mouse port allows connection of peripherals, such as printers, hard drives, scanners, webcams and thumb drives

Flexible Keyboard/Mouse Applications

- Console mouse port emulation/bypass supports most mouse drivers and multifunction mice
- Works with multimedia keyboards and wireless keyboards and mice
- Supports Mac and Sun keyboard emulation

Easy Plug-and-Play Setup and Use

- Compatible with Windows, Mac and Linux
- No external power supply, software or drivers to install
- Switches automatically to other computer when one powers off
- Upgradable firmware
- Takes up no valuable desk space

Highlights

- Built-in 4-ft. (1.22 m) DVI, USB and audio cables
- Supports video resolutions up to 1920 x 1200 (1080p)
- Supports 2.1-channel surround sound with full bass
- Remote, hotkey and mouse port switching
- Compatible with Windows®, Mac® and Linux®

System Requirements

- DVI monitor
- USB keyboard
- USB mouse
- Computers with DVI and USB ports

Package Includes

- B032-DUA2 2-Port USB/DVI Cable KVM Switch
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332200365
Max CPU	2
Technology	DVI; Stereo Audio; USB 2.0 (High Speed)
POWER	
Power Consumption (Watts)	3.05
CONNECTIONS	
Number of Ports	2
PC/Server Connections	DVI; USB
Side A - Connector 1	DVI-D DUAL-LINK (FEMALE) (WIRED TO DVI-D SINGLE-LINK)
Side A - Connector 2	(2) USB A (FEMALE)
Side A - Connector 3	(3) 3.5MM (FEMALE)
Side B - Connector 1	(2) DVI-D SINGLE LINK (MALE)
Side B - Connector 2	(4) USB A (MALE)
Side B - Connector 3	(4) 3.5MM (MALE)
PHYSICAL	
Shipping Dimensions (hwd / in.)	2.40 x 6.70 x 9.40
Shipping Dimensions (hwd / cm)	6.10 x 17.02 x 23.88
Shipping Weight (lbs.)	1.30
Shipping Weight (kg)	0.59
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
Unit Dimensions (hwd / cm)	2.65 x 11.30 x 7.65
Unit Weight (lbs.)	1.06
Unit Weight (kg)	0.48
ENVIRONMENTAL	
Operating Temperature Range	32° to 122°F (0° to 50°C)
Storage Temperature Range	-4° to 140°F (-20° to 60°C)
Relative Humidity	0% to 80% RH, Non-Condensing
COMMUNICATIONS	
IP Remote Access	No



Powering Business Worldwide



FEATURES & SPECIFICATIONS	
NIAP-Certified Secure	No
Number of Users	1
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; CE (Europe); REACH; FCC (USA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2026 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.