


VGA over Cat5 Extender, 2-Port Transmitter

MODEL NUMBER: **B132-002-1**

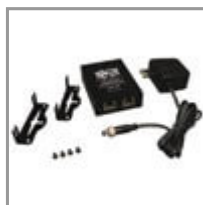

Description

Tripp Lite's B132-002-1 allows you to split a single VGA signal into 2. Along with a B132-100-1 or B132-100-WP-1 remote receiver unit, you can extend a 1920 x 1440 (60Hz) signal up to 500 ft., or a 1024 x 768 (60Hz) signal up to 1,000 ft., when using 24Awg, Solid Wire Cat5e/6 cable, such as Tripp Lite's N022-01K-GY (Cat5) and N222-01K-GY (Cat6). For optimal video image quality between 500 and 1,000 ft., use Zero-Skew cable, such as Tripp Lite P524-01K. Includes mounting hardware that allows unit to be wallmounted, rackmounted or pole mounted. Ideal for digital signage situations, such as retail, schools, churches, etc. Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases.

Features

- Splits a single VGA signal into 2
- A B132-100-1 or B132-100-WP-1 remote receiver unit is required for each connected monitor
- Extends a 1920 x 1440 (60Hz) signal up to 500 ft., or a 1024 x 768 (60Hz) signal up to 1,000 ft., when using 24Awg, Solid Wire Cat5e/6 cable, such as Tripp Lite's N022-01K-GY (Cat5) and N222-01K-GY (Cat6)
- For optimal image quality between 500 and 1,000 ft., use Zero-Skew cable, such as Tripp Lite P524-01K
- Includes mounting hardware that allows unit to be wallmounted, rackmounted or pole mounted.
- Ideal for digital signage situations, such as retail, schools, churches, etc.
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Specifications

OVERVIEW	
UPC Code	037332160164
Product Type	Cat5/Cat6 Transmitter
Technology	VGA/SVGA

Highlights

- Splits a single VGA signal into 2
- Extends a 1920 x 1440 (60Hz) signal up to 500 ft., or a 1024 x 768 (60Hz) signal up to 1,000 ft., when using 24Awg, Solid Wire Cat5e/6 cable, such as Eaton's N022-01K-GY (Cat5) and N222-01K-GY (Cat6)
- For optimal image quality between 500 and 1,000 ft., use Zero-Skew cable, such as Eaton P524-01K
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Package Includes

- 2 Port Extender/Splitter local (Transmitter) unit
- Mounting hardware
- External Power Supply (Input: 100-240V, 50/60Hz, 1.5A Output: 12.6V, 3A)
- Owner's Manual



Powering Business Worldwide



POWER	
AC Adapter	Input: 100-240V, 50/60Hz, 1.5A; Output: 12.6V, 3A
CONNECTIONS	
Number of Ports	2
Side A - Connector 1	HD15 (FEMALE)
Side B - Connector 1	(2) RJ45 (FEMALE)
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	2.20 x 7.20 x 6.50
Shipping Dimensions (hwd / cm)	5.59 x 18.29 x 16.51
Shipping Weight (lbs.)	1.00
Shipping Weight (kg)	0.45
Unit Dimensions (hwd / in.)	1.000 x 2.500 x 3.600
Unit Dimensions (hwd / cm)	2.54 x 6.35 x 9.40
Unit Weight (lbs.)	0.45
Unit Weight (kg)	0.20
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	1-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.