


16-Device USB Charging Station Cabinet with Sync for iPad and Android Tablets, Wall-Mount and Cart Options, 230V, Schuko CEE7 to C13 Plug, Black

MODEL NUMBER: CSCXS16USB

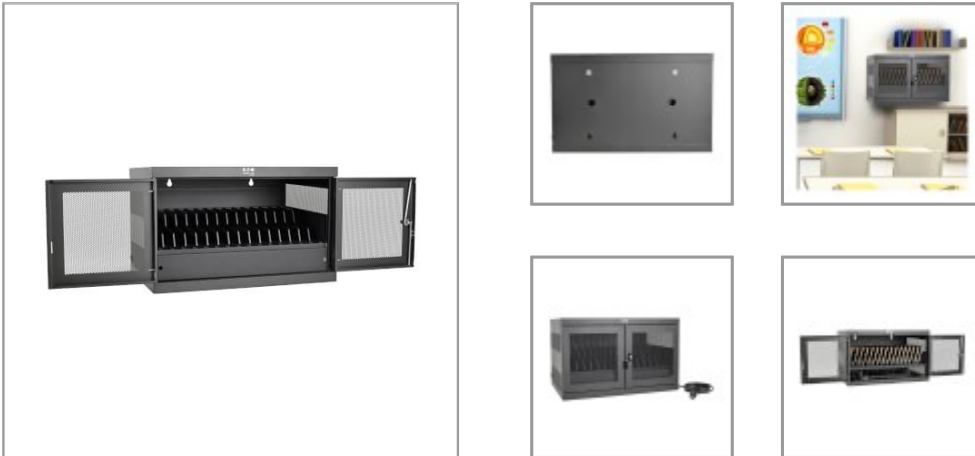

Provides 2.4A USB charging, syncing, secure storage and cord management for up to 16 tablets and other devices.

Features

Charges, Syncs, Secures and Organizes Up to 16 Tablets and Other USB Devices

This charging cabinet provides fast charging, convenient syncing, secure storage and cord management for up to 16 iPad, Android, Surface and Kindle tablets, as well as smartphones and other USB devices. Ideal for education, office, commercial, retail, industrial and healthcare environments, this locking steel cabinet with a black powder-coated finish keeps valuable mobile devices safe, secure and always ready to use.

Fast Charging and Convenient Syncing

The CSCXS16USB features 16 USB ports capable of delivering the fastest charging supported by each device, up to 2.4A per port. A USB uplink port connects to a host computer for wired syncing, though the CSCXS16USB also supports wireless syncing and simultaneous syncing/charging (up to 1.5A per port during wired syncing). The 3.7-meter (12-foot) AC input cord with Schuko-to-C13 plug reaches distant outlets to help you place the cart in a convenient location.

Comprehensive Protection Against Theft, Tampering, Overheating and Abrasions

The CSCXS16USB locks with the included keys to help protect devices from theft, damage or tampering. A three-point locking mechanism latches doors at the top, middle and bottom. For extra security, you can replace or supplement the built-in lock with your own padlock, and rear ports accommodate an optional cable or chain lock to secure the entire unit in place. Flow-through ventilation prevents devices from overheating. The protective shelf is specially coated to prevent device scratches and scuffs, and the cord access ports include rubber grommets to protect against abrasions. A solid top doubles as a work surface and helps prevent accidental drips and spills from damaging devices.

Clutter-Reducing Organization

USB ports and charging cords are carefully stored out of sight. A front trim panel easily removes without tools to permit quick service access. Each device has its own charging cord access port.

Flexible Configuration

The CSCXS16USB ships fully assembled for quick installation on a desktop or floor in a structurally sound area or wall mounting with user-supplied tools and hardware. You can also convert it to a mobile cart with the optional CSHANDLEKIT2 (sold separately), and roll it where needed. The split front doors open 180

Highlights

- Secures up to 16 mobile devices behind locking doors to help prevent tampering
- 230V cabinet features 3.7 m cord with Schuko-to-C13 plug for reaching distant outlets
- Removable dividers accommodate thicker devices such as battery chargers
- Supports wall mounting or desktop/floor placement in a structurally sound area
- Ships fully assembled for immediate placement in an office, classroom, etc.

Package Includes

- CSCXS16USB 16-Device USB Charging Station Cabinet, Black
- (2) Keys
- Owner's manual



Powering Business Worldwide

TRIPP LITE
SERIES

degrees for improved device and service access. You can remove the shelf dividers to fit thicker devices, such as battery chargers, and a firmware upgrade port allows future updates.

Specifications

OVERVIEW	
UPC Code	037332285034
Product Type	Multi-Device Charger
Charging Form Factor	Stationary Cabinet
Charger Functions	Charge; Secure; Sync
Device Compatibility	Tablet
Device Slots	16
INPUT	
Nominal Input Voltage(s) Supported	230V AC
Voltage Compatibility (VAC)	230
Input Frequency	50 Hz
Input Plug Type	Schuko
Input Cord Length (ft.)	12
Input Cord Length (m)	3.66
POWER	
Power Consumption (Watts)	56.00
CHARGING	
Number of Charging Ports	16
Total Charging Amps	40
Total Charging Watts	200
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports Details	Pass through
Charging Ports / Amps	(16) 2.4A
Overcharge Protection	Yes
Charging Amps per Port	2.4A
PHYSICAL	
Color	Black
Material of Construction	Steel



Powering Business Worldwide

TRIPP LITE
SERIES

Charging Station Form Factor	Stationary Cabinet
Unit Dimensions (hwd / in.)	18.800 x 30.330 x 20.200
Unit Weight (lbs.)	85.98
Unit Weight (kg)	39.00
Number of Shelves	1
ENVIRONMENTAL	
Operating Temperature Range	32° to 86°F (0° to 30°C)
Storage Temperature Range	5° to 122°F (-15° to 50°C)
Relative Humidity	5% TO 95% RH (NON CONDENSING)
Operating Humidity Range	5% TO 95% RH (NON CONDENSING)
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Built-In Circuit Breaker	Yes
Cord Management	Yes
Overcurrent Protection	Yes
EMI/RFI Line Noise Protection	Yes
Flow-Through Ventilation	Yes
IP68 Rated	No
IP20 Rated	No
UV Sterilization	No
Locking	Yes
Lock Type	Key
LED Lights	No
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 62368-1 (Canada); UL 62368-1
Product Compliance	CE (Europe); REACH; RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty
CATEGORY PAGE FILTERS (Y/N ONLY)	
External Receptacle	No



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.