


32-Device USB Charging Station Cabinet with Sync for Smartphones, Wall Mount and Desktop Options, 230V, BS1363 to C13 Plug, Black

MODEL NUMBER: CSDXB32USB

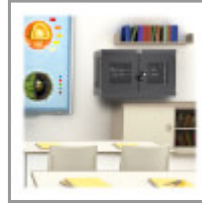

Provides 2.4A USB charging, syncing, secure storage and cord management for up to 32 smartphones or other small USB devices.

Features

Charges, Syncs, Secures and Organizes Up to 32 Smartphones and Other USB Devices

This secure phone charging station provides fast charging, convenient syncing, secure storage and cord management for up to 32 smartphones with cases up to 7 x 1 x 3.65 inches. Ideal for corporate, healthcare, industrial, commercial and retail environments, this locking steel cabinet with a black powder-coated finish keeps valuable mobile devices safe, secure and always ready to use.

Fast Charging and Convenient Syncing

The CSDXB32USB features 32 USB ports capable of delivering the fastest charging supported by each device, up to 2.4A per port. A USB uplink port connects to a host computer for wired syncing, though the CSDXB32USB also supports wireless syncing and simultaneous syncing/charging (up to 1.5A per port during wired syncing). The removable 3.7-meter (12-foot) AC input cord with BS1363-to-C13 plug reaches distant outlets to help you place the cabinet in a convenient location.

Comprehensive Protection Against Theft, Tampering, Overheating and Abrasions

The CSDXB32USB phone station locks with the included keys to help protect devices from theft, damage or tampering. A three-point locking mechanism latches doors at the top, middle and bottom. For extra security, you can replace or supplement the built-in lock with your own padlock, and rear ports accommodate an optional cable or chain lock to secure the entire unit in place. Flow-through ventilation prevents devices from overheating, and attachment points on the top and bottom of the cabinet allow mounting of cooling fans (sold separately). The protective shelf is specially coated to prevent device scratches and scuffs.

Flexible Configuration

This compact charging station ships fully assembled for quick installation on a desktop or floor in a structurally sound area or wall mounting with user-supplied tools and hardware. The split front doors open 180 degrees for improved device and service access. A USB firmware upgrade port allows future updates to support the most current smartphones.

Specifications

Highlights

- Secures up to 32 mobile devices behind locking doors to help prevent tampering
- 230V cabinet features 3.7 m cord with BS1363-to-C13 plug for reaching distant outlets
- Features attachment points for mounting cooling fans that can prevent overheating
- Supports wall mounting or desktop/floor placement in a structurally sound area
- Ships fully assembled for immediate placement in an office, classroom, etc.

Package Includes

- CSDXB32USB 32-Device USB Charging Station, Black
- Removable AC input cord with BS1363-to-C13 plug, 12 ft. (4.7 m)
- (2) Keys
- Owner's manual



Powering Business Worldwide

TRIPP LITE
SERIES

OVERVIEW	
UPC Code	037332285027
Charging Form Factor	Stationary Cabinet
Product Type	Multi-Device Charger
Charger Functions	Charge; Secure; Sync
Device Compatibility	Phone
Device Slots	32
INPUT	
Nominal Input Voltage(s) Supported	230V AC
Maximum Input Amps	5.0
Voltage Compatibility (VAC)	230
Input Frequency	50 Hz
Input Plug Type	BS1363
Input Cord Length (ft.)	12
Input Cord Length (m)	3.66
POWER	
Power Consumption (Watts)	112.00
CHARGING	
Number of Charging Ports	32
Charging Method	USB
Charging Port Type	(32) USB A (FEMALE)
Charging Ports Details	Pass through
Charging Ports / Amps	(32) 5A
Overcharge Protection	No
Charging Amps per Port	5A
PHYSICAL	
Color	Black
Material of Construction	Steel
Charging Station Form Factor	Stationary Cabinet
Unit Dimensions (hwd / in.)	14.720 x 17.950 x 23.620
Unit Weight (lbs.)	62.11
Unit Weight (kg)	28.17
Number of Shelves	2



Powering Business Worldwide

TRIPP LITE
SERIES

ENVIRONMENTAL	
Operating Temperature Range	32° to 86°F (-15° to 50°C)
Storage Temperature Range	5° to 122°F (-15° to 50°C)
Operating Humidity Range	5% TO 95% RH (NON CONDENSING)
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Built-In Circuit Breaker	Yes
Cord Management	Yes
Overcurrent Protection	Yes
EMI/RFI Line Noise Protection	Yes
Flow-Through Ventilation	Yes
IP68 Rated	No
IP20 Rated	No
UV Sterilization	No
Locking	Yes
Lock Type	Key
LED Lights	No
STANDARDS & COMPLIANCE	
Product Certifications	CAN/CSA-C22.2 No. 62368-1 (Canada); UL 62368-1
Product Compliance	CE (Europe); RoHS; UKCA
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	2-year limited warranty
CATEGORY PAGE FILTERS (Y/N ONLY)	
External Receptacle	No

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.