


## Safe-IT Heavy-Duty Rolling Cart for 37" to 70" Displays, UL Certified, Antimicrobial Protection

MODEL NUMBER: DMCS3770AMUL

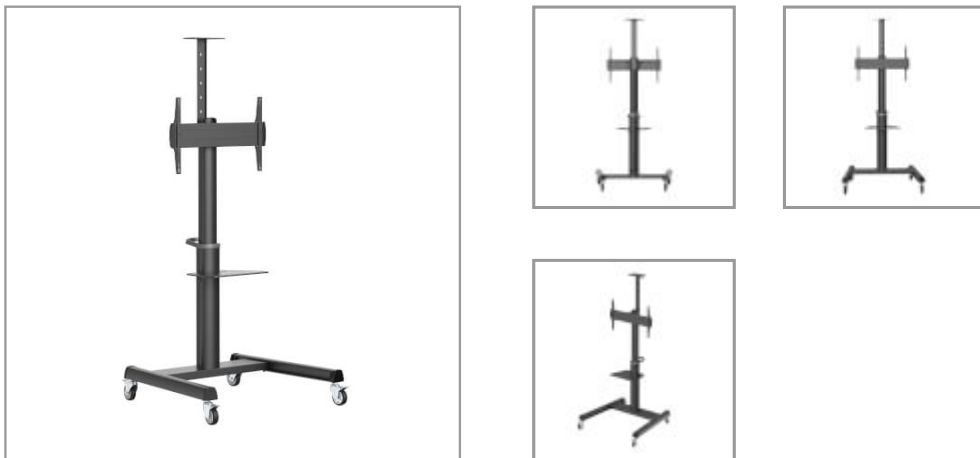

UL-certified rolling cart with antimicrobial protection lets you move your 37 to 70 in. television or monitor from one room to another.

### Features

#### Move Your Television or Interactive Whiteboard to Your Audience

This Safe-IT™ Tripp Lite rolling TV cart combines a height-adjustable display mount with the convenience of a mobile cart. Mount your television, monitor, digital whiteboard or interactive touchscreen to the all-metal unit, and then roll it safely and smoothly from room to room. The DMCS3770AMUL lets you deliver your message in corporate, education, healthcare, transportation, hospitality, retail, government and other settings requiring flexibility in a screen's location.

#### Heavy-Duty Metal Casters Take Your Message Wherever It Needs to Go

A mobile stand with three-inch swivel casters allows you to roll the DMCS3770AMUL into any office, conference room, huddle space or classroom best suited for cost-efficient resource sharing. Ease of movement allows collaborative workflow to happen in any location and maximizes usage to increase engagement, creativity and productivity. An antimicrobial handle helps you guide the cart's movement. The casters lock into place to keep the stand securely in position while at rest.

#### UL Certified for an Enhanced Sense of Safety

The DMCS3770AMUL is certified to meet UL/cUL 1678 safety standards.

#### Raise and Lower the Screen to Find the Most Comfortable Viewing Angle

The height-adjustable rolling cart fits most flat- or curved-panel displays, whiteboards and monitors from 37 to 70 inches in either portrait or landscape mode. Its durable steel frame withstands the stress of repeated adjustments and supports up to 154 pounds (70 kilograms). Raise or lower the height of the display during assembly anywhere from 49.2 to 63 inches. You can also tilt the screen to achieve the most comfortable viewing angle.

#### Antimicrobial Protection Helps Provide a Safer, Cleaner and Healthier Work Environment

The handle features antimicrobial properties that help resist the growth of bacteria, viruses, fungi, mold and mildew.

#### Conveniently Place Peripherals and Manage Cables

Adjustable shelves hold audio/video and other components, such as surge protectors, laptops, projectors, webcams and Blu-ray players. Each shelf holds up to 11 pounds (4.9 kg). Cables can be routed through the columns to keep them hidden and avoid excessive clutter.

### Highlights

- Ideal for rolling your TV or whiteboard into offices, classrooms and conference rooms
- Durable steel frame blends into any room décor and supports up to 154 lb. (70 kg.)
- 3 in. swivel casters enable smooth rolling and lock to secure the cart at rest
- Certified to meet UL/cUL 1678 safety standards for education and medical facilities
- Antimicrobial protection helps resist the growth of bacteria, viruses, fungi, mold and mildew

### System Requirements

- Flat- or curved-screen television, monitor, digital whiteboard or interactive touchscreen from 37 to 70 in.
- Supports the following VESA patterns: 200 x 200, 300 x 200, 300 x 300, 400 x 200, 400 x 300, 400 x 400 and 600 x 400

### Package Includes

- DMCS3770AMUL Heavy-Duty Rolling Cart
- Owner's manual



### VESA-Compliant Mounting Ensures Display Compatibility

VESA (Video Electronics Standards Association) promotes uniformity in the video electronics industry by developing standards for TVs and monitors. For hassle-free display compatibility, this mount supports the following VESA mounting hole patterns: 200 x 200, 300 x 200, 300 x 300, 400 x 200, 400 x 300, 400 x 400 and 600 x 400. Hardware for assembly and mounting is included.

## Specifications

OVERVIEW	
UPC Code	037332275363
Device Compatibility	Monitor/HDTV; Projector
PHYSICAL	
Color	Black
Material of Construction	Aluminum, Steel
VESA Pattern (mm)	200x200; 300x200; 300x300; 400x200; 400x300; 400x400; 600x400
Motion	Full
Mounting Location	Floor
Degrees of Motion	360° Rotate
Minimum Screen Size (in.)	37
Minimum Screen Size (cm)	93.9
Maximum Screen Size (in.)	70
Maximum Screen Size (cm)	177.8
Maximum Weight Capacity (lbs.)	154
Maximum Weight Capacity (kg)	70
Number of Displays	1
Unit Dimensions (hwd / in.)	85.25 x 40.55 x 38.84
Unit Dimensions (hwd / cm)	214 x 103 x 88.49
Unit Weight (lbs.)	58.4
Unit Weight (kg)	26.49
Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Cord Management	Yes
Tools Necessary	Yes
Security Lock	No
Casters	Yes



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	CAN/CSA C22.2; UL 1678
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>