


Triple Flat-Panel Rail Wall Mount for 10" to 15" TVs and Monitors

MODEL NUMBER: **DMR1015X3**

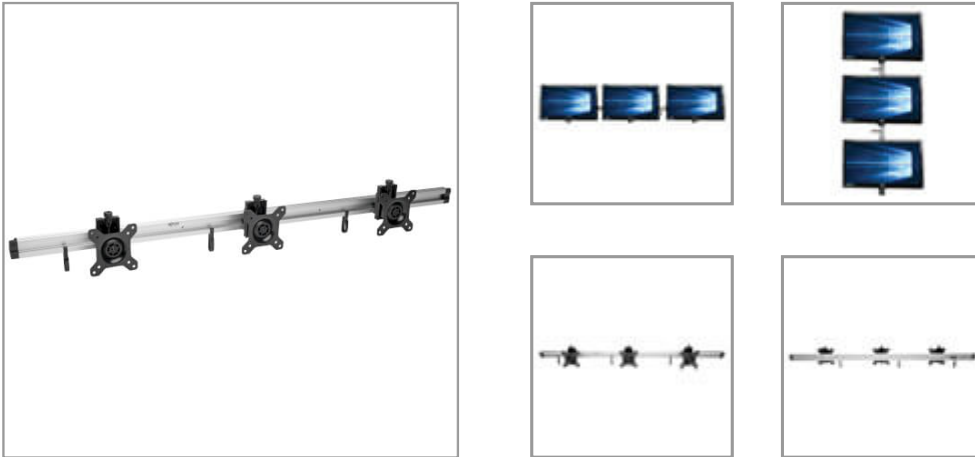

Low-profile rail mount hangs 3 flat-panel televisions, monitors or other displays on the wall. Recommended for video walls, menu boards and other applications in restaurants, bars, airports, hotels, offices and boardrooms.

Description

The VESA-compliant DMR1015X3 Triple Flat-Panel Rail Wall Mount allows you to mount three flat-panel televisions, monitors or other displays on the wall in either portrait or landscape mode. Recommended for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms, the low-profile mount fits most flat-panel displays from 10 to 15 inches.

Up to three displays attach to VESA mounts that can slide closer or further apart along the rail for optimal viewing. The rail is concealed behind the displays for a sleek, professional appearance. Included cable guides attach to the rail to keep power cords out of the way.

Durable steel construction supports up to 18 lbs (8.2 kgs) per VESA mount. Mounting hardware is included. Conforms to VESA-compliant displays with either of the following mounting hole patterns: 75 x 75 mm and 100 x 100 mm.

Features

Mounts 3 Televisions or Monitors to the Wall

- Fits most flat-panel TVs, monitors and other displays from 10 to 15 in.
- Ideal for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms
- Designed for portrait or landscape mounting

Convenient One-Touch Adjustment

- 20° swivel and -15° to +15° tilt capability provides comfortable viewing
- Full 360° rotation for viewing in portrait or landscape orientation

Innovative Rail Design

- VESA mounts adjust independently along rail
- Rail conceals behind displays for sleek, professional appearance
- Cables attach to rail to prevent tangles and clutter
- Adjustable mounting rails match up with off-center wall studs
- Wall-mounting hardware included

Highlights

- Fits most flat-panel displays from 10 to 15 in.
- Designed for portrait or landscape mounting
- VESA mounts adjust independently along rail
- Durable steel construction
- Supports up to 18 lbs (8.2 kgs) per VESA mount

Package Includes

- Wall rail
- (3) VESA mounts
- (12) M4 x 12 screws
- (12) M4 x 30 screws
- (12) Spacers
- (4) Cable guides
- (5) Anchor bolts
- (5) Concrete anchors
- (5) Washers
- Owner's manual



Powering Business Worldwide



Durable Steel Construction

- Supports up to 18 lbs (8.2 kgs) per VESA mount

VESA Compliance

- Supports the following VESA mounting hole patterns: 75 x 75 mm and 100 x 100 mm

Specifications

| OVERVIEW | |
|---------------------------------|-------------------------------------|
| UPC Code | 037332202819 |
| Device Compatibility | Monitor/HDTV |
| PHYSICAL | |
| Color | Black; Silver |
| Material of Construction | Steel |
| VESA Pattern (mm) | 75x75; 100x100 |
| Motion | Full |
| Mounting Location | Wall |
| Degrees of Motion | -15/+15 Tilt; 20 Swivel; 360 Rotate |
| Minimum Screen Size (in.) | 10 |
| Minimum Screen Size (cm) | 25.4 |
| Maximum Screen Size (in.) | 15 |
| Maximum Screen Size (cm) | 38.1 |
| Maximum Weight Capacity (lbs.) | 18 |
| Maximum Weight Capacity (kg) | 8 |
| Min/Max Arm Extension (in.) | 3 |
| Min/Max Arm Extension (cm) | 7.60 |
| Number of Displays | 3 |
| Shipping Dimensions (hwd / in.) | 5.04 x 50.98 x 2.44 |
| Shipping Dimensions (hwd / cm) | 12.80 x 129.49 x 6.20 |
| Shipping Weight (lbs.) | 7.77 |
| Shipping Weight (kg) | 3.52 |
| Unit Dimensions (hwd / in.) | 4.730 x 50.000 x 3.350 |
| Unit Dimensions (hwd / cm) | 12 x 127 x 6 |
| Unit Weight (lbs.) | 6.14 |
| Unit Weight (kg) | 2.79 |



Powering Business Worldwide



| | |
|--------------------------------------|-------------------------|
| Assembly Required | Yes |
| FEATURES & SPECIFICATIONS | |
| Antimicrobial | No |
| Cord Management | Yes |
| Tools Necessary | Yes |
| Security Lock | No |
| STANDARDS & COMPLIANCE | |
| Product Compliance | RoHS |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 5-year limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.