


Triple Flat-Panel Rail Wall Mount for 10" to 15" TVs and Monitors

MODEL NUMBER: **DMR1015X3**

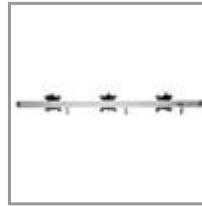

Low-profile rail mount hangs 3 flat-panel televisions, monitors or other displays on the wall.

Recommended for video walls, menu boards and other applications in restaurants, bars, airports, hotels, offices and boardrooms.

Description

The VESA-compliant DMR1015X3 Triple Flat-Panel Rail Wall Mount allows you to mount three flat-panel televisions, monitors or other displays on the wall in either portrait or landscape mode. Recommended for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms, the low-profile mount fits most flat-panel displays from 10 to 15 inches.

Up to three displays attach to VESA mounts that can slide closer or further apart along the rail for optimal viewing. The rail is concealed behind the displays for a sleek, professional appearance. Included cable guides attach to the rail to keep power cords out of the way.

Durable steel construction supports up to 18 pounds per VESA mount. Mounting hardware is included. Conforms to VESA-compliant displays with either of the following mounting hole patterns: 75 x 75 mm and 100 x 100 mm.

Features

Mounts 3 Televisions or Monitors to the Wall

- Fits most flat-panel TVs, monitors and other displays from 10 to 15 in.
- Ideal for video walls, menu boards and other display applications in restaurants, bars, airports, hotels, offices and boardrooms
- Designed for portrait or landscape mounting

Convenient One-Touch Adjustment

- 20° swivel and -15° to +15° tilt capability provides comfortable viewing

Highlights

- Fits most flat-panel displays from 10 to 15 in.
- Designed for portrait or landscape mounting
- VESA mounts adjust independently along rail
- Durable steel construction
- Supports up to 18 lb. per VESA mount

Package Includes

- Wall rail
- (3) VESA mounts
- (12) M4 x 12 screws
- (12) M4 x 30 screws
- (12) Spacers
- (4) Cable guides
- (5) Anchor bolts
- (5) Concrete anchors
- (5) Washers
- Owner's manual



- Full 360° rotation for viewing in portrait or landscape orientation

Innovative Rail Design

- VESA mounts adjust independently along rail
- Rail conceals behind displays for sleek, professional appearance
- Cables attach to rail to prevent tangles and clutter
- Adjustable mounting rails match up with off-center wall studs
- Wall-mounting hardware included

Durable Steel Construction

- Supports up to 18 lb. per VESA mount

VESA Compliance

- Supports the following VESA mounting hole patterns: 75 x 75 mm and 100 x 100 mm

Specifications

OVERVIEW	
UPC Code	037332202819
PHYSICAL	
Color	Black; Silver
Degrees of Motion	-15/+15 Tilt; 20 Swivel; 360 Rotate
Material of Construction	Steel
Maximum Screen Size (cm)	38.1
Maximum Screen Size (in.)	15
Maximum Weight Capacity (kg)	8
Maximum Weight Capacity (lbs.)	18
Min/Max Arm Extension (cm)	7.60
Min/Max Arm Extension (in.)	3
Minimum Screen Size (cm)	25.4
Minimum Screen Size (in.)	10
Motion	Full
Mounting Location	Wall
Number of Displays	3
Shipping Dimensions (hwd / cm)	12.80 x 129.49 x 6.20
Shipping Dimensions (hwd / in.)	5.04 x 50.98 x 2.44



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Shipping Weight (kg)	3.52
Shipping Weight (lbs.)	7.77
Unit Dimensions (hwd / cm)	12 x 127 x 6
Unit Dimensions (hwd / in.)	4.73 x 50 x 3.35
Unit Weight (kg)	2.79
Unit Weight (lbs.)	6.14
VESA Pattern (mm)	75x75; 100x100
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
Cord Management	Yes
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2019 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>