


# Full-Motion Smartphone and Tablet Desktop Mount, White

MODEL NUMBER: **DMTB413**

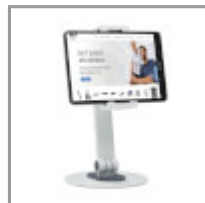

Mounts your smartphone, iPad or Galaxy tablet on a desktop or other flat surface for easy access in classrooms, home offices and retail settings.

## Features

### Rest Your Tablet or Phone Above a Desktop for Convenient Access

A handy tool for work-from-anywhere spaces, this low-profile tablet mount lets you install your mobile device above your work surface to maximize space. The large round base is well balanced to securely hold your mount and device in place. The mount with flexible ball joint tilts (-160/+210 degrees) and swivels (-52/+52 degrees) to help you find the perfect viewing angle, and it rotates 180 degrees for use in portrait or landscape mode.

### Quick to Assemble and Easy to Mount

The DMTB413 assembles in minutes using the included hardware and rests on any desktop, workbench or counter. The versatile tablet mount supports up to 2.2 pounds (1 kilogram).

### Fits Smartphones and Tablets from 4.7 to 12.9 in.

The bracket accepts most Apple, Android, Samsung or other smartphones or tablets up to 12.9 inches. In addition to your home or office work area, the DMTB413 is ideal for retail points of sale, restaurant checkouts, hotel lobbies, classrooms, showrooms and conference rooms.

## Highlights

- Versatile tablet stand fits most smartphones and tablets from 4.7 to 12.9 in.
- Secure device bracket smoothly rotates for portrait or landscape orientation
- Gracefully tilts to help you find the most comfortable viewing angle
- Large round base is ideally balanced to securely hold mount and device in place
- Easy to assemble and install in just a few minutes with the included hardware

## System Requirements

Smartphones and tablets from 4.7 to 12.9 in.

## Package Includes

- DMTB413 Desktop Smartphone and Tablet Mount
- Installation hardware
- Installation instructions

# Specifications

OVERVIEW	
UPC Code	037332278784
Device Compatibility	Tablet
PHYSICAL	
Color	White
Material of Construction	Plastic, metal
Motion	Full



Powering Business Worldwide



Mounting Location	Desktop
Degrees of Motion	-60/+210 Tilt; -52/+52 Swivel; 180 Rotate
Minimum Screen Size (in.)	4.7
Minimum Screen Size (cm)	12
Maximum Screen Size (in.)	12.9
Maximum Screen Size (cm)	32.8
Maximum Weight Capacity (lbs.)	2.2
Maximum Weight Capacity (kg)	1
Number of Displays	1
Shipping Dimensions (hwd / in.)	9.80 x 7.10 x 2.20
Shipping Dimensions (hwd / cm)	24.89 x 18.03 x 5.59
Shipping Weight (lbs.)	2.70
Shipping Weight (kg)	1.22
Unit Dimensions (hwd / in.)	13.000 x 6.300 x 6.300
Unit Dimensions (hwd / cm)	13 x 6.3 x 6.3
Unit Weight (lbs.)	2
Unit Weight (kg)	0.91
Assembly Required	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antimicrobial	No
Cord Management	No
Tools Necessary	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.