


## Swivel/Tilt Corner Wall Mount for 37" to 70" TVs and Monitors - Flat/Curved

MODEL NUMBER: **DMWC3770M**

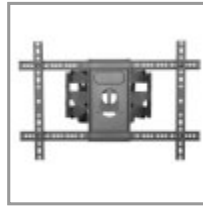

Wall mount with split wall plates supports installation of a flat-panel or curved-screen television or monitor in a corner.

### Features

**Corner Mount Your Flat-Panel or Curved-Screen TV or Monitor** Split wall plates allow the DMWC3770M to mount on both walls of a corner, providing a wide viewing angle in home theaters, classrooms, boardrooms, hotels, bars and restaurants. It's also a great display solution for rooms with limited wall space due to window placement or furniture arrangements. This true corner mount accommodates most flat-panel or curved-screen televisions or monitors from 37 to 70 inches. Maximum weight supported is 99 lbs (44.9 kgs)

**Adjust the Display Angle for Comfortable Viewing** One-touch adjustment capability makes it easy to optimize viewing angles. For maximum screen visibility, the articulating arms can swivel 90° left or right. The -8° to +5° tilt and -5° to +5° screen level adjustment help minimize glare and improve the audience's viewing experience.

**Rely on Durable All-Metal Construction with Convenient Cable Access** Made of steel with a black powder-coated finish, this full-motion wall mount withstands the stress of repeated adjustments and use in public areas. An open frame design supports easy access to cables.

**VESA Compliance Ensures Display Compatibility** VESA (Video Electronics Standards Association) promotes uniformity in the video electronics industry by developing standards, such as universal mounting hole patterns, for TVs and monitors. For hassle-free display compatibility, this corner wall mount supports the following VESA mounting hole patterns: 100 x 100, 200 x 100, 200 x 200, 200 x 300, 200 x 400, 300 x 200, 300 x 300, 300 x 400, 400 x 200, 400 x 300, 400 x 400, 500 x 200, 500 x 300, 500 x 400, 600 x 300 and 600 x 400. Mounting hardware is included.

## Specifications

### OVERVIEW

UPC Code

037332240538

### Highlights

- Accommodates most flat or curved screens from 37 to 70 in.
- Split wall plates mount on the adjacent walls of a corner
- One-touch adjustment makes it easy to change the viewing angle
- 90° swivel, -8° to +5° tilt and -5° to +5° screen adjustment maximize viewing comfort
- Supports displays up to 99 lbs (44.9 kgs)

### Applications

- Provide flexible viewing options for seating areas in home theaters
- Take advantage of unused wall space in a classroom or conference room
- Optimize viewing for more patrons in a bar or restaurant
- Mount displays in a hotel lobby without interfering with wall art

### Package Includes

- DMWC3770M corner wall mount
- Mounting fasteners
- Wrench
- Owner's manual

Device Compatibility	Monitor/HDTV
<b>PHYSICAL</b>	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	100x100; 200x100; 200x200; 200x300; 200x400; 300x200; 300x300; 300x400; 400x200; 400x300; 400x400; 500x200; 500x300; 500x400; 600x300; 600x400
Motion	Full
Mounting Location	Wall
Degrees of Motion	90 Swivel -8/+5 Level Adjustment
Minimum Screen Size (in.)	37
Maximum Screen Size (in.)	70
Maximum Weight Capacity (lbs.)	99
Maximum Weight Capacity (kg)	45
Min/Max Arm Extension (in.)	4.92 min to 20.27 max
Min/Max Arm Extension (cm)	Hasta 62 cm [24.4"] de la pared
Number of Displays	1
Shipping Dimensions (hwd / in.)	31.20 x 12.70 x 3.30
Shipping Dimensions (hwd / cm)	79.25 x 32.26 x 8.38
Shipping Weight (lbs.)	16.80
Shipping Weight (kg)	7.62
Unit Dimensions (hwd / in.)	24.400 x 25.300 x 16.500
Unit Dimensions (hwd / cm)	61.98 x 64.26 x 41.91
Unit Weight (lbs.)	13.9
Unit Weight (kg)	6.30
Assembly Required	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antimicrobial	No
Cord Management	No
Tools Necessary	Yes
Security Lock	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; RoHS3; REACH
<b>WARRANTY &amp; SUPPORT</b>	



1000 Eaton Boulevard  
Cleveland, OH 44122  
United States

Product Warranty Period (Worldwide)	5-year limited warranty
--	-------------------------



© 2023 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.