


Fixed Wall Mount for 60" to 100" TVs and Monitors, UL Certified

MODEL NUMBER: DWF60100XX

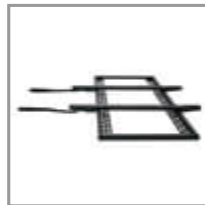

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants.

Description

The VESA-compliant DWF60100XX Fixed Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 60 to 100 inches. The low-profile mount is concealed behind the display to give a sleek, professional appearance. Frame is open for easy wall access. Display brackets with connected straps adjust to compensate for off-center wall studs. Durable all-metal frame with scratch-resistant powder-coated finish supports up to 350 lbs (158.8 kgs). Mounting hardware included. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 900 x 400 mm, 900 x 500 mm and 900 x 600 mm

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 60 to 100 in. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants
Mounts out of sight behind display for sleek, professional appearance
Mounting hardware included
Tested to accordance with UL Standard 2442

Durable Metal Construction Supports up to 350 lbs (158.8 kgs)
Open frame allows easy wall access
Adjustable display brackets with connected straps compensate for off-center wall studs
Scratch-resistant powder-coated finish

VESA Compliance Supports the following VESA mounting hole patterns: 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 900 x 400 mm, 900 x 500 mm and 900 x 600 mm

Specifications

Highlights

- Fits most flat-panel displays from 60 to 100 in.
- Hangs out of sight for a sleek, professional appearance
- Open frame for easy wall access
- Supports up to 350 lbs (158.8 kgs)

Package Includes

- Wall plate
- (2) Adapter brackets
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (8) Small spacers
- (4) Big spacers
- (6) Anchor bolts
- (6) Concrete anchors
- (6) D6 washers
- Owner's manual

| OVERVIEW | |
|--------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| UPC Code | 037332186676 |
| Device Compatibility | Monitor/HDTV |
| PHYSICAL | |
| Color | Black |
| Material of Construction | Steel |
| VESA Pattern (mm) | 200x200; 200x300; 200x400; 200x500; 300x200; 300x300; 300x400; 300x500; 300x600; 400x200; 400x300; 400x400; 400x500; 400x600; 500x200; 500x300; 500x400; 500x500; 500x600; 600x300; 600x400; 600x500; 600x600; 700x300; 700x400; 700x500; 700x600; 800x300; 800x400; 800x500; 800x600; 900x400; 900x500; 900x600 |
| Motion | Fixed |
| Mounting Location | Wall |
| Degrees of Motion | Fixed |
| Minimum Screen Size (in.) | 60 |
| Minimum Screen Size (cm) | 152.4 |
| Maximum Screen Size (in.) | 100 |
| Maximum Screen Size (cm) | 254 |
| Maximum Weight Capacity (lbs.) | 350 |
| Maximum Weight Capacity (kg) | 159 |
| Number of Displays | 1 |
| Shipping Dimensions (hwd / in.) | 1.60 x 17.32 x 49.90 |
| Shipping Dimensions (hwd / cm) | 4.06 x 43.99 x 126.75 |
| Shipping Weight (lbs.) | 13.40 |
| Shipping Weight (kg) | 6.08 |
| Unit Dimensions (hwd / in.) | 24.000 x 39.720 x 1.250 |
| Unit Dimensions (hwd / cm) | 60.7 x 100.9 x 3.18 |
| Unit Weight (lbs.) | 10.03 |
| Unit Weight (kg) | 4.55 |
| Assembly Required | Yes |
| FEATURES & SPECIFICATIONS | |
| Cord Management | No |
| Antimicrobial | No |
| Tools Necessary | Yes |
| Security Lock | No |

| STANDARDS & COMPLIANCE | |
|-------------------------------------|-------------------------|
| Product Certifications | UL 2442 |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 5-year limited warranty |