


Full-Motion TV Wall Mount with Fully Articulating Arm for 23" to 55" Flat-Screen Displays

MODEL NUMBER: DWM2355S

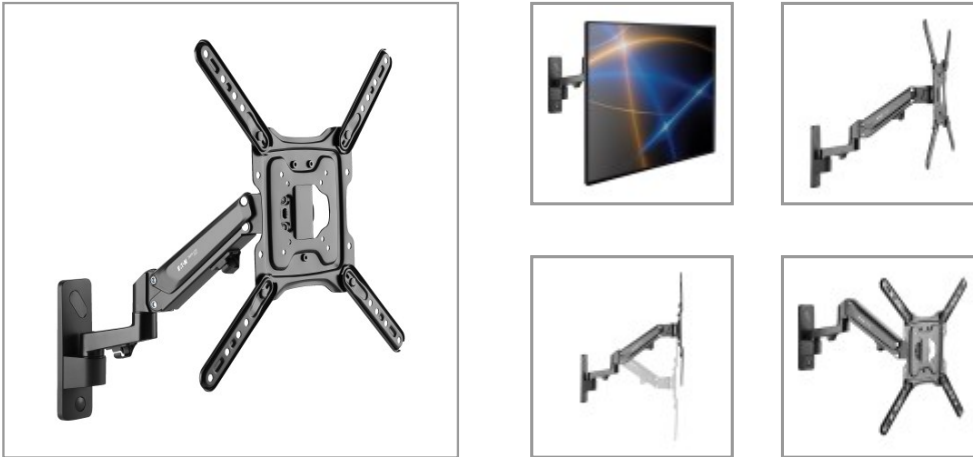

Mounts your 23 to 55 in. television to the wall of your home theater, office, restaurant or boardroom to provide optimal viewing angles.

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 23 to 55 in. Ideal for home theaters, offices, classrooms, boardrooms, hotels, bars and restaurants. Full-motion articulating arm adjusts independently for angle and height. Mounting hardware included. Mounts on wood or concrete block.

Convenient One-Touch Adjustment 180° swivel and -15° to 15° tilt capability provides comfortable viewing from multiple angles.

Durable Metal Construction Supports up to 51 lbs (23.1 kgs). Soft rubber-feel finish tolerates frequent handling and blends with any décor. Display cables tuck inside articulating arm to prevent clutter.

VESA Compliance Conforms with VESA-compliant universal mounting hole patterns.

Highlights

- TV wall mount with articulating gas-spring arm adjusts easily with just a single touch
- -15° to +5° tilt and -90° to +90° swivel helps you find the perfect angle to avoid glare
- Durable steel construction blends into any décor and supports up to 51 lbs (23.1 kgs)
- Display cables attach to arm to reduce clutter and keep cords organized
- VESA compliance ensures compatibility with most popular mounting hole patterns

Applications

- Mounting a flat-screen television or monitor in an office lobby, conference room, bar, restaurant, airport or anywhere else digital signage is desired
- Installing a TV in your home theater that can be easily adjusted to accommodate the comfort levels of the audience

System Requirements

- Flat-screen television or monitor from 23 to 55 in.

Package Includes

- Wall plate with articulating arm
- VESA plate
- (4) VESA adapter brackets
- (2) Wall plate end caps
- (4) Nuts
- (4) Bolts
- Wrench
- Hex key, 4 mm
- Hex key, 6 mm
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 30 screws
- (4) M8 x 50 screws
- (4) D5 washers
- (4) D8 washers
- (8) Small spacers
- (8) Large spacers



Powering Business Worldwide

TRIPP LITE
SERIES

- (3) Anchor bolts
- (3) Concrete anchors
- (3) Washers
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332258779
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	75x75; 100x100; 200x100; 200x200; 300x300; 400x200; 400x300; 400x400
Motion	Full
Mounting Location	Wall
Degrees of Motion	-15/+15 Tilt; 180 Swivel
Distance from Wall (in.)	12.7
Distance from Wall (cm)	32
Distance from Wall (mm)	323
Minimum Screen Size (in.)	23
Minimum Screen Size (cm)	58.4
Maximum Screen Size (in.)	55
Maximum Screen Size (cm)	139.7
Maximum Weight Capacity (lbs.)	51
Maximum Weight Capacity (kg)	23
Min/Max Arm Extension (in.)	2.83 min to 18.34 max
Min/Max Arm Extension (cm)	71.9 min to 46.6 max
Number of Displays	1
Shipping Dimensions (hwd / in.)	17.30 x 13.70 x 3.30
Shipping Dimensions (hwd / cm)	43.94 x 34.80 x 8.38
Shipping Weight (lbs.)	8.90
Shipping Weight (kg)	4.04
Unit Dimensions (hwd / in.)	17.100 x 18.100 x 17.900
Unit Dimensions (hwd / cm)	16.69 x 6.88 x 63.19



Powering Business Worldwide

TRIPP LITE
SERIES

Unit Weight (lbs.)	7.1
Unit Weight (kg)	3.22
Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	Yes
Tools Necessary	Yes
Security Lock	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; RoHS3; CE (Europe); REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.