


Tilt Wall-Mount for 32" to 70" Flat-Screen Displays

MODEL NUMBER: DWT3260X

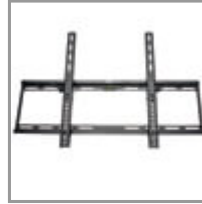

Description

Tripp Lite's VESA-compliant DWT3260X Tilt Flat-Screen Wall Mount's low-profile design features an open frame for easy wall access and optimal display positioning flexibility. With tilt adjustment for improved viewing angles in applications where the audience is located below the display, it packs a lot of functionality into an unobtrusive frame. It can also free up valuable space in your workstation by allowing you to effortlessly reposition your display at any time, even after installation. Its durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 165 lbs. and fits most 32- to 70-inch flat-panel displays. It comes with all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs. A built-in bubble level enables accurate display leveling. For peace of mind, the DWT3260X comes backed by a 5-year warranty.

Features

- Tripp Lite's VESA-compliant DWT3260X Tilt Flat-Screen Wall Mount's low-profile design features an open frame for easy wall access and optimal display positioning flexibility
- With tilt adjustment for improved viewing angles in applications where the audience is located below the display, it packs a lot of functionality into an unobtrusive frame
- It can free up valuable space in your workstation by allowing you to effortlessly reposition your display at any time, even after installation
- Durable, all-metal construction with scratch-resistant, powder-coat finish supports weights of up to 165 lb
- Fits most 32- to 70-inch flat-panel displays
- Comes with all necessary mounting hardware and features horizontal adjustment to compensate for off-center wall studs
- Built-in bubble level enables accurate display leveling
- 5-year warranty

Specifications

Highlights

- **SEE NEW MODEL - DWT3270X**
- Low-profile mounting keeps unit out of sight for sleek, professional appearance
- Fits most flat-panel displays from 32" to 70"
- Open frame for easy wall access
- Tilt adjustment improves viewing angles in applications where the audience is below the display
- Horizontal adjustment compensates for off-center wall studs
- Wide range of motion with -10° to 0° tilt capability
- Equipped with a bubble level for accurate display leveling
- Supports up to 165 lbs.
- 5-year warranty

Package Includes

- DWT3260X Tilt Flat-Screen Wall Mount
- Mounting Hardware
- Owner's Manual



OVERVIEW	
UPC Code	037332178848
PHYSICAL	
Material of Construction	Metal
Color	Black
VESA Pattern (mm)	600x400
Motion	Tilt
Mounting Location	Wall
Degrees of Motion	-10/+0 Tilt
Distance from Wall (in.)	1.77
Distance from Wall (cm)	5
Distance from Wall (mm)	45
Maximum Weight Capacity (lbs.)	165
Maximum Weight Capacity (kg)	75
Shipping Dimensions (hwd / cm)	5.51 x 21.49 x 69.01
Shipping Dimensions (hwd / in.)	2.17 x 8.46 x 27.17
Shipping Weight (kg)	2.69
Shipping Weight (lbs.)	5.94
Unit Weight (lbs.)	5.94
Unit Weight (kg)	2.69
FEATURES & SPECIFICATIONS	
Cord Management	No
Tools Necessary	Yes
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty
Product Warranty Period (U.S. & Canada)	5-year limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>