


Tilt Wall Mount for 60" to 100" TVs and Monitors, UL Certified

MODEL NUMBER: DWT60100XX

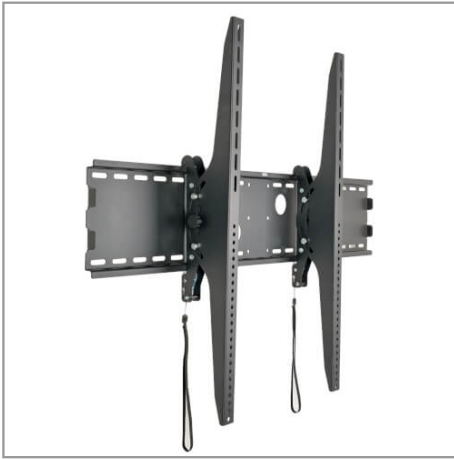

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Tilts to provide optimal viewing angles.

Description

The VESA-compliant DWT60100XX Tilt Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 60 to 100 inches. A -15° to +15° tilt capability minimizes glare and provides comfortable viewing from multiple angles.

Low-profile mount is concealed behind the display to give a sleek, professional appearance. Display brackets with connected straps adjust to compensate for off-center wall studs. Durable all-metal frame with scratch-resistant powder-coated finish supports up to 350 pounds. Mounting hardware included. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 100 x 100 mm, 100 x 200 mm, 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 300 x 700 mm, 300 x 800 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 400 x 700 mm, 400 x 800 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 500 x 600 mm, 500 x 700 mm, 500 x 800 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 600 x 700 mm, 600 x 800 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 700 x 700 mm, 700 x 800 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 800 x 700 mm, 800 x 800 mm, 900 x 400 mm, 900 x 500 mm, 900 x 600 mm, 900 x 700 mm, 900 x 800 mm, 1000 x 400 mm, 1000 x 500 mm, 1000 x 600 mm, 1000 x 700 mm and 1000 x 800 mm

Features

Mounts Your TV or Monitor to the WallFits most flat-panel televisions, monitors and other displays from 60 to 100 in.Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurantsMounts out of sight behind display for sleek, professional appearanceMounting hardware includedTested in accordance with UL Standard 2442

Convenient One-Touch Adjustment-15° to +15° tilt capability provides comfortable viewing from multiple anglesImproves viewing angles in applications where audience is below the display

Durable Metal ConstructionSupports up to 350 lb.Adjustable display brackets with connected straps compensate for off-center wall studsScratch-resistant powder-coated finish

VESA ComplianceSupports the following VESA mounting hole patterns: 100 x 100 mm, 100 x 200 mm, 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 300 x 700 mm, 300 x 800 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 400 x 700 mm, 400 x 800 mm, 500 x 200 mm,

Highlights

- Fits most flat-panel displays from 60 to 100 in.
- Hangs out of sight for a sleek, professional appearance
- -15° to +15° tilt capability for wide range of motion
- Supports up to 350 lb.

Package Includes

- Wall plate
- Mounting template
- (2) Adapter brackets
- (2) Tilt adjusting knobs
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (8) Small spacers
- (4) Big spacers
- (6) Anchor bolts
- (6) Concrete anchors
- (6) D6 washers
- Owner's manual



500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 500 x 600 mm, 500 x 700 mm, 500 x 800 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 600 x 700 mm, 600 x 800 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 700 x 700 mm, 700 x 800 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 800 x 700 mm, 800 x 800 mm, 900 x 400 mm, 900 x 500 mm, 900 x 600 mm, 900 x 700 mm, 900 x 800 mm, 1000 x 400 mm, 1000 x 500 mm, 1000 x 600 mm, 1000 x 700 mm and 1000 x 800 mm

Specifications

OVERVIEW	
UPC Code	037332186683
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
Degrees of Motion	-15/+15 Tilt
Material of Construction	Steel
Maximum Screen Size (cm)	254
Maximum Screen Size (in.)	100
Maximum Weight Capacity (kg)	159
Maximum Weight Capacity (lbs.)	350
Minimum Screen Size (cm)	152.4
Minimum Screen Size (in.)	60
Motion	Tilt
Mounting Location	Wall
Number of Displays	1
Shipping Dimensions (hwd / cm)	6.86 x 23.37 x 118.36
Shipping Dimensions (hwd / in.)	2.70 x 9.20 x 46.60
Shipping Weight (kg)	9.71
Shipping Weight (lbs.)	21.40
Unit Dimensions (hwd / cm)	83.2 x 113.0 x 113.0
Unit Dimensions (hwd / in.)	32.76 x 44.88 x 5.12
Unit Weight (kg)	7.87
Unit Weight (lbs.)	17.36
VESA Pattern (mm)	1000x400; 1000x500; 1000x600; 1000x700; 1000x800; 100x100; 100x200; 200x100; 200x200; 200x300; 200x400; 200x500; 300x200; 300x300; 300x400; 300x500; 300x600; 300x700; 300x800; 400x200; 400x300; 400x400; 400x500; 400x600; 400x700; 400x800; 500x200; 500x300; 500x400; 500x500; 500x600; 500x700; 500x800; 600x300; 600x400; 600x500; 600x600; 600x700; 600x800; 700x300; 700x400; 700x500; 700x600; 700x700; 700x800; 800x300; 800x400; 800x500; 800x600; 800x700; 800x800; 900x400; 900x500; 900x600; 900x700; 900x800



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No
STANDARDS & COMPLIANCE	
Approvals	RoHS3, REACH
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>