


## Easy Pull Type-A Connectors - M/M set of VGA, 3.5mm, RCA Audio, Composite Video

MODEL NUMBER: **EZA-VGACSAM-2**

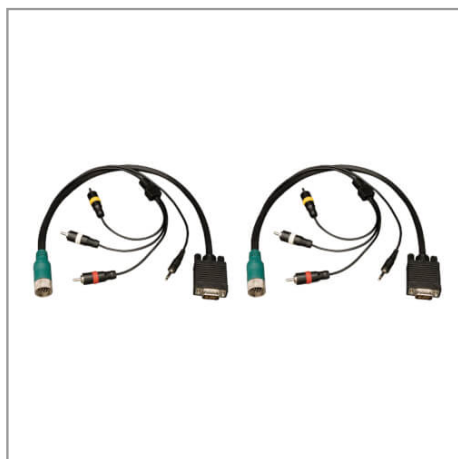

### Highlights

- SVGA / 3.5mm / Red-White RCA Audio / Composite Video, Male to Male
- Versatile trunk cable allows for a variety of connection options
- High quality RGB style VGA cable supports resolutions up to 1600 x 1200

### Package Includes

- 2 x HD15/3.5mm/Red White RCA Audio/Composite Video, All Male Plugs

### Description

Easy Pull Connector Kit includes: 2 x HD15 Male, 2 x stereo 3.5mm Plug, 4 x RCA Red/White Audio plugs, and 2 x Yellow Composite Video plugs, 1 ft. pigtails. Video support up to 1600 x 1200. Use with either PVC or Plenum Easy Pull trunk cables.

### Features

- Easy Pull, SVGA / 3.5mm / Red-White RCA Audio / Composite Video, Male to Male
- Eliminates the need to field terminate VGA connectors
- Allows cable to be run according to code - inside conduit, drop ceilings, etc.
- Makes pulling long cables fast and easy
- Trunk cables available in 35 ft., 50 ft. and 100 ft. lengths, PVC or Plenum rated jackets
- Support resolutions up to 1600 x 1200

## Specifications

OVERVIEW	
UPC Code	037332153791
Technology	Composite; Stereo Audio; VGA/SVGA
CONNECTIONS	
Side A - Connector 1	HD15 (MALE)
Side A - Connector 2	3.5MM (MALE)
Side A - Connector 3	DIN 14 PIN (MALE)
Side B - Connector 1	HD15 (MALE)
Side B - Connector 2	3.5MM (MALE)

Side B - Connector 3	DIN 14 PIN (MALE)
Latching or Gripping Connector	No
PHYSICAL	
Color	Black; Green
Cable Length (ft.)	1.5
Cable Length (m)	0.46
Shipping Dimensions (hwd / in.)	0.25 x 8.60 x 11.00
Shipping Dimensions (hwd / cm)	0.64 x 21.84 x 27.94
Shipping Weight (lbs.)	0.30
Shipping Weight (kg)	0.14
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.