


# USB-A to Right-Angle Lightning Sync/Charge Cable, MFi Certified - White, M/M, USB 2.0, 6 ft. (1.83 m)

MODEL NUMBER: M100-006-LRA-WH

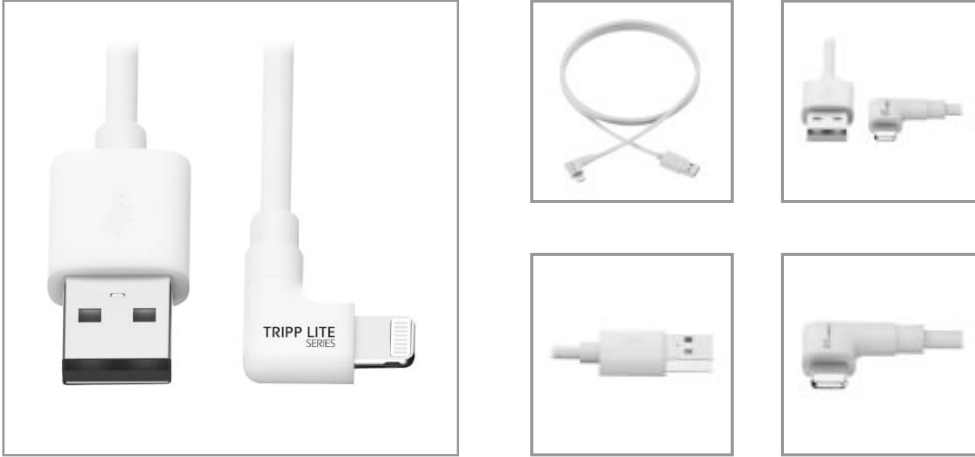

This USB Type-A to Lightning cable connects your 8-pin iPhone, iPad or iPod device to the USB port on your computer or wall charger.

## Features

**Effortlessly Sync and Charge Your Apple Devices** This USB to Lightning cable lets you connect your iPhone, iPad, or iPod to sync your device with your media library and charge it. Portable and convenient, you can easily take this cable anywhere. Keep one handy in your car, your bag, briefcase and anywhere else a charger will come handy.

**MFi-Certified for Broad Device Compatibility** The six-foot Lightning cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices. The USB-A plug connects to any computer or wall charger with a USB port.

**Reversible Lightning Connector Right Angle Plugs in Either Direction** The fumble-free reversible Lightning plug connects in either direction and the angled connector provides a natural fit for ports in hard-to-reach locations. The six-foot cord lets you easily connect to a USB port on most computers.

## Specifications

OVERVIEW	
UPC Code	037332222060
Technology	Lightning; USB 2.0 (High Speed)
Cable Type	Passive
INPUT	
Maximum Input Amps	2
POWER	

## Highlights

- Syncs and charges your iPhone, iPad or iPod device quickly and easily
- Connects to USB-A port on computer or wall charger
- Angled Lightning connector is ideal for tight spaces
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- Reversible Lightning connector plugs into your Apple device in either direction

## Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-A port on your computer or a wall charger up to 6 ft. away
- Transfer photos and other important files between an external hard drive and your Apple device

## System Requirements

- Computer, laptop or charger with USB-A port
- Most current iPhone, iPad and iPod devices

## Package Includes

M100-006-LRA-WH Right-Angle Lightning Cable, USB Type A To Lightning, 6 ft.



Powering Business Worldwide

TRIPP LITE  
SERIES

USB Power Delivery (PD) Charging Support	No
<b>CONNECTIONS</b>	
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	LIGHTNING (MALE) - RIGHT ANGLE
Connector Plating	Nickel
Contact Plating	Gold
Connector Style	Angled
<b>CHARGING</b>	
Total Charging Watts	12
<b>PHYSICAL</b>	
Material of Construction	PVC
Cable Jacket Color	White
Cable Jacket Material	PVC
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	3.2mm
Wire Gauge (AWG)	28/21
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Shipping Dimensions (hwd / in.)	0.91 x 5.20 x 2.60
Shipping Weight (lbs.)	0.10
Shipping Weight (kg)	0.05
Unit Dimensions (hwd / in.)	0.910 x 5.200 x 2.600
Unit Packaging Type	Box
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	-4° to 140°F (-20° to 60°C)
Storage Temperature Range	-4° to 176°F (-20° to 80°C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	12W (5V/2.4A)
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Specification	USB 2.0 (up to 480 Mbps)



Powering Business Worldwide

TRIPP LITE  
SERIES

Data Transfer Rate	480 Mbps
Angled Plug	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	MFi
Product Compliance	RoHS; REACH; UKCA
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	2-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.