


USB-A to Lightning Sync/Charge Cable, MFi Certified - White, M/M, USB 2.0, 10 ft. (3.05 m)

MODEL NUMBER: M100-010-WH

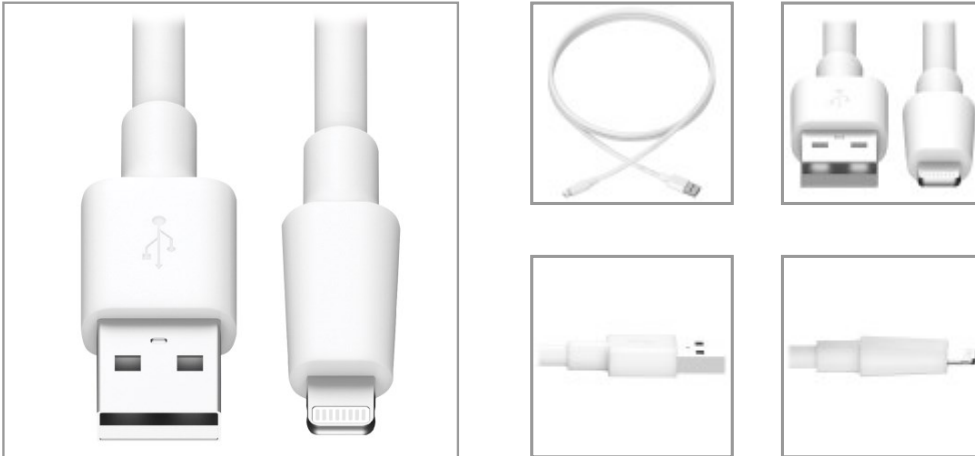

This USB Type-A to Lightning cable connects your iPhone, iPad or iPod device to the USB port on your computer or wall/car charger

Features

The M100-010-WH USB Sync/Charge Cable connects your latest generation iPhone, iPad or iPod to the USB port on any computer, so you can charge your Apple device and transfer data over long distances. The 10-ft. (3.05 m) cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices. Reversible 8-pin Lightning connector plugs into your Apple device in either direction.

Highlights

- Features a reversible 8-pin Lightning plug and a USB-A plug
- Works with any computer
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- Compatible with all devices with 8-pin connectors
- Plugs into Apple device in either direction

Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-A port on your computer or a wall charger up to 10-ft. (3.05 m) away
- Transfer photos and other important files between an external hard drive and your Apple device

System Requirements

- Device or charger with USB-A port
- iPhone, iPad, iPad mini, iPad mini 2, iPad mini 3, iPad mini 4, iPad Air, iPad Air 2, iPad Pro 12.9 inch, iPad Pro 10.5 inch, iPad Pro 9.7 inch and iPod Touch devices with Lightning port

Package Includes

- M100-010-WH USB Sync/Charge Cable with Apple Lightning Connector



Specifications

OVERVIEW	
UPC Code	037332189769
Technology	Lightning; USB; USB 2.0 (High Speed)
PHYSICAL	
Color	White
Cable Outer Diameter (OD)	3.7mm
Cable Jacket Material	PVC
Wire Gauge (AWG)	25/19
Cable Length (ft.)	10
Cable Length (m)	3
Cable Length (in.)	120
Material of Construction	PVC
Shipping Dimensions (hwd / cm)	14.48 x 3.05 x 7.62
Shipping Dimensions (hwd / in.)	5.70 x 1.20 x 3.00
Shipping Weight (kg)	0.09
Shipping Weight (lbs.)	0.20
ENVIRONMENTAL	
Operating Temperature Range	-4 to 140 F (-20 to 60 C)
Storage Temperature Range	-4 to 176 F (-20 to 80 C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	12W (5V/2.4A)
CONNECTIONS	
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	LIGHTNING (MALE)
Connector Plating	Nickel
Contact Plating	Gold
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

STANDARDS & COMPLIANCE	
Certifications	RoHS, CA65, REACH, MFi
WARRANTY	
Product Warranty Period (Worldwide)	2-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>