


Single-Gang Surface Mounting Box, UK Style, 86 x 86 x 47 mm, White

MODEL NUMBER: **N042U-MB1**

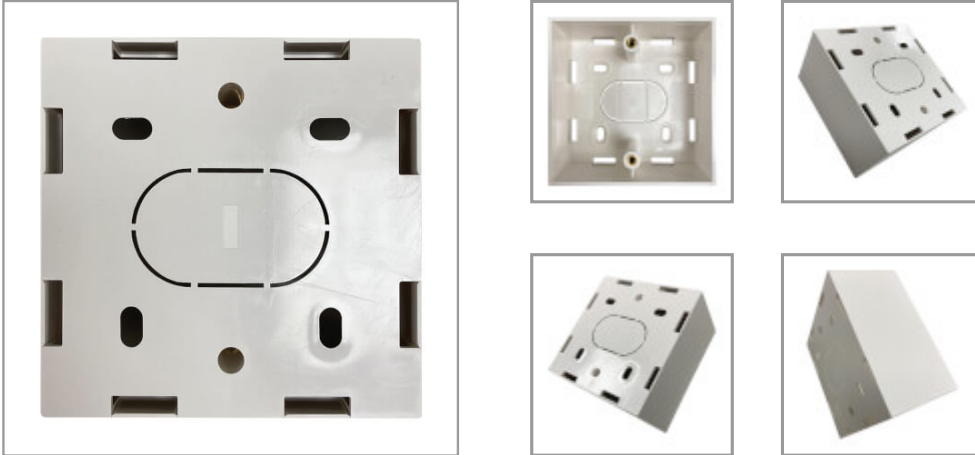

Works with a compatible wall plate to complete in-wall audio/video, voice and Ethernet connections using any type of keystone jack.

Features

UK-Style Back Box Connects Audio/Video, Voice and Data Cable Lines in Your Network

This single-gang box combines with a compatible wall plate (sold separately) to complete a premise wiring application, such as home theater (audio/video), VoIP phone (voice) or Ethernet (data) network.

High-Impact Construction Designed to Blend In Seamlessly with Your Room

This durable white mounting box blends elegantly into any home or office décor for a sleek, professional installation. Mounting screws are included. The ABS plastic construction meets UL 94V-0 flame-retardant standards for protection against fire and high heat.

Compatible with U.K. Applications

The N042U-MB1 is designed to work with standard single-gang wall plates measuring 86 x 86 millimeters. Compatible models include N042U-WK1-S, N042U-WK2-S, N042U-WK1-SA, N042U-WK2-SA, N042U-W01-ST, N042U-W02-ST, N042U-W01-S, N042U-W02-S, N042U-W04-S, N042U-WF1-1 and N042U-WF1-6C.

Highlights

- Ideal for completing home theater, VoIP or Ethernet wiring installations
- High-impact plastic construction designed to blend in with your home/office décor

Package Includes

- N042U-MB1 Single-Gang UK-Style Mounting Box, White
- (2) Mounting screws

Specifications

| OVERVIEW | |
|----------------|--|
| UPC Code | 037332269355 |
| Accessory Type | Wall Plate |
| Technology | Cat5/5e; Cat6; Cat6a; USB 2.0 (High Speed); HDBaseT; HDMI; DisplayPort |
| Country/Region | UK |
| PHYSICAL | |
| Color | White |



Powering Business Worldwide



| | |
|--------------------------------------|---|
| Material of Construction | ABS |
| Total Number of Ports | 0 |
| Unit Dimensions (hwd / in.) | 3.390 x 3.390 x 1.850 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 14° to 140°F (-10° to 60°C) |
| Storage Temperature Range | -40° to 154°F (-40° to 68°C) |
| Operating Humidity Range | 10% to 90% RH, (Non-Condensing) |
| Storage Humidity Range | 10% to 90% RH, (Non-Condensing) |
| FEATURES & SPECIFICATIONS | |
| Antibacterial | No |
| STANDARDS & COMPLIANCE | |
| Product Certifications | UL 94; UL Listed; cUL Listed |
| Product Compliance | RoHS; REACH; Trade Agreements Act (TAA) |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.