


48-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel, RJ45 Ethernet, USB, HDMI, Cat5e/6

MODEL NUMBER: N062-048-KJ

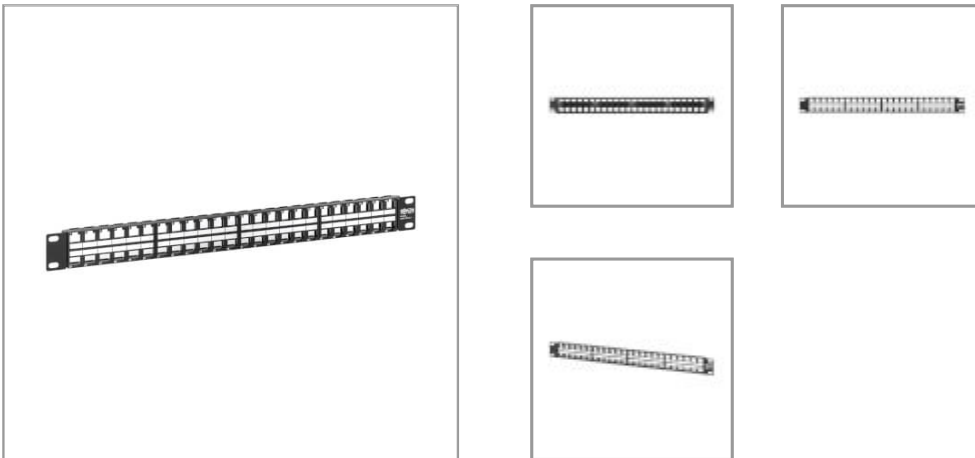

Manages and organizes network cables in a variety of applications, including audio/video, voice, Ethernet and USB.

Features

Manages and Organizes up to 48 Network Connections

This 1U unshielded patch panel features 48 blank cutouts that accommodate any type of keystone jack, including RJ45 Ethernet, HDMI audio/video, voice and USB. Each port is clearly numbered to help you identify connections.

Quick and Easy to Install in Your Rack

Made from long-lasting cold-rolled steel, the N062-048-KJ patch panel mounts easily in 1U of an EIA-standard 19-inch 2-post rack.

Highlights

- 48 blank cutouts compatible with all keystone jacks, including RJ45 and HDMI
- Ideal for Ethernet, voice, audio/video and USB applications for home or office
- Numbered ports allow easy identification of jacks and cabling
- Heavy-duty cold-rolled steel construction designed for long life
- Mounts easily into 1U of space in an EIA-standard 19 in. 2-post rack

Package Includes

- N062-048-KJ 48-Port 1U Rack-Mount Unshielded Blank Keystone/Multimedia Patch Panel
- (x25) Cable Ties
- Quick Start Guide

Specifications

OVERVIEW	
UPC Code	037332276858
Product Type	Blank
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDMI; USB 2.0 (High Speed)
Firmware / Software Docs	
Offset Ports	No
PHYSICAL	
Color	Black

Material of Construction	Rear Panel: SPCC; Frame: ABS + PC
Rack Height	1U
Shipping Dimensions (hwd / in.)	2.80 x 4.00 x 22.10
Shipping Weight (lbs.)	1.20
Unit Dimensions (hwd / in.)	1.740 x 19.000 x 0.500
ENVIRONMENTAL	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 158°F (-40° to 70°C)
Operating Humidity Range	10% to 90% RH, Non-Condensing
Storage Humidity Range	10% to 90% RH, Non-Condensing
CONNECTIONS	
Number of Ports	48
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
FEATURES & SPECIFICATIONS	
Numbered Ports	Yes
EIA/TIA 2/32 Spacing	No
Down-Angled Ports	No
Panel Applications	Audio/Video; Ethernet; USB; Voice
STANDARDS & COMPLIANCE	
Product Compliance	CE (Europe); REACH; RoHS; UKCA; Trade Agreements Act (TAA)
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty