


# Double-Gang Surface-Mount Back Box, White, TAA

MODEL NUMBER: **N080-SMB2-WH**

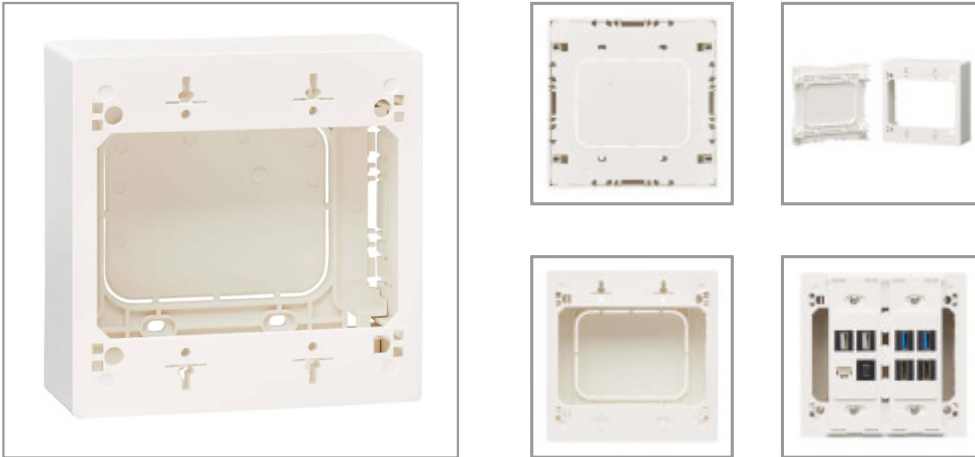

Deep double-gang junction box mounts a wall plate to complete multiple audio/video, voice and/or Ethernet in-wall connections.

## Features

**Double-Gang Surface-Mount Junction Box for Premise Applications**The N080-SMB2-WH is ideal for mounting a double-gang wall plate to complete multiple audio/video, voice and Ethernet in-wall connections using any type of keystone jack, including Cat5e/6/6a, USB, HDMI, DisplayPort and RCA. Designed to work with mid-sized and standard double-gang wall plates, this back box is two inches deep.

**Raceway Cutouts on Each Side for Easy Access**The N080-SMB2-WH features raceway cutouts in three different sizes (1 inch, 1.25 inches and 1.75 inches in diameter) on each side, as well as a rectangular knockout on the back. The cover snaps securely to the base with no screws required.

**Highly Adaptable to Match Your Specific Requirements**Made from robust ABS thermoplastic, the N080-SMB2-WH is colored white to blend elegantly into any home or office decor for a sleek, professional installation. Four mounting screws are included.

**TAA-Compliant for GSA Schedule Purchases**The N080-SMB2-WH is compliant with the Federal Trade Agreements Act (TAA), which makes it eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.

## Specifications

OVERVIEW	
UPC Code	037332236272
Accessory Type	Wall Plate
Technology	Cat5/5e; Cat6; Cat6a; USB 2.0 (High Speed); HDBaseT; HDMI; DisplayPort
Country/Region	Global
CONNECTIONS	

## Highlights

- Mid-sized back box accommodates any mid-sized or standard double-gang wall plate
- High-impact ABS thermoplastic construction designed to last a long time
- Classic white color blends elegantly into your home or office décor
- Raceway cutouts in 3 different sizes at each panel allow bulk cabling
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

## Applications

- Complete multiple in-wall audio/video, voice and/or Ethernet cable lines simultaneously

## Package Includes

- N080-SMB2-WH Double-Gang Surface-Mount Junction Box
- (4) #6-20 wood screws
- (4) 2-sided adhesive strips



Powering Business Worldwide

TRIPP LITE  
SERIES

Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
<b>PHYSICAL</b>	
Color	White
Total Number of Ports	0
Shipping Dimensions (hwd / in.)	12.00 x 10.00 x 0.50
Shipping Dimensions (hwd / cm)	30.48 x 25.40 x 1.27
Shipping Weight (lbs.)	0.39
Shipping Weight (kg)	0.18
Unit Dimensions (hwd / in.)	5.060 x 5.080 x 2.130
Unit Dimensions (hwd / cm)	128 x 8 x 5
Unit Weight (lbs.)	0.27
Unit Weight (kg)	0.12
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14° to 140°F (-10° to 60°C)
Storage Temperature Range	-40° to 154°F (-40° to 68°C)
Relative Humidity	10% to 90% RH
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antibacterial	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	Trade Agreements Act (TAA)
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://triplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.