


# Cat6 RJ45 Modular Plug for Round Stranded UTP Conductor 4-Pair, 100 Pack

MODEL NUMBER: N230-100-STR

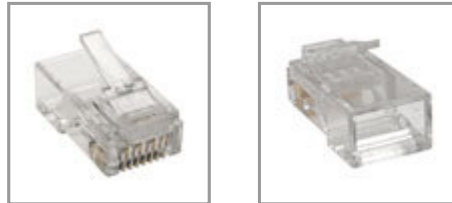

Clear RJ45 connector terminates Cat6 round stranded conductor cabling in data and voice applications.

## Description

The N230-100-STR contains 100 unshielded RJ45 modular plugs for round stranded UTP conductor 4-pair Cat6 cable. Recommended for creating your own custom-length Cat6 cable runs, these clear connectors come in a shatterproof plastic jar that's easy to pack in your toolbox and carry to your next installation.

Ideal for data and voice applications, these reliable RJ45 connectors are designed to terminate round Cat6 cable, such as N220-Series patch cabling. Their 15-micron gold-plated contacts ensure reliable signal transmission throughout the cable run, and their staggered nose pattern reduces near-end crosstalk. They are compatible with most RJ45 crimping tools (with AMP an exception).

## Features

### RJ45 Cat6 Connectors for Creating a Custom-Length Cat6 Cable

- 100 Cat6 RJ45 modular plugs in an easy-to-pack jar
- Ideal for data and voice applications
- Designed for terminating Cat6 round stranded UTP conductor 4-pair cable, such as N220-Series

### 15m Gold-Plated Contacts for Premium Data Transfer

- Reliable signal transmission ensured throughout cable run
- Reduces near-end crosstalk (NEXT) with staggered nose pattern
- Works with most RJ45 crimping tools (excluding AMP)

## Specifications

OVERVIEW	
UPC Code	037332206077
Product Type	RJ45 Plug
Technology	Cat6

## Highlights

- 100 Cat6 RJ45 plugs in an easy-to-carry, easy-to-pack plastic jar
- Works with most RJ45 crimping tools (excluding AMP)
- Premium data transfer through 15m gold-plated contacts
- Reduces near-end crosstalk (NEXT) with staggered nose pattern
- For use with Cat6 round stranded UTP conductor 4-pair cable

## Applications

- Creating custom-length cables with Cat6 cable ends for use in data and voice applications

## Package Includes

- (100) Cat6 RJ45 Modular Plugs



Powering Business Worldwide



CONNECTIONS	
Side A - Connector 1	RJ45 (MALE)
Side B - Connector 1	RJ45 (MALE)
PHYSICAL	
Shipping Dimensions (hwd / in.)	2.62 x 4.40 x 2.40
Shipping Dimensions (hwd / cm)	6.65 x 11.18 x 6.10
Shipping Weight (lbs.)	0.40
Shipping Weight (kg)	0.18
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
ENVIRONMENTAL	
Operating Temperature Range	-40° to 158°F (-40° to 70°C)
Storage Temperature Range	-40° to 158°F (-40° to 70°C)
Relative Humidity	10% to 90% RH, Non-Condensing
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.