


## 24-Port 1U Rack-Mount Cat6a/Cat6/Cat5e 110 Punchdown, RJ45, TAA

MODEL NUMBER: N252-024-6A

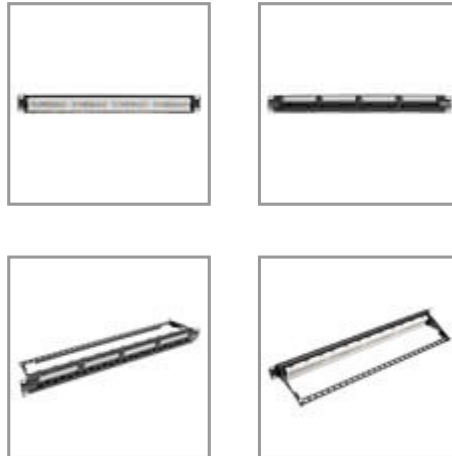

24-port Cat6a patch panel manages and organizes Cat6a input and output cable connections in your high-density 10 Gbps Ethernet network. 110 punchdown termination required.

### Description

The N252-024-6A 24-Port 1U Rack-Mount Cat6a/Cat6/Cat5e 110 Patch Panel meets or exceeds Cat6a specifications and works with T568A and T568B wiring to comply with industry standards. Fully rated for 10 Gbps Ethernet data transfer speeds, this low-profile rack-mount patch panel manages and organizes the cabling in your high-density network.

110 punchdown termination is required. The detachable cable management bar keeps patch cables neat, tidy and efficiently organized on the back of the panel. Ports are clearly numbered and labeled to help you identify connections. The 24-port Cat6 patch panel mounts easily into 1U of an EIA-standard 19-inch rack. Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases.

IEC 60512-99-002 Compliant  
PoE Certificate Number: 2019-248  
110/Krone Dual IDC  
UTP Cat6a 22-24 AWG solid cable (Requires PoE cable if used in PoE setting)

### Features

#### Rack-Mount Patch Panel Manages and Organizes High-Density Network Cabling

- Meets or exceeds Cat6a specifications
- Fully rated for 10 GbE data transfer speeds
- UL approved

#### 110 Punchdown Termination Required

- Works with T568A and T568B wiring to comply with industry standards
- Ports are numbered and labeled for easy connection identification

### Highlights

- Meets or exceeds Cat6a specifications
- 24 RJ45 ports numbered and labeled for easy ID
- Cable management bar keeps patch cables organized
- Fully rated for 10 GbE data transfer speeds
- Mounts into 1U of EIA-standard 19 in. racks

### Package Includes

- N252-024-6A 24-Port 1U Rack-Mount Cat6a/Cat6/Cat5e 110 Patch Panel
- Detachable cable management bar
- (8) Cable ties
- ID label
- Owner's manual



#### Cable Management Bar on Rear

- Detachable bar keeps patch cables neat, tidy and organized

#### Quick, Easy Installation

- Mounts into 1U of EIA-standard 19 in. racks

#### TAA-Compliant for GSA Schedule Purchases

- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule Purchases

## Specifications

OVERVIEW	
UPC Code	037332205636
Technology	Cat5/5e; Cat6; Cat6a
PHYSICAL	
Cable Management	Bar
Color	Black
CONNECTIONS	
Ports	24
Side A - Connector 1	110 IDC
Side B - Connector 1	RJ45 (FEMALE)
PoE Power Budget (Watts)	90
PoE Type	Type 3 PoE++/UPoE (60W, IEEE 802.3bt)
STANDARDS & COMPLIANCE	
Certifications	RoHS
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>