


Cat6a 10G Certified Snagless UTP Ethernet Cable (RJ45 M/M), Aqua, 7 ft.

MODEL NUMBER: N261-007-AQ

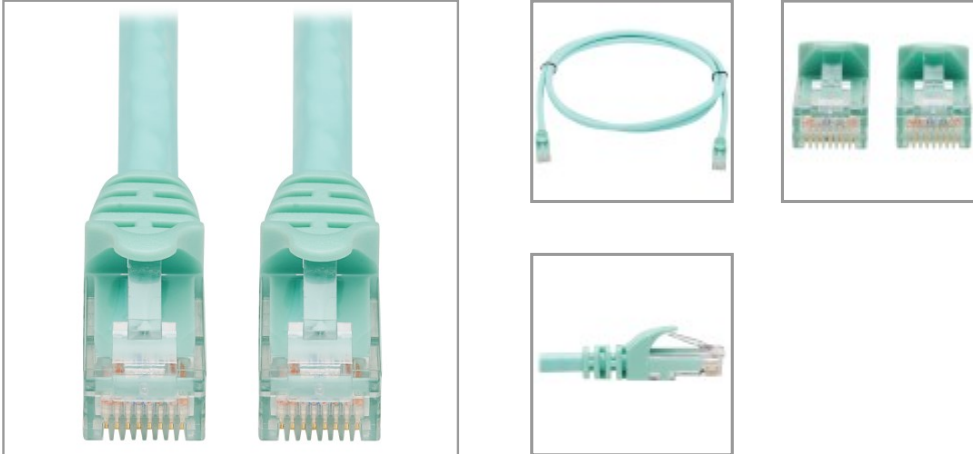

Highlights

- Next Generation Cat6 - CAT6a (Augmented)
- 10Gbps Over Copper to 100mtr
- Each cable Fluke® Tested and Verified
- 7 ft. cable

Package Includes

- 7ft Cat6a Aqua Patch Cable

Description

Tripp Lite introduces its 10Gig Cat6a Augmented Aqua Patch cables. Cat6a is the next generation of UTP Ethernet, allowing 10Gbps over 4-pair copper, up to 100 meters. The aqua blue color signifies that it is part of the 10Gig cabling family, along with our Aqua 10Gig Fiber Patch Cables. Each Cat6a cable is individually tested and certified on Fluke® test equipment. Snag-free strain relief boot provides the most secure and accurate connections.

Features

- 7ft 10Gig over copper patch cable
- 100% FLUKE® tested and certified
- ETL/UL Verified
- Supports IEEE 802.3af and is DTE power compliant
- Backward compatible with all previous 10BaseT generations
- New Cat6 RJ45 plug improves NEXT performance to 650Mhz
- 24ga, 4pr, Stranded PVC cable
- Compatible with T568A and T568B wiring
- Easy disconnect snagless hood
- PoE rated to four times the standard

Specifications

| OVERVIEW | |
|----------|--------------|
| UPC Code | 037332131713 |



| | |
|-------------------------------------|---------------------------|
| Technology | Cat6a |
| INPUT | |
| Cable Length (ft.) | 7 |
| Cable Length (m) | 2.1 |
| Cable Length (in.) | 84 |
| Cable Length (cm) | 213.4 |
| PHYSICAL | |
| Cable Shielding | UTP |
| Color | Aqua |
| Shipping Dimensions (hwd / cm) | 22.86 x 17.78 x 1.27 |
| Shipping Dimensions (hwd / in.) | 9.00 x 7.00 x 0.50 |
| Shipping Weight (kg) | 0.09 |
| Shipping Weight (lbs.) | 0.20 |
| Snagless Connector | Yes |
| Wire Type | Stranded |
| COMMUNICATIONS | |
| Network Speed | 10Gbps |
| CONNECTIONS | |
| Side A - Connector 1 | RJ45 (MALE) |
| Side B - Connector 1 | RJ45 (MALE) |
| STANDARDS & COMPLIANCE | |
| Certifications | RoHS |
| WARRANTY | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.triplite.com/products/product-certification-agencies>