


T1 Shielded RJ48C Crossover Cable (RJ45 M/M), 10 ft. (3.05 m) TAA

MODEL NUMBER: **N266-010**

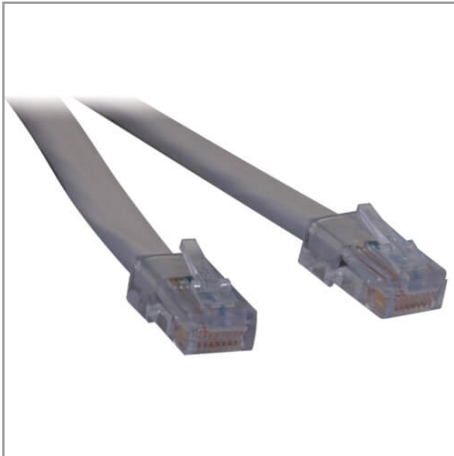

Highlights

- 22AWG, 100ohm T1 Rated Cross-over Cable
- Connects your T1 CSU/DSU
- Meets ANSI T1.403 Cabling Requirement
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Package Includes

10-ft. (3.05 m) T1 Cross-over Shielded RJ48C Patch Cable

Description

Tripp Lite's T1, RJ45-RJ45 , (RJ48C) Cross-over Patch Cables are constructed with premium Quabbin 9720, T1 certified cable. Two individually shielded, 22AWG, 100ohm pairs, maximize the performance of your expensive T1 circuits and equipment. Beware of generic T1 patch cables made with inexpensive Cat5 unshielded patch cable. The American National Standards Institute (ANSI) states in ANSI T1.403 that T1 cable be constructed of two balanced pairs, 22 AWG Solid conductor, 100ohm impedance, with a loss budget of 5.5db. Cross-over wiring configuration available in 3-ft. (0.91 m), 5-ft. (1.52 m), 7-ft. (2.13 m), and 10-ft. (3.05 m) lengths. Custom lengths available...consult your reseller. Also available in Straight-through wiring configuration...see Tripp Lite N265- Series T1 patch cables.

Features

- ANSI certified T1 cable, Levels 1, 1A, and 1C
- Complies with ANSI T1.403 Carrier-to-Customer Installation-DS1 Metallic Interface
- Cross-over T1 wiring configuration
- Available in 3-ft. (0.91 m), 5-ft. (1.52 m), 7-ft. (2.13 m), and 10-ft. (3.05 m) stocked lengths
- Custom length cables available
- NEC (UL) Type CMR
- Available also in Straight-through wiring configurations
- 22AWG Solid Tinned Copper

Specifications

OVERVIEW	
UPC Code	037332150370



Technology	T1
PHYSICAL	
Color	Beige
Cable Shielding	STP
Cable Jacket Rating	CMR
Conductor Material	Solid Copper
Cable Length (ft.)	10
Cable Length (m)	3
Cable Length (in.)	120
Cable Length (cm)	304.8
Shipping Dimensions (hwd / cm)	30.48 x 25.40 x 1.27
Shipping Dimensions (hwd / in.)	12.00 x 10.00 x 0.50
Shipping Weight (kg)	0.15
Shipping Weight (lbs.)	0.34
CONNECTIONS	
Side A - Connector 1	RJ45 (MALE)
Side B - Connector 1	RJ45 (MALE)
Connector Type	Crossover
SPECIAL FEATURES	
Snagless Connector	No
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>