


# Keyspan Mini DisplayPort to DisplayPort Cable Adapter (M/F) - 4K 60 Hz, DP 1.2, HDCP 2.2, 6 in. (15.2 cm)

MODEL NUMBER: P139-06N-DP-V2B

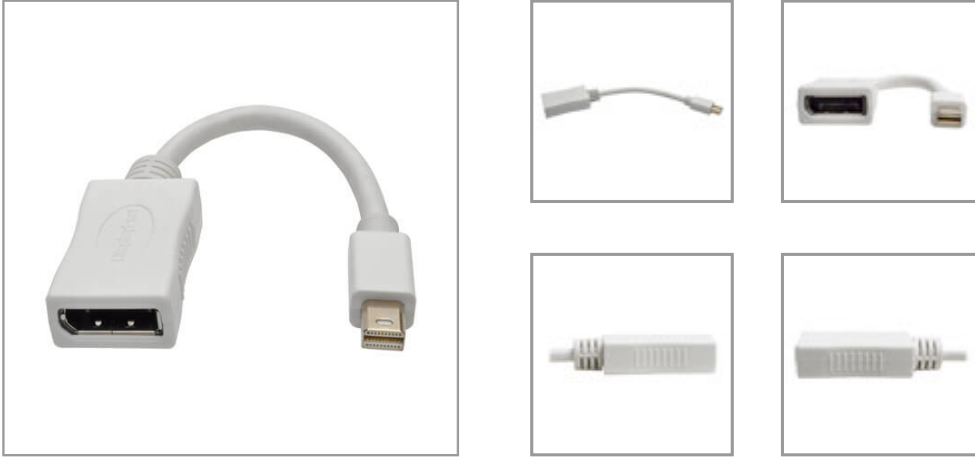

Connects a computer with a Mini DisplayPort (mDP) output to a high-definition monitor, projector or television with a DisplayPort input.

## Features

**Sends UHD Mini DisplayPort Audio/Video to a DisplayPort Monitor or a DisplayPort Computer to an mDP Monitor, Projector or TV**

- Connects an mDP computer to a DisplayPort monitor, projector or TV or a DisplayPort computer to an mDP monitor, projector or TV
- Recommended for displaying Mini DisplayPort video on a large monitor or digital sign
- Allows you to continue using an existing DisplayPort display, instead of buying a new monitor

## Vibrant Video Quality

- Supports UHD video resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz, including 1080p
- Compliant with HDCP 2.2 and DisplayPort 1.2a

## Superior Materials for Superior Performance

- Nickel-plated connectors with gold-plated contacts for excellent conductivity
- Integral strain relief for long life
- Plug and play—no software or drivers required

## Specifications

OVERVIEW	
UPC Code	037332200891
Product Type	Video Adapter
Technology	DisplayPort
CONNECTIONS	

## Highlights

- Supports UHD video resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Nickel-plated connectors with gold-plated contacts
- Integral strain relief
- Compliant with HDCP 2.2 and DisplayPort 1.2a
- Plug and play—no software or drivers required

## Package Includes

P139-06N-DP-V2B Keyspan Mini DisplayPort 1.2a to DisplayPort Cable Adapter (M/F), 6 in. (15.2 cm)



Powering Business Worldwide

TRIPP LITE  
SERIES

Side A - Connector 1	MINI DISPLAYPORT (MALE)
Side B - Connector 1	DISPLAYPORT (FEMALE)
<b>PHYSICAL</b>	
Color	White
Cable Jacket Color	White
Cable Length (ft.)	0.5
Cable Length (m)	0.15
Cable Length (in.)	6
Cable Length (cm)	15.24
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.05
Shipping Weight (kg)	0.02
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.