


High-Speed HDMI Cable, Gripping Connectors - 4K @ 60 Hz, 4:4:4 (M/M), Black, 3 ft. (0.91 m)

MODEL NUMBER: P568-003-2A

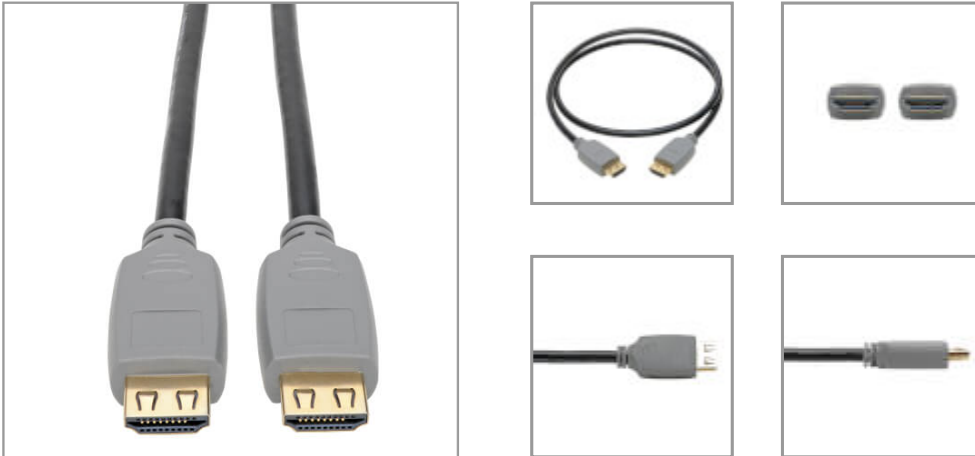

High-speed 4K HDMI cable connects your laptop or tablet to an HDTV, monitor or projector for crystal-clear 4K video with 4:4:4 color.

Features

4K HDMI Cable Connects Home Theater or Digital Signage Audio/Video Components

This high-speed HDMI cable securely connects HDMI-enabled laptops, tablets, PCs, Blu-ray players, game consoles or satellite/cable TV boxes to HDTVs, HD monitors, projectors or home theater receivers. Gripping HDMI connectors on both ends help ensure components stay firmly attached to avoid viewing interruptions. The 3-ft. (0.91 m) length helps reduce cable clutter and minimize the risk of tripping.

Enjoy the Clarity of 4K HDMI Video with Multi-Channel Audio and 4:4:4 Color

This Tripp Lite 4K HDMI cable provides a pure digital connection that supports Ultra HD video resolutions up to 4K at 60 Hz (3840 x 2160), as specified in HDMI 2.0a, for crystal-clear picture and sound. It's compatible with HDCP 2.2 and is capable of carrying HDR (high dynamic range) signals. It also supports 4:4:4 chroma subsampling for top-level PC gaming or using your HDTV as a PC monitor. The cable is backward compatible with previous HDMI generations, allowing you to use it to connect lower-resolution components.

Avoid Signal Disruptions with Extra-Secure Gripping HDMI Connectors

Having a cable come loose accidentally can cause A/V signal loss right as the running back scrambles for the end zone or your avatar is surrounded by zombies. These specially designed HDMI connectors firmly grip the HDMI ports on your equipment to help prevent accidental disconnection and signal disruption. With greater port retention than typical HDMI connectors, the gripping connectors resist vibrations that can loosen connections over time. This is especially helpful for ensuring components stay attached in difficult-to-access installations.

Invest in Quality Construction for Reliable Performance

High-quality materials ensure outstanding performance throughout the cable's lifetime. Contacts and connectors are gold-plated to resist corrosion. Double shielding reduces line noise (EMI/RFI) that can disrupt signals traveling through the HDMI cord.

Highlights

- Supports 4K @ 60 Hz video resolutions as specified in HDMI 2.0
- High-grip HDMI plugs maintain constant A/V signal without accidental disconnections
- Supports High Dynamic Range (HDR) for richer contrast and expanded color accuracy
- 3-ft. (0.91 m) length allows flexibility in placing devices, while avoiding cable clutter
- Plug-and-play operation with no software required for easy, immediate installation

Applications

- Watch 4K video content from a Blu-ray player, game console, laptop or tablet on an Ultra HD television, monitor or projector
- Connect a Chromebook or MacBook to a conference table's A/V box to give a video presentation on a large screen
- Play online or PC video games that display optimal graphics
- Attach an HDTV to your PC for use as a 4K monitor
- Combine with an Apple digital A/V adapter to support iPad2 video mirroring
- Send Ultra HD content to digital signs or point-of-sale displays

Package Includes

- P568-003-2A High-Speed HDMI



Cable with Gripping Connectors,
M/M, 3 ft.

Specifications

| OVERVIEW | |
|---------------------------------|----------------------------------|
| UPC Code | 037332236739 |
| Technology | HDMI; HDR |
| INPUT | |
| Cable Length (ft.) | 3 |
| Cable Length (m) | 0.9 |
| PHYSICAL | |
| Cable Jacket Material | PVC |
| Cable Outer Diameter (OD) | 0.3 inches |
| Color | Black |
| Shipping Dimensions (hwd / in.) | 9.00 x 7.00 x 0.50 |
| Shipping Weight (kg) | 0.08 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 14 to 122 °F (-10 to 50 °C) |
| Storage Temperature Range | 5 to 140 °F (-15 to 60 °C) |
| Relative Humidity | 0% to 90% Non Condensing |
| CONNECTIONS | |
| Side A - Connector 1 | HDMI (MALE) - GRIPPING |
| Side B - Connector 1 | HDMI (MALE) - GRIPPING |
| Connector Plating | Gold |
| Contact Plating | Gold |
| FEATURES & SPECIFICATIONS | |
| Max Supported Video Resolution | 4K @ 60 Hz, (3840 x 2160), 4:4:4 |
| HDMI Specification | 2.0a |
| HDCP Specification | 2.2 |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| STANDARDS & COMPLIANCE | |
|-------------------------------------|---------------------------|
| Certifications | RoHS |
| WARRANTY | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>