


High-Speed HDMI Cable, Gripping Connectors - 4K @ 60 Hz, 4:4:4 (M/M), Black, 6 ft. (1.83 m)

MODEL NUMBER: P568-006-2A

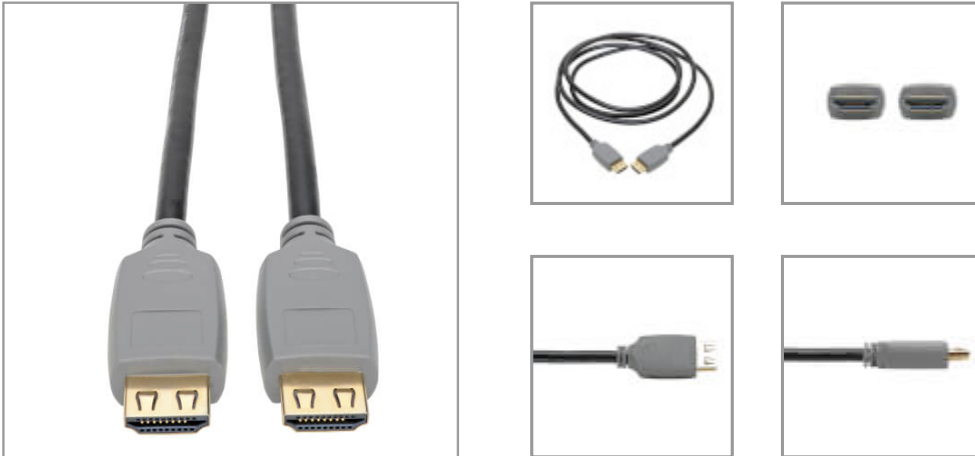

High-speed 4K HDMI cable connects your laptop or tablet to an HDTV, monitor or projector for crystal-clear 4K video with 4:4:4 color.

Features

4K HDMI Cable Connects Home Theater or Digital Signage Audio/Video Components

This high-speed HDMI cable securely connects HDMI-enabled laptops, tablets, PCs, Blu-ray players, game consoles or satellite/cable TV boxes to HDTVs, HD monitors, projectors or home theater receivers. Gripping HDMI connectors on both ends help ensure components stay firmly attached to avoid viewing interruptions. The 6-ft. (1.83 m) length allows you flexibility in placing your home theater components.

Enjoy the Clarity of 4K HDMI Video with Multi-Channel Audio and 4:4:4 Color

This Tripp Lite 4K HDMI cable provides a pure digital connection that supports Ultra HD video resolutions up to 4K at 60 Hz (3840 x 2160) for crystal-clear picture and sound, as specified in HDMI 2.0a. It's compatible with HDCP 2.2, as well as HDR video, providing a wide range of vibrant colors with richer contrast, brighter whites and deeper blacks that pop on your 4K display. HDCP 2.2 compliance allows you to stream 4K Amazon and Netflix content with no complications. This adapter supports 4:4:4 chroma subsampling for top-level PC gaming or using your HDTV as a PC monitor. The cable is backward compatible with previous HDMI generations, allowing you to use it to connect lower-resolution components.

Avoid Signal Disruptions with Extra-Secure Gripping HDMI Connectors

Having a cable come loose accidentally can cause A/V signal loss right as the running back scrambles for the end zone or your avatar is surrounded by zombies. These specially designed HDMI connectors firmly grip the HDMI ports on your equipment to help prevent accidental disconnection and signal disruption. With greater port retention than typical HDMI connectors, the gripping connectors resist vibrations that can loosen connections over time. This is especially helpful for ensuring components stay attached in difficult-to-access installations.

Invest in Quality Construction for Reliable Performance

High-quality materials ensure outstanding performance throughout the cable's lifetime. Contacts and connectors are gold-plated to resist corrosion. Double shielding reduces line noise (EMI/RFI) that can disrupt signals traveling through the HDMI cord.

Highlights

- Delivers UHD picture quality at resolutions up to 4K @ 60 Hz (3840 x 2160) as specified in HDMI 2.0a
- High-grip HDMI plugs maintain constant A/V signal without accidental disconnections
- Supports 4:4:4 chroma subsampling for HDR-compatible televisions
- 6-ft. (1.83 m) length allows flexibility in setting up devices in your home theater
- Plug-and-play operation with no software required for easy, immediate installation

Applications

- Watch 4K video content from a Blu-ray player, game console, laptop or tablet on an Ultra HD television, monitor or projector
- Connect a Chromebook or MacBook to a conference table's A/V box to give a video presentation on a large screen
- Play online or PC video games that display optimal graphics
- Attach an HDTV to your PC for use as a 4K monitor
- Combine with an Apple digital A/V adapter to support iPad2 video mirroring
- Send Ultra HD content to digital signs or point-of-sale displays

Package Includes

- P568-006-2A High-Speed HDMI



Cable with Gripping Connectors,
M/M, 6-ft. (1.83 m)

Specifications

OVERVIEW	
UPC Code	037332235985
Technology	HDMI; HDR
INPUT	
Cable Length (ft.)	6
Cable Length (m)	1.83
PHYSICAL	
Cable Jacket Material	PVC
Cable Outer Diameter (OD)	0.3 inches
Color	Black
Material of Construction	PVC
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.13
Shipping Weight (lbs.)	0.29
ENVIRONMENTAL	
Operating Temperature Range	14 to 122 °F (-10 to 50 °C)
Storage Temperature Range	5 to 140 °F (-15 to 60 °C)
Relative Humidity	0% to 90% Non Condensing
CONNECTIONS	
Side A - Connector 1	HDMI (MALE) - GRIPPING
Side B - Connector 1	HDMI (MALE) - GRIPPING
Connector Plating	Gold
Contact Plating	Gold
FEATURES & SPECIFICATIONS	
Max Supported Video Resolution	4K @ 60 Hz (3840 x 2160), 4:4:4



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

HDMI Specification	2.0a
HDCP Specification	2.2
STANDARDS & COMPLIANCE	
Certifications	RoHS
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>