


## High-Speed 4K HDMI Cables (M/M) - 4:4:4, 6 ft. (1.8 m), Black, 5 Pack

MODEL NUMBER: P568-006-5PK

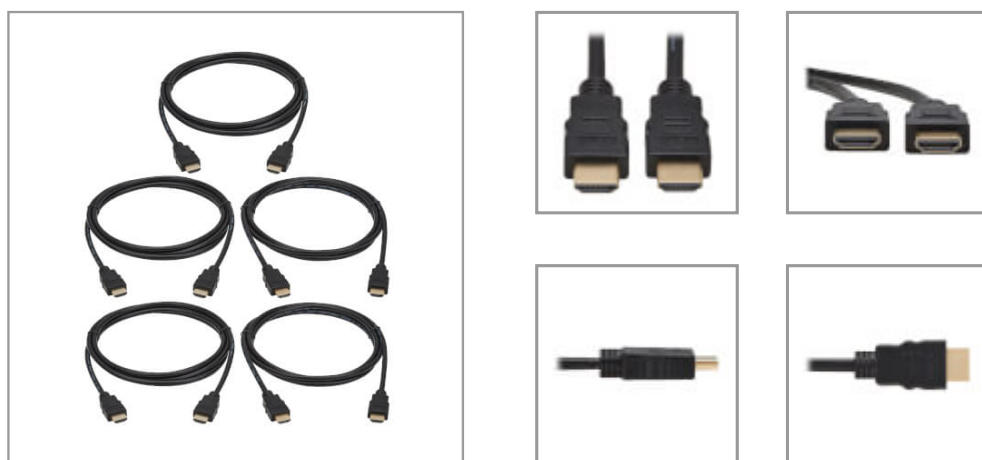

Connect your laptops, media servers or 4K Blu-ray players to 4K-compatible televisions, monitors or projectors.

### Features

#### HDMI Cables Get Your Gaming, Home Theater or Digital Signage Setup 4K-Ready

This five-pack of high-speed 4K HDMI cables (M/M) securely connects 4K-compatible source and display devices in your audio/video application. The P568-006-5PK is compatible with all HDMI devices, including 4K Blu-ray players, gaming consoles, laptops, media servers, satellite/cable TV boxes and tablets, as well as HDTVs, monitors, projectors and audio receivers. Plus, these five HDMI cables are backward compatible with your existing HDMI devices.

#### Transmits 4K Video with 4:4:4 Color

The P568-006-5PK supports Ultra HD 4K resolutions up to 3840 x 2160 at 30 Hz with 24-bit True Color and stereo audio. HDCP 1.3 encryption allows you to stream 4K content with no loss in resolution. These cables also support uncompressed 4:4:4 chroma subsampling for top-level PC gaming or using your HDTV as a PC monitor.

#### Invest in Quality Construction for Reliable Performance

The P568-006-5PK features foil and braid shielding that ensures reliable, error-free signal quality and protection from EMI/RFI line noise that can distort or destroy data. Gold-plated HDMI connectors provide maximum conductivity and minimum data loss to guarantee a clear transmission free of interference. Integral strain relief gives the cables extra flexibility, reduces stress and helps the cables move freely without cracking or breaking loose from the connector.

### Highlights

- Supports UHD resolutions up to 4K @ 30 Hz (4:4:4) for enhanced video without latency
- Foil/braid shielding protects against EMI/RFI line noise that can distort or destroy data
- Gold-plated connectors provide the most optimal signal transfer between devices
- Plug-and-play operation with no software required for easy, immediate installation

### System Requirements

Both source and display devices must be compatible with 4K standards to watch 4K video

### Package Includes

(5) High-Speed 4K HDMI Cables, M/M, 6 ft. (1.8 m), Black

## Specifications

OVERVIEW	
UPC Code	037332296535
Product Type	Passive Cable
Technology	HDMI
Cable Type	Passive



Powering Business Worldwide

TRIPP LITE  
SERIES

VIDEO	
Max Supported Video Resolution	3840 x 2160 (4K) @ 30Hz
Max Supported Color Depth	24-bit True Color
HDR Support	No
3D Video Supported	No
Chroma Sub Sampling	4:4:4
EDID Support	Yes
Signal Transmission	Bidirectional
DisplayPort Alt Mode	No
AUDIO	
Audio Specification	Stereo Audio
CONNECTIONS	
Side A - Connector 1	HDMI (MALE)
Side B - Connector 1	HDMI (MALE)
Connector Plating	Gold
Contact Plating	Gold
Connector Style	Straight
Latching or Gripping Connector	No
PHYSICAL	
Color	Black
Material of Construction	PVC
Cable Jacket Color	Black
Connector Color	Black
Cable Jacket Material	PVC
Cable Jacket Rating	VW-1
Cable Outer Diameter (OD)	5.5MM
Wire Gauge (AWG)	30
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Ferrite Core	No
Minimum Bend Radius	55mm
Shipping Dimensions (hwd / in.)	11.81 x 9.45 x 0.50



Powering Business Worldwide

TRIPP LITE  
SERIES

Shipping Weight (kg)	0.82
Unit Dimensions (hwd / in.)	11.810 x 9.450 x 0.500
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	32° to 113°F (0° to 45°C)
Storage Temperature Range	-40° to 176°F (-40° to 80°C)
Operating Humidity Range	10% to 85% RH, Non-Condensing
Storage Humidity Range	5% to 90% RH, Non-Condensing
<b>COMMUNICATIONS</b>	
EDID Compatible	No
Consumer Electronics Control (CEC) Supported	Yes
<b>FEATURES &amp; SPECIFICATIONS</b>	
EMI/RFI Line Noise Protection	No
Integrated/Removable Cable	No
MST Support	No
Antibacterial	No
IP68 Rated	No
IP20 Rated	No
Fully Molded Connector Ends	No
Ohms	No
Integral Strain Relief	No
Impedance-Matched Twisted-Pair Construction	No
Scaler Function	No
IP67 Rated	No
Armored Cable	No
Ethernet Support	No
HDCEP Specification	1.3
Driver Required	No
DIN Mountable	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; REACH
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty



*Powering Business Worldwide*

TRIPP LITE  
SERIES

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.