


In most applications where the HDMI cable exceeds 16ft, a signal booster (Model Number: B122-000-60) should be used with this cable to ensure a signal strong enough for your display.

High-Speed HDMI Cable, Digital Video and Audio, HD (M/M), White, 25 ft. (7.62 m)

MODEL NUMBER: P568-025-WH

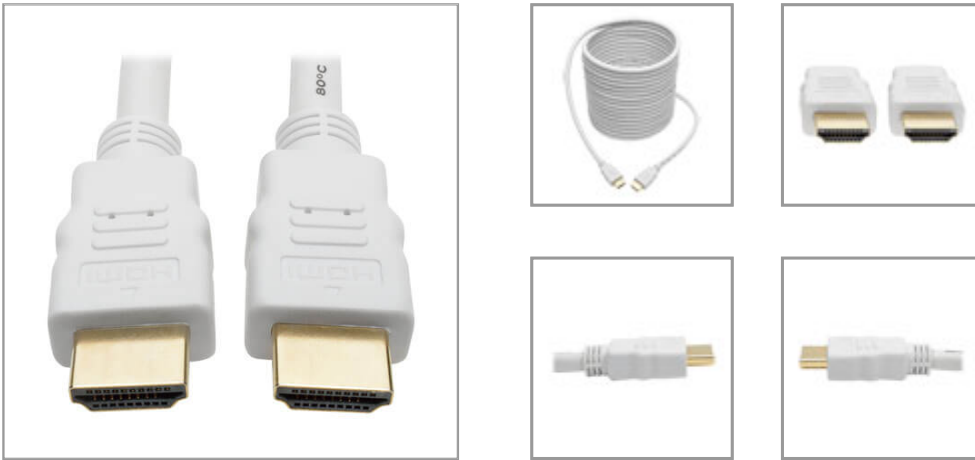

Premium HDMI cable connects two HD-enabled devices, including computers, Blu-ray™ players, video game systems, DVRs, video cameras, A/V receivers, monitors, projectors and televisions.

Description

The P568-025-WH High-Speed HDMI Cable (M/M) is recommended for digital signage, video presentations, point-of-sale displays, classrooms and other applications that display High Resolution (HD) video and multi-channel audio. It connects HD-enabled source devices, such as computers and Blu-ray players, or displays, such as monitors, projectors and televisions.

This cable supports video resolutions up to HD 1080p and data transfer speeds up to 18 Gbps. When used with an Apple® digital A/V adapter, it supports iPad2® video mirroring for playing games, watching videos or displaying presentations.

The 25-ft. (7.62 m) molded 30 AWG cable features premium foil and braid shielding to deliver reliable, error-free signal quality and protection from EMI/RFI line noise that can distort or destroy data. Gold-plated white connectors provide maximum conductivity and minimize data loss. Integral strain relief gives the cable extra flexibility, reduces stress, and helps the cable and connectors move freely without cracking. A flexible PVC jacket makes the HDCP 2.2-compliant cable easy to install in tight spaces.

Features

Connects HDMI Source to TV, Projector or MonitorIdeal for digital signage, video presentations, point-of-sale displays, classrooms and other applications with video and multi-channel audio

High Performance and Wide CompatibilitySupports HD video resolutions up to 1080pSupports data transfer speeds up to 18 GbpsComplies with HDCP 2.2 standardsSupports iPad2 video mirroring when used with Apple digital A/V adapterBackward compatible with previous HDMI generations

Superior Quality Ensures a Flawless SignalCorrosion-resistant gold-plated white connectors for maximum conductivity and minimum data lossFully molded 30 AWG construction with integral strain relief reduces stress and adds flexibilityPremium foil and braid shielding for EMI/RFI noise protectionFlexible PVC jacket easy to install in tight spaces

Specifications

Highlights

- Supports HD video resolutions up to 1080p
- Supports data transfer speeds up to 18 Gbps
- Complies with HDCP 2.2 standards
- Premium foil and braid shielding protects against EMI/RFI noise
- Gold-plated white connectors for optimal signal transfer

Package Includes

- P568-025-WH High-Speed HDMI Cable (M/M), White, 25-ft. (7.62 m)



OVERVIEW	
UPC Code	037332203540
Product Type	Passive
Technology	HDMI
PHYSICAL	
Color	White
Cable Length (ft.)	25
Cable Length (m)	7.6
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.42
Shipping Weight (lbs.)	0.93
ENVIRONMENTAL	
Operating Temperature Range	32 TO 113 F (0 TO 45 C)
Storage Temperature Range	-40 TO 176 F (-40 TO 80 C)
Operating Humidity Range	10 TO 85% RH
Storage Humidity Range	5 TO 90% RH
CONNECTIONS	
Side A - Connector 1	HDMI (MALE)
Side B - Connector 1	HDMI (MALE)
FEATURES & SPECIFICATIONS	
HDCP Specification	2.2
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>