
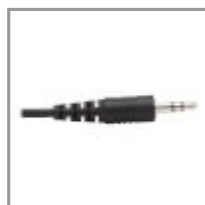


DisplayPort KVM Cable Kit, 3 in 1 - 4K DisplayPort, USB, 3.5 mm Audio (3xM/3xM), 4:4:4, 6 ft. (1.83 m), Black

MODEL NUMBER: P783-006

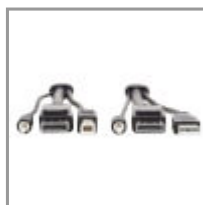

3-in-1 KVM cable kit with DisplayPort, USB A/B and 3.5 mm plugs connects your computer to a B002-DP1A4 or other compatible NIAP KVM.

Features

6-ft. (1.83 m) 3-in-1 Cable Connects Your DisplayPort Computer to a NIAP KVM Switch

This cable features DisplayPort, USB A/B and 3.5 mm audio connectors on both ends for connecting your computer to a KVM switch. Designed specifically for the B002-DP1A4 NIAP KVM, the six-foot cable supports DisplayPort video resolutions up to 3840 x 2160 (4K x 2K) at 60 Hz with true 4:4:4 chroma subsampling. It's compatible with HDCP 2.2, DisplayPort 1.2 and USB 2.0 (480 Mbps) standards. By combining three different cables into one convenient cord, you cut down on unnecessary clutter and save money.

Highlights

- Cuts cable clutter and saves money by combining 3 essential KVM cables into one
- Delivers UHD picture quality at resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Supports true 4:4:4 chroma subsampling to meet latest color standards
- Transfers data at reliable USB 2.0 speeds up to 480 Mbps
- Plug-and-play operation with no software required for easy, immediate installation

Applications

- Connect a headless computer to a Tripp Lite KVM switch
- Upgrade or replace worn or lost KVM cables
- Eliminate clutter by replacing multiple cables with one new one
- Extend the distance between the KVM switch and computer to 6 ft.

System Requirements

- B002-DP1A4 or other compatible NIAP KVM

Package Includes

- P783-006 DisplayPort KVM cable kit, 3 in 1 (M/M), 6 ft.

Specifications

OVERVIEW	
UPC Code	037332241382
Accessory Type	Cable Kit
Technology	DisplayPort
Accessory Class	KVM Switch Accessories
VIDEO	
Max Supported Video Resolution	3840 x 2160P @ 60 Hz (4K x 2K)
CONNECTIONS	



Powering Business Worldwide



Side A - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB A (MALE)
Side B - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB B (MALE)
Contact Plating	Gold
PHYSICAL	
Color	Black
Cable Jacket Color	Black
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Weight (lbs.)	0.48
Shipping Weight (kg)	0.22
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
ENVIRONMENTAL	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Relative Humidity	0 ~ 90% RH, Non-Condensing
FEATURES & SPECIFICATIONS	
USB Specification	USB 2.0 (up to 480 Mbps)
Displayport Specification	1.2
HDCP Specification	2.2
STANDARDS & COMPLIANCE	
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.