


# Dual DisplayPort KVM Cable Kit - DP, USB, 3.5 mm Audio (3xM/3xM) + DP (M/M), 4K, 4:4:4, 6 ft. (1.83 m), Black

MODEL NUMBER: P783-006-DP

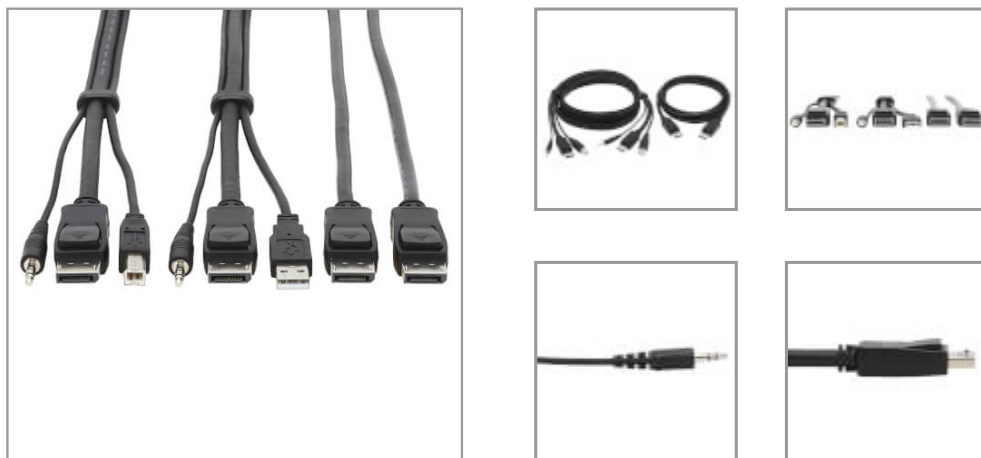

Dual DisplayPort KVM cable kit with DP, USB A/B and 3.5 mm plugs connects your computer to a Tripp Lite B002-DP2A4 or other compatible NIAP KVM.

## Features

**6-ft. (1.83 m) Cables Connect Your Computer and 2 DisplayPort Monitors to a NIAP KVM** This DisplayPort cable kit includes two 6-foot cables for connecting a computer with two monitors to a KVM switch. The P783-006 features DisplayPort, USB A/B and 3.5 mm audio connectors on both ends for connecting your computer to a KVM switch. The P580-006 is a DisplayPort cable with male connectors on each end.

**Specifically Designed for Select KVMs to Save You Time and Money** Recommended for the NIAP KVM Series. The cables support DisplayPort video resolutions up to 3840 x 2160 (4K x 2K) at 60 Hz with true 4:4:4 chroma subsampling. They are compatible with HDCP 2.2 and DisplayPort 1.2 standards. The P783-006 also supports USB 2.0 data transfer speeds up to 480 Mbps. By combining several different cables into one convenient kit, you cut down on unnecessary clutter and save money.

## Highlights

- Cuts cable clutter and saves money by combining essential KVM cables into just 2
- Includes 6-ft. (1.83 m) DisplayPort cable and 6-ft. (1.83 m) 3-in-1 DP, USB and 3.5 mm audio cable
- Delivers UHD picture quality at resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Supports true 4:4:4 chroma subsampling to meet latest color standards
- Plug-and-play operation with no software required for easy, immediate installation

## Applications

- Connect a headless computer with dual displays to a Tripp Lite KVM switch
- Upgrade or replace worn or lost KVM cables
- Eliminate clutter and save money by replacing multiple cables with one new kit
- Extend the distance between the KVM switch and computer to 6-ft. (1.83 m)

## System Requirements

- B002-DP2A4 NIAP KVM or other compatible KVM switch

## Package Includes

- P783-006 DisplayPort KVM cable kit, 3 in 1 (M/M), 6-ft. (1.83 m)
- P580-006 DisplayPort monitor cable (M/M), 6-ft. (1.83 m)

## Specifications

OVERVIEW	
UPC Code	037332241634
Accessory Type	Cable Kit
Technology	DisplayPort
Accessory Class	KVM Switch Accessories
VIDEO	



Powering Business Worldwide

**TRIPP-LITE**  
by **EAT•N**

Max Supported Video Resolution	3840 x 2160 @60Hz
<b>CONNECTIONS</b>	
Side A - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB A (MALE)
Side A - Connector 2	DISPLAYPORT (MALE)
Side B - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB B (MALE)
Side B - Connector 2	DISPLAYPORT (MALE)
Contact Plating	Gold
<b>PHYSICAL</b>	
Color	Black
Cable Jacket Color	Black
Cable Length (ft.)	6
Cable Length (m)	1.83
Cable Length (in.)	72
Shipping Dimensions (hwd / in.)	1.25 x 10.10 x 12.50
Shipping Dimensions (hwd / cm)	3.18 x 25.65 x 31.75
Shipping Weight (lbs.)	0.80
Shipping Weight (kg)	0.36
Unit Dimensions (hwd / in.)	0.000 x 0.000 x 0.000
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14° to 122°F (-10° to 50°C)
Storage Temperature Range	5° to 140°F (-15° to 60°C)
Relative Humidity	0 ~ 90% RH, Non-Condensing
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Specification	USB 2.0 (up to 480 Mbps)
Displayport Specification	1.2
HDCP Specification	2.2
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty



*Powering Business Worldwide*



1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.