


## DisplayPort KVM Cable Kit, 3 in 1 - 4K DisplayPort, USB, 3.5 mm Audio (3xM/3xM), 4:4:4, 10 ft. (3.05 m), Black

MODEL NUMBER: P783-010

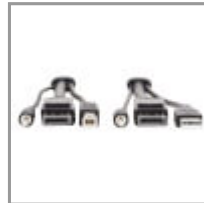

3-in-1 KVM cable kit with DisplayPort, USB A/B and 3.5 mm plugs connects your computer to a B002-DP1A4 or other compatible NIAP KVM.

### Features

**10-ft. (3.05 m) 3-in-1 Cable Connects Your DisplayPort Computer to a Tripp Lite NIAP KVM Switch** This cable features DisplayPort, USB A/B and 3.5 mm audio connectors on both ends for connecting your computer to a KVM switch. Designed specifically for the Tripp Lite B002-DP1A4 NIAP KVM, the 10-ft. (3.05 m) cable supports DisplayPort video resolutions up to 3840 x 2160 (4K x 2K) at 60 Hz with true 4:4:4 chroma subsampling. It's compatible with HDCP 2.2, DisplayPort 1.2 and USB 2.0 (480 Mbps) standards. By combining three different cables into one convenient cord, you cut down on unnecessary clutter and save money.

### Highlights

- Cuts cable clutter and saves money by combining 3 essential KVM cables into one
- Delivers UHD picture quality at resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Supports true 4:4:4 chroma subsampling to meet latest color standards
- Transfers data at reliable USB 2.0 speeds up to 480 Mbps
- Plug-and-play operation with no software required for easy, immediate installation

### Applications

- Connect a headless computer to a Tripp Lite KVM switch
- Upgrade or replace worn or lost KVM cables
- Eliminate clutter by replacing multiple cables with one new one
- Extend the distance between the KVM switch and computer to 10 ft.

### System Requirements

- Tripp Lite B002-DP1A4 or other compatible NIAP KVM

### Package Includes

- P783-010 DisplayPort KVM cable kit, 3 in 1 (M/M), 10 ft.

## Specifications



UPC Code	037332241603
Technology	DisplayPort; USB
<b>VIDEO</b>	
Max Supported Video Resolution	3840 x 2160P @ 60 Hz (4K x 2K)
<b>INPUT</b>	
Cable Length (ft.)	10
Cable Length (m)	3
Cable Length (in.)	120
<b>PHYSICAL</b>	
Color	Black
Shipping Dimensions (hwd / cm)	25.40 x 20.32 x 1.27
Shipping Dimensions (hwd / in.)	10.00 x 8.00 x 0.50
Shipping Weight (kg)	0.34
Shipping Weight (lbs.)	0.74
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14 ~ 122F (-10 ~ 50C)
Storage Temperature Range	5 ~ 140F (-15 ~ 60C)
Relative Humidity	0 ~ 90% RH, Non-Condensing
<b>CONNECTIONS</b>	
Side A - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB A (MALE)
Side B - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB B (MALE)
Contact Plating	Gold
<b>FEATURES &amp; SPECIFICATIONS</b>	
Displayport Specification	1.2
HDCP Specification	2.2
USB Specification	USB 2.0 (up to 480 Mbps)
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

<https://www.tripplite.com/products/product-certification-agencies>