


## SATA to eSATA Transition Cable (7Pin/7Pin), 3 ft. (0.91 m)

MODEL NUMBER: P952-003

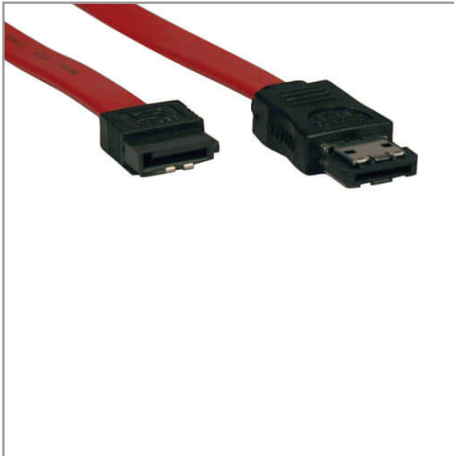

### Highlights

- SATA Internal "L" to External eSATA "I" Cable - 3-ft.
- Supports data transfer rates of up to 6.0 Gbps
- Cable is shielded to protect against EMI/RFI line noise

### Package Includes

- SATA to eSATA Transition Cable - 3-ft.

### Features

- SATA Internal "L" to External eSATA "I" Data Cable - 3-ft.
- Supports data transfer rates up to 6 Gbps
- Fully shielded cable to protect against EMI/RFI line noise

## Specifications

OVERVIEW	
UPC Code	037332140623
Technology	SATA/eSATA
PHYSICAL	
Color	Red
Cable Length (ft.)	3
Cable Length (m)	0.9
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.06
Shipping Weight (lbs.)	0.13
CONNECTIONS	
Side A - Connector 1	7 PIN SATA (MALE)



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

Side B - Connector 1	7 PIN ESATA (MALE)
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2022 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>