


## SATA to eSATA Transition Cable (7Pin/7Pin), 18-in. (45.72 cm)

MODEL NUMBER: P952-18I

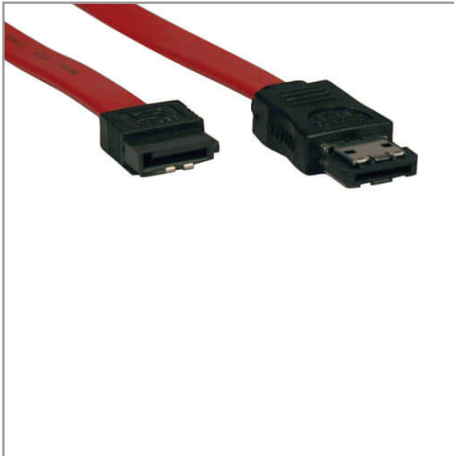

Connects newer eSATA devices to older SATA ports without the expense and effort of installing an internal adapter.

### Features

**18 in. Transition Cable Connects New eSATA Devices to Older SATA Ports**Optimized for data storage, Tripp Lite's P952-18I SATA to eSATA cable allows you to connect newer eSATA devices to older SATA ports without the added time and expense of installing an internal adapter in your computer. This red transition cable has 7-pin male connectors on both ends and provides data transfer rates up to 6 Gbps for fast file uploads and downloads. The 18-inch length helps reduce cable clutter.

**Premium Protection from EMI/RFI Line Noise Helps Your Equipment Perform Better**Various electromagnetic and radio sources found in virtually every home and business can cause disruptive interference on the AC line. Known as EMI (electromagnetic interference) and RFI (radio frequency interference), this line noise is a common cause of performance problems. This cable is fully shielded against disruptive line noise that can inflict hardware damage or data loss. This EMI/RFI filtering also helps your connected components perform better and last longer.

### Highlights

- Connects newer eSATA devices to older SATA ports with no internal adapter needed
- Transfers data at speeds up to 6 Gbps for fast file uploads and downloads
- Fully shielded against EMI/RFI interference to help connected devices last longer
- 18 in. length allows flexibility in placing devices, while avoiding cable clutter
- Plug-and-play operation makes it easy to connect in seconds

### Applications

- Connect a newer eSATA device to an older SATA port without installing an internal adapter
- Transfer data from one drive to another at speeds up to 6 Gbps

### Package Includes

- P952-18I SATA to eSATA Transition Cable (7Pin/7Pin), 18 in.

## Specifications

OVERVIEW	
UPC Code	037332140630
Technology	SATA/eSATA
INPUT	
Cable Length (ft.)	1.5
Cable Length (m)	0.5
Cable Length (in.)	18



Cable Length (cm)	45.72
<b>PHYSICAL</b>	
Color	Red
Shipping Dimensions (hwd / cm)	1.27 x 17.78 x 24.13
Shipping Dimensions (hwd / in.)	0.50 x 7.00 x 9.50
Shipping Weight (kg)	0.05
Shipping Weight (lbs.)	0.12
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	0 ~ 40C (32F ~ 104F)
Storage Temperature Range	-20 ~ 65C (-4F ~ 149F)
Operating Humidity Range	20 to 80%
Storage Humidity Range	10 to 90%
<b>CONNECTIONS</b>	
Side A - Connector 1	7 PIN SATA (MALE)
Side B - Connector 1	7 PIN ESATA (MALE)
<b>STANDARDS &amp; COMPLIANCE</b>	
Certifications	ROHS
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>