


1.9kW Single-Phase Metered PDU, 120V Outlets (28 5-15/20R), L5-20P/5-20P Adapter, 15 ft. (4.57 m) Cord, 0U Vertical

MODEL NUMBER: PDUMV20

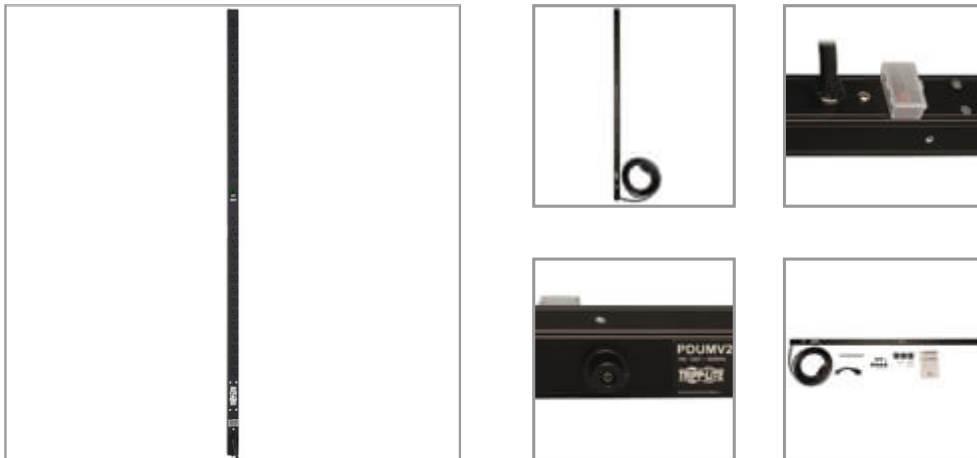

Features

- 20A single phase 120V Metered Power Distribution Unit / PDU (Agency de-rated to 16A continuous)
- Two-digit lighted meter reports combined total output current in amps
- Attached NEMA L5-20P input plug with 15-ft. (4.57 m) line cord and 5-20P adapter
- 0U 60in / 152cm vertical rackmount format installs using no rack spaces
- 28 NEMA 5-15/20R outlets
- Includes 20A circuit breaker and lighted power switch inside a transparent protective cover
- Toolless installation supported in button-mount compatible equipment racks
- Bolt-down installation brackets support installation in other racks and additional surfaces

Highlights

- Metered single phase 120V 16A 0U 60in / 152cm vertical rackmount PDU
- Two-digit current meter reports output current in amps
- Attached 15-ft. (4.57 m) cord with NEMA L5-20P plug and 5-20P adapter
- 28 NEMA 5-15/20R outlets
- Toolless button mount and bolt-down bracket installation hardware included

Package Includes

- PDUMV20 Metered Vertical PDU
- (1) L5-20P to 5-20P plug adapter
- Mounting hardware and spare mounting buttons
- Instruction manual with warranty information

Specifications

| OVERVIEW | |
|--------------------------------|-----------------------------------|
| UPC Code | 037332132543 |
| PDU Type | Metered |
| INPUT | |
| PDU Input Voltage | 120V |
| Recommended Electrical Service | Single-phase 20A 120V service |
| Maximum Input Amps | 16 |
| Maximum Input Amps Details | Agency de-rated to 16A continuous |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|--|---|
| PDU Plug Type | NEMA 5-20P; NEMA L5-20P |
| Input Phase | Single-Phase |
| Input Cord Length (ft.) | 15 |
| Input Cord Length (m) | 4.57 |
| OUTPUT | |
| Output Capacity Details | 1.92kW (120V) / 16A total capacity; 16A max per outlet |
| Frequency Compatibility | 50 / 60 Hz |
| Output Receptacles | (28) 5-15/20R |
| Output Nominal Voltage | 120V |
| Overload Protection | 20A circuit breaker |
| USER INTERFACE, ALERTS & CONTROLS | |
| Front Panel LCD Display | Digital meter reports PDU output current in amps |
| Switches | Lighted on/off switch with integrated transparent safety cover |
| PHYSICAL | |
| Form Factors Supported | Vertical |
| Material of Construction | Aluminum |
| PDU Form Factor | Vertical (0U) |
| Shipping Dimensions (hwd / cm) | 6.10 x 8.89 x 160.53 |
| Shipping Dimensions (hwd / in.) | 2.40 x 3.50 x 63.20 |
| Shipping Weight (kg) | 3.18 |
| Shipping Weight (lbs.) | 7.00 |
| Unit Dimensions (hwd / cm) | 153.59 x 3.81 x 4.17 |
| Unit Dimensions (hwd / in.) | 60.47 x 1.5 x 1.64 |
| Unit Weight (kg) | 2.44 |
| Unit Weight (lbs.) | 5.39 |
| ENVIRONMENTAL | |
| Operating Temperature Range | 0C ~ 40C (32F ~ 104F) |
| Storage Temperature Range | -30°C to +50°C (-22°F to +122°F) |
| STANDARDS & COMPLIANCE | |
| Certifications | Tested to UL 60950-1: 2007 R10.14 (USA) and CAN/CSA-C22.2 No. 60950-1-07+A1:2011+A2:2014 (Canada), NOM (Canada), RoHS Compliant |
| WARRANTY | |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|--|-------------------------|
| Product Warranty Period (Worldwide) | 2-year limited warranty |
|--|-------------------------|

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:
<https://www.tripplite.com/products/product-certification-agencies>