


# Power It! 2-Outlet Pop-Up Power and Charging Dock - 2x USB-A, 6 ft. Cord, Antimicrobial Protection, Black

MODEL NUMBER: PS22POPAM

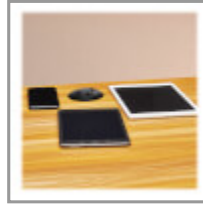

Installs in your desktop's pre-cut grommet to charge and power up to 4 devices at the same time.

## Features

### Fits into Your Desktop Grommet for Reliable Power and Charging

This Power It!® dock is designed for installation in your desktop's pre-cut three-inch grommet hole. When not being used to power or charge devices, you can push down the PS22POPAM into the grommet and flush against the desktop's surface to save valuable space. To connect devices, simply pop it up out of the hole. This Pop-Up Power and Charging Dock is ideal for home and office workstations with limited desk space.

### NEMA 5-15R Outlets and USB Ports Accept a Wide Range of Electronic Devices

Two NEMA 5-15R outlets and two USB-A ports (4.5A combined) are available for powering and charging your laptop, tablet, smartphone or other devices. The six-foot input cord with right-angle plug connects to a nearby AC wall outlet.

### Antimicrobial Protection Helps Provide a Safer, Cleaner and Healthier Environment

The PS22POPAM features antimicrobial protection that helps resist the growth of bacteria, viruses, fungi, mold and mildew.

## Highlights

- Pushes down out of the way flush with desktop surface when not in use
- 2 NEMA 5-15R outlets distribute AC power to connected home/office equipment
- 2 USB-A ports share 4.5A for fast charging of phones and other mobile devices
- 6 ft. input cord allows flexibility in placing devices away from wall outlet
- Antimicrobial protection helps resist the growth of bacteria, viruses, fungi, mold and mildew

## Package Includes

- PS22POPAM 2-Outlet Pop-Up Power and Charging Dock
- Owner's manual

## Specifications

OVERVIEW	
UPC Code	037332271914
Product Type	Power Strip
Charging Form Factor	Strip
Device Compatibility	Amazon Kindle; Laptop; Phone; Tablet
INPUT	



Powering Business Worldwide



Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V
Input Cord Length Details	Strip
Input Cord Gauge (AWG)	14
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Details	SJT
Input Cord Length (ft.)	6
Right-Angle Plug	No
Input Cord Length (m)	1.83
Integrated Cord Clip	No
<b>OUTPUT</b>	
Frequency Compatibility	60 Hz
Output Receptacles	(2) 5-15R
Transformer Accommodation	No
Right-Angle Outlets	No
<b>USER INTERFACE, ALERTS &amp; CONTROLS</b>	
Diagnostic LED(s)	Yes
<b>CHARGING</b>	
Number of Charging Ports	2
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 4.2A
Overcharge Protection	No
<b>SURGE / NOISE SUPPRESSION</b>	
Automatic Shut-Off	No
<b>DATALINE SURGE SUPPRESSION</b>	
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
Telephone/DSL Protection	No
<b>PHYSICAL</b>	
Color	Black



Powering Business Worldwide



Material of Construction	Plastic
Power Cord Color	Black
Mounting Holes or Slots	No
Receptacle Color	Black
Shipping Dimensions (hwd / in.)	4.20 x 4.10 x 12.00
Shipping Dimensions (hwd / cm)	10.67 x 10.41 x 30.48
Shipping Weight (lbs.)	1.90
Shipping Weight (kg)	0.86
Unit Dimensions (hwd / in.)	10.140 x 2.950 x 3.000
Unit Dimensions (hwd / cm)	10.14 x 2.95 x 3
Unit Weight (lbs.)	1.87
Unit Weight (kg)	0.85
<b>FEATURES &amp; SPECIFICATIONS</b>	
Rotatable Outlets	No
Antimicrobial	Yes
Built-In Circuit Breaker	No
GaN Technology	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	CAN/CSA-C22.2 No. 308 (Canada); NOM (Mexico); UL 962A
Product Compliance	FCC Part 15 Class B (USA); RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
 Cleveland, OH 44122  
 United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
 Eaton is a registered trademark. All other trademarks  
 are the property of their respective owners.