


## 8-Outlet Vertical Power Strip, 120V, 15A, 10 ft. (3.05 m) Cord, 5-15P, 24 in.

MODEL NUMBER: PS240810

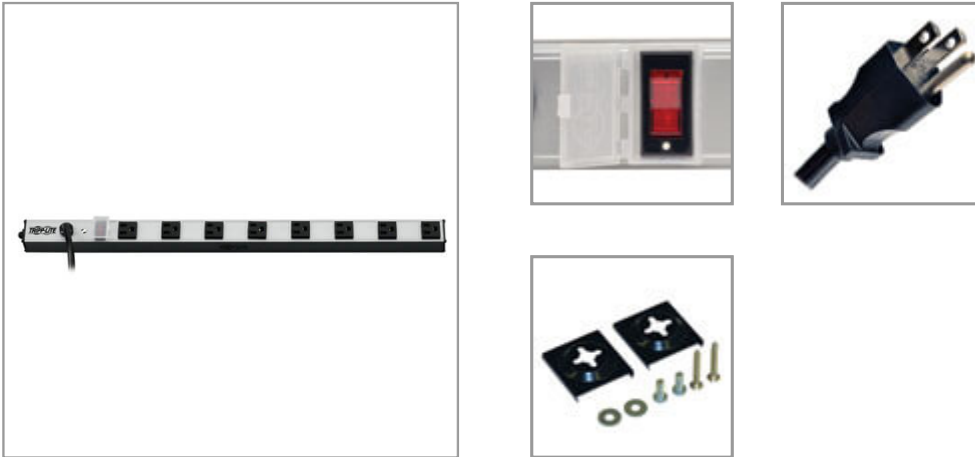

The PS240810 power strip provides horizontal or vertical power distribution for rackmount, raceway and workbench applications in a convenient 24-inch mountable housing.

### Description

The PS240810 provides a 15-amp, 120v power strip with 8 standard NEMA 5-15 outlets in a rugged, all-metal, mountable housing. It allows for both vertical and horizontal mounting, making it ideal for a variety of uses including office, rackmount, workbench, industrial and telecom applications. With a NEMA 5-15P, 10-ft. (3.05 m) power cord, you don't have to install the PS240810 next to outlets you already have; it can be mounted across the room and deliver reliable service where you need it most. A lighted and covered On/Off switch helps prevent accidental shut-offs, while a 15-amp circuit breaker guards against dangerous circuit overloads. Its sturdy all-metal extruded aluminum housing stands up to demanding network, laboratory or factory environments.

### Features

**Multi-Outlet Power Distribution:**

**Vertical or Horizontal Mounting:**

**Extra Long Power Cord:**

**Premium Safety Features:**

**Heavy-Duty Housing:**

## Specifications

### Highlights

- Ideal for applications needing multiple convenience outlets for powering a variety of electronic equipment 24-in mountable housing with 8 standard NEMA 5-15R outlets and a 10-ft. (3.05 m) power cord
- Lighted, covered On/Off switch and 15-amp circuit breaker
- Sturdy construction and heavy-duty, all-metal housing

### Package Includes

- PS240810
- Mounting hardware
- Instruction manual



Powering Business Worldwide



OVERVIEW	
UPC Code	037332187512
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	15A 120V
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	10
Right-Angle Plug	No
Input Cord Length (m)	3.05
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(8) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(4) Yes
Right-Angle Outlets	No
Outlet Spacing	2.48 in.
USER INTERFACE, ALERTS & CONTROLS	
Switches	Lighted 2 position switch controls power to all outlets
Locking Switch Cover	Transparent on/off switch cover prevents accidental turn-off
PHYSICAL	
Color	Silver
Material of Construction	Aluminum
Power Cord Color	Black
Form Factors Supported	Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications
Housing Color	Silver
Included Mounting Accessories	Includes mounting clips
Mounting Holes or Slots	No
Outlets Measurement (Center to Center)	2.48 in.



Powering Business Worldwide



Receptacle Color	Black
Shipping Dimensions (hwd / in.)	2.40 x 4.60 x 27.80
Shipping Dimensions (hwd / cm)	6.10 x 11.68 x 70.61
Shipping Weight (lbs.)	3.09
Shipping Weight (kg)	1.40
Unit Dimensions (hwd / in.)	1.250 x 1.500 x 24.200
Unit Dimensions (hwd / cm)	61.97 x 3.18 x 3.8
Unit Weight (lbs.)	2.16
Unit Weight (kg)	0.98
Outlet Spacing	2.48 in.
<b>FEATURES &amp; SPECIFICATIONS</b>	
Antimicrobial	No
Built-In Circuit Breaker	Yes
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Certifications	cUL Listed; UL 1363; UL Listed
Product Compliance	RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.