


Safe-IT UL 1363 Medical-Grade Power Strip, 6 Hospital-Grade Outlets, USB Charging, Safety Covers, Antimicrobial, 6 ft. Cord

MODEL NUMBER: PS-606-HGUSB

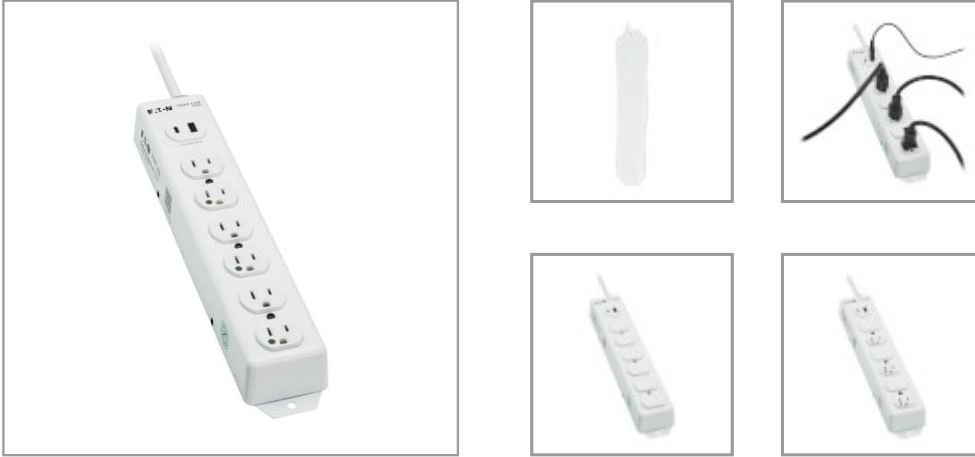

Delivers power to medical equipment in areas outside patient care vicinities, including nursing stations, labs, offices and pharmacies.

Features

Medical-Grade Power Strip Approved for Hospitals, Clinics and Other Medical Facilities

The PS-606-HGUSB features six NEMA 5-15R-HG hospital-grade outlets that supply power to equipment used in areas outside patient care vicinities, including nursing stations, pharmacies, office and administration areas, and labs. This power strip has a NEMA 5-15P-HG “green dot” plug and meets UL 1363 standards.

Dual USB Ports Provide Charging Power

One USB-A port and one USB-C Power Delivery (PD) port let you charge smartphones, tablets and other vital mobile devices. The USB-C PD port provides up to 30W.

Antimicrobial Protection Helps Provide a Safer, Cleaner and Healthier Work Environment

The Safe-IT™ power strip is protected by an antimicrobial coating that helps resist the growth of bacteria, viruses, fungi, mold and mildew.

Premium Safety Features Help Ensure Proper Power Connections

With no central power switch, this power strip presents no danger of accidental shutoff and cutting off power to essential devices. Locking plastic safety covers are included to block access to unused outlets.

Ready for Installation in Demanding Medical Environments

The six-foot cord gives you some leeway in positioning the power strip away from a standard NEMA 5-15R wall outlet. Built-in mounting flanges let you mount the all-metal housing to a stable, flat surface. Scan the Easy Asset QR code on the side of the power strip to access product resources and other critical information.

Highlights

- Medical-grade power strip approved for use outside patient care vicinities
- 6 NEMA 5-15R-HG outlets come with optional locking covers for protection
- Dual USB ports provide charging power to 2 mobile devices at the same time
- 6 ft. power cord allows flexibility in placing power strip away from wall outlet
- Antimicrobial protection helps resist the growth of bacteria, viruses, fungi, mold and mildew

Package Includes

- PS-606-HGUSB UL 1363 Medical-Grade Power Strip, 6 Outlets, 6 ft. Cord
- (6) Outlet safety covers
- Owner's manual

Specifications

| OVERVIEW | |
|----------|--------------|
| UPC Code | 037332287731 |



Powering Business Worldwide

TRIPP LITE
SERIES

| INPUT | |
|--|--------------------------------|
| Nominal Input Voltage(s) Supported | 120V AC |
| Recommended Electrical Service | 15A 120V |
| Input Connection Type | NEMA 5-15P-HG |
| Input Plug Features | Hospital Grade Plug |
| Input Cord Gauge Type | 14 gauge; SJT |
| Voltage Compatibility (VAC) | 120 |
| Input Plug Type | NEMA 5-15P-HG |
| Input Cord Length (ft.) | 6 |
| Right-Angle Plug | No |
| Input Cord Length (m) | 1.83 |
| Integrated Cord Clip | No |
| OUTPUT | |
| Frequency Compatibility | 50 / 60 Hz |
| Output Receptacles | (6) 5-15R-HG |
| Circuit Breaker (amps) | 15 |
| Overload Protection | 15A circuit breaker |
| Transformer Accommodation | (2) Yes |
| Outlet Orientation | Single row of 6 |
| Right-Angle Outlets | No |
| USER INTERFACE, ALERTS & CONTROLS | |
| Diagnostic LED(s) | No |
| Switches | No power switch |
| CHARGING | |
| Number of Charging Ports | 2 |
| Total Charging Watts | 30 |
| Charging Method | USB |
| Charging Port Type | USB A (FEMALE); USB C (FEMALE) |
| Charging Ports Details | USB C Power Delivery |
| Charging Ports / Amps | (1) 2A; 3A / 2A / 1.5A |
| PHYSICAL | |
| Color | White |
| Material of Construction | Metal |



Powering Business Worldwide

TRIPP LITE
SERIES

| | |
|---|--|
| Power Cord Color | White |
| Housing Color | White |
| Included Mounting Accessories | Keyhole mounting tabs and flanges |
| Mounting Holes or Slots | Yes |
| Slot or Hole Mount Measurement (Center to Center) | Distance between keyhole tabs = 261.92mm; Distance between end tabs = 330.17 |
| Outlets Measurement (Center to Center) | 1.52 in. |
| Receptacle Color | White |
| Shipping Dimensions (hwd / in.) | 14.17 x 5.98 x 2.17 |
| Shipping Dimensions (hwd / cm) | 35.99 x 15.19 x 5.51 |
| Shipping Weight (lbs.) | 2.54 |
| Shipping Weight (kg) | 1.15 |
| Unit Dimensions (hwd / in.) | 13.630 x 2.250 x 1.650 |
| Unit Weight (lbs.) | 2.4 |
| Unit Weight (kg) | 1.09 |
| Mounting Details | Includes flanges |
| FEATURES & SPECIFICATIONS | |
| Rotatable Outlets | No |
| Antimicrobial | Yes |
| Built-In Circuit Breaker | Yes |
| Antibacterial | No |
| Built-in Cable Management | No |
| STANDARDS & COMPLIANCE | |
| Product Certifications | cUL Listed; UL 1363; UL Listed |
| Product Compliance | RoHS; FCC Part 15 Class B (USA) |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.