


## 24-Outlet Vertical Power Strip, 120V, 20A, Hardwired Input, 72 in.

MODEL NUMBER: **PS7224-20HW**

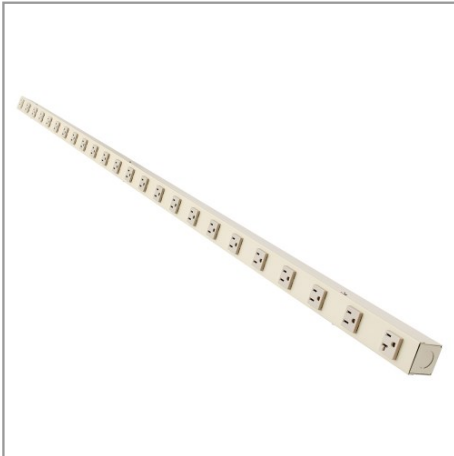

### Highlights

- AC input hardwired via knockout on unit
- 24 outlets
- Ideal for applications requiring permanent installation

### Package Includes

- PS7224-20HW
- Instruction manual

### Description

Tripp Lite's PS7224-20HW Power Strip offers 20 amp multi-outlet AC power distribution in a convenient 72 inch hardwire cabinet. Includes knockout panels to accept 3/4 in. conduit fittings for hardwire installation and 24 output receptacles with 2.795 inch center-to-center spacing. Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications.

INPUT/OUTPUT: Input: Hard-wire access via knockout panels that accept 3/4 inch conduit fittings

Output: 24 outlets total, 2 NEMA 5-15/20R (20A) and 22 NEMA 5-15R (15A)

ELECTRICAL: 120V AC, 50/60Hz, 20A (no circuit breaker)

FORMAT: 72 inch strip format with 24 outlets

### Features

- Versatile all-metal 72 inch format with outlets arranged in a single row
- Knockout panels for 3/4 inch conduit fittings allow permanent hardwire installation
- Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications
- 24 outlets total, 2 NEMA 5-15/20R (20A) and 22 NEMA 5-15R (15A)
- 20 amp electrical capacity
- 120V AC, 50/60Hz electrical compatibility

## Specifications

OVERVIEW	
UPC Code	037332042361
INPUT	
Nominal Input Voltage(s) Supported	120V AC



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
www.tripplite.com

Recommended Electrical Service	20A 120V
Voltage Compatibility (VAC)	120
Input Plug Type	Hard-wire
Input Cord Length (ft.)	0
Input Cord Length (m)	0.00
Integrated Cord Clip	No
<b>OUTPUT</b>	
Frequency Compatibility	50 / 60 Hz
Output (Watts)	2400
Output Receptacles	(2) 5-15/20R; (22) 5-15R
Circuit Breaker (amps)	20
Transformer Accommodation	(12) Yes
Right-Angle Outlets	No
Outlet Spacing	2.795 in.
<b>PHYSICAL</b>	
Antimicrobial Coating	No
Color	Beige
Integrated Keyhole Mounting Slots	No
Material of Construction	Metal
Outlets Measurement (Center to Center)	101.60mm
Receptacle Color	Beige
Shipping Dimensions (hwd / cm)	7.11 x 6.60 x 194.31
Shipping Dimensions (hwd / in.)	2.80 x 2.60 x 76.50
Shipping Weight (kg)	3.45
Shipping Weight (lbs.)	7.60
Unit Dimensions (hwd / cm)	182.88 x 3.8 x 3.8
Unit Dimensions (hwd / in.)	72 x 1.5 x 1.5
<b>STANDARDS &amp; COMPLIANCE</b>	
Canada	cUL
Approvals	UL
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

© 2020 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:  
<https://www.tripplite.com/products/product-certification-agencies>