


4-Outlet Power Strip with USB-A Charging (6.2A) - NEMA 5-15R, 120V, 15A, 10 ft. (3.05 m) Cord, 5-15P, 24 in.

MODEL NUMBER: PSC240410USBB

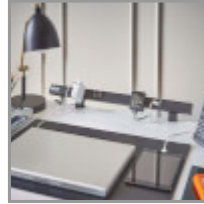

Four-outlet power strip with USB-A charging ports distributes power and charges mobile devices. Includes optional mounting clamps.

Features

24 in. Power Strip Provides 4 AC Outlets and 4 USB-A Charging Ports Compatible with standard electrical equipment, this UL-listed power strip has a 24-inch aluminum housing with a durable black finish. There are a total of four NEMA 5-15R outlets and four USB-A charging ports; each one-foot section has two outlets and two charging ports. The outlets are placed at a right angle to prevent connected power cords from blocking access to the adjacent outlet. In the event of an overload, a 15-amp resettable circuit breaker immediately shuts down the power strip to prevent equipment damage.

Charge Up to 4 Mobile Devices with 6.2A of Shared Power In addition to AC outlets, this power strip provides USB charging for up to four mobile devices, including tablets, e-readers and smartphones. Each pair of USB-A charging ports provides up to 3.1 amps of shared power. The USB ports eliminate the need for AC adapters for charging cords, leaving outlets available for AC equipment.

Place Outlets and Charging Ports Away from the Power Source The PSC240410USBB has a 10-ft. (3.05 m) cord, so you can mount it away from its AC wall outlet or other power source. The cord has a NEMA 5-15P plug.

Use Optional Mounting Clamps to Add Flexibility to Horizontal Installations If drilling mounting holes is not possible or desirable, use the included heavy-duty C-clamps to mount the power strip. The clamps attach to the edge of a desk, table, workbench or other solid, flat surface up to 2.25 inches thick. Slide the clamps onto the edge of your surface, hand tighten the adjustment knobs and snap the power strip into the built-in mounting clips. No drilling is required. It is easy to relocate the installation because there are no fasteners to remove. The PSC240410USBB also comes with clips for vertical or horizontal surface-mounting to a wall or workbench.

Highlights

- 4 right-angle 5-15R outlets distribute power to home and office electronics
- 4 USB-A charging ports power mobile devices; 6.2 amps of shared power
- 10-ft. (3.05 m) cord with 5-15P plug offers flexible placement in relation to an AC wall outlet
- 24 in. metal housing withstands the rigors of daily use
- Included clamps mount to a desk, table or workbench; no drilling required

Applications

- Distribute power to computer equipment and other devices in an office, workbench, industrial, retail or telecom environment
- Clamp mount a power strip to the edge of a desk or workbench for easy access to outlets and USB charging ports
- Provide outlets and USB charging ports at a trade show booth without permanently mounting the power strip

Package Includes

- PSC240410USBB 4-Outlet Power Strip with USB-A Charging
- (2) Mounting clamps with clips
- (2) Mounting clips for surface-mounting
- Owner's manual

Specifications

| OVERVIEW | |
|----------|--------------|
| UPC Code | 037332238825 |



Powering Business Worldwide



| | |
|--|---|
| Product Type | Power Strip |
| Charging Form Factor | Strip |
| Device Compatibility | Phone; Tablet; Amazon Kindle |
| INPUT | |
| Nominal Input Voltage(s) Supported | 120V AC |
| Recommended Electrical Service | 15A 120V |
| Input Cord Gauge Type | 14 gauge; SJT |
| Voltage Compatibility (VAC) | 120 |
| Input Plug Type | NEMA 5-15P |
| Input Cord Length (ft.) | 10 |
| Right-Angle Plug | No |
| Input Cord Length (m) | 3.05 |
| Integrated Cord Clip | No |
| OUTPUT | |
| Frequency Compatibility | 50 / 60 Hz |
| Output Receptacles | (4) 5-15R |
| Circuit Breaker (amps) | 15 |
| Transformer Accommodation | (4) Yes |
| Right-Angle Outlets | Yes |
| CHARGING | |
| Number of Charging Ports | 1 |
| Charging Method | USB |
| Charging Port Type | USB A (FEMALE) |
| Charging Ports / Amps | (1) 6.2A |
| PHYSICAL | |
| Color | Black |
| Material of Construction | Aluminum |
| Power Cord Color | Black |
| Form Factors Supported | Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications |
| Included Mounting Accessories | Desk/table mounting clamps |
| Mounting Holes or Slots | No |
| Outlets Measurement (Center to Center) | 1.42 in. |
| Receptacle Color | Black |



Powering Business Worldwide



| | |
|--------------------------------------|--------------------------------|
| Shipping Dimensions (hwd / in.) | 2.40 x 5.40 x 27.60 |
| Shipping Dimensions (hwd / cm) | 6.10 x 13.72 x 70.10 |
| Shipping Weight (lbs.) | 3.40 |
| Shipping Weight (kg) | 1.54 |
| Unit Dimensions (hwd / in.) | 1.610 x 24.000 x 1.250 |
| Unit Dimensions (hwd / cm) | 60.69 x 3.18 x 4.09 |
| Unit Weight (lbs.) | 2.29 |
| Unit Weight (kg) | 1.04 |
| FEATURES & SPECIFICATIONS | |
| Antimicrobial | No |
| Built-In Circuit Breaker | Yes |
| STANDARDS & COMPLIANCE | |
| Product Certifications | cUL Listed; UL 1363; UL Listed |
| Product Compliance | RoHS |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

1000 Eaton Boulevard
 Cleveland, OH 44122
 United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
 Eaton is a registered trademark. All other trademarks
 are the property of their respective owners.