


Toolless Horizontal 90-Degree T-Junction for Fiber Routing System, 240 mm (10 in.)

MODEL NUMBER: SRFC10JUNT

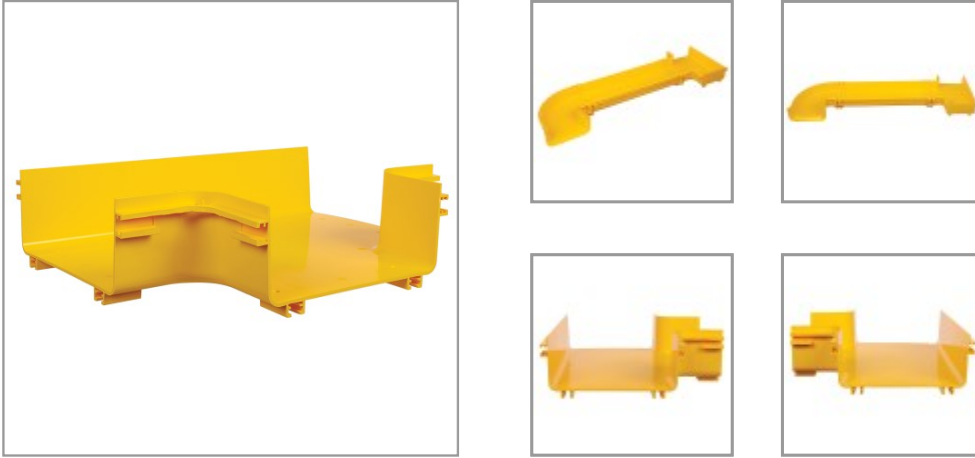

240 mm T-section turns a straight horizontal run in your fiber management system into a 90-degree horizontal branch.

Features

High-Impact PVC T-Junction Helps You Create 90-Degree Fiber Cable Routing Branches

The SmartRack® SRFC10JUNT connects to three channel sections or other fittings in your fiber routing system to create a 90-degree horizontal branch. Three of SRFC10CPL10 couplers (sold separately) are required to complete your installation. Made from durable, lightweight PVC material, this T-section connects using the couplers' included hardware to help keep your fiber optic cable bundles neat and organized. Screws tighten by hand with no tools required to complete a professional, finished look in your data center, network closet or industrial space.

Highlights

- Allows you flexibility in creating your custom fiber optic cable routing system
- Constructed from durable but lightweight PVC plastic
- Easy to install with your fiber routing system with no tools needed
- Requires 3 SRFC10CPL10 couplers (sold separately)

Applications

- Create a fiber routing system along the wall or ceiling of your data center or network closet or across the tops of the rack enclosures

System Requirements

- 3 x SRFC10CPL10 couplers (sold separately)

Package Includes

- Horizontal 90° T-junction, 240 mm
- Installation guide

Specifications

| OVERVIEW | |
|--|------------------------------|
| UPC Code | 037332240996 |
| Product Type | Junction |
| Accessory Type | Cable Management Accessories |
| Cable Management System Component Type | Junction |
| PHYSICAL | |
| Color | Yellow |
| Shipping Dimensions (hwd / in.) | 19.20 x 15.30 x 5.10 |
| Shipping Weight (kg) | 1.75 |
| Unit Dimensions (hwd / in.) | 4.645 x 18.740 x 14.840 |
| Unit Dimensions (hwd / cm) | 11.341 x 47.599 x 37.693 |



Powering Business Worldwide



| | |
|--------------------------------------|-------------------------|
| Unit Weight (lbs.) | 1.2 |
| Unit Weight (kg) | 0.54 |
| FEATURES & SPECIFICATIONS | |
| IP68 Rated | No |
| IP20 Rated | No |
| STANDARDS & COMPLIANCE | |
| Product Compliance | RoHS; EIA/ECA-310-E |
| WARRANTY & SUPPORT | |
| Product Warranty Period (Worldwide) | 5-year limited warranty |

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.