


# Toolless 45-Degree Up/Down Ramp Kit for Fiber Routing System, 240 mm (10 in.)

MODEL NUMBER: SRFC10RAMP

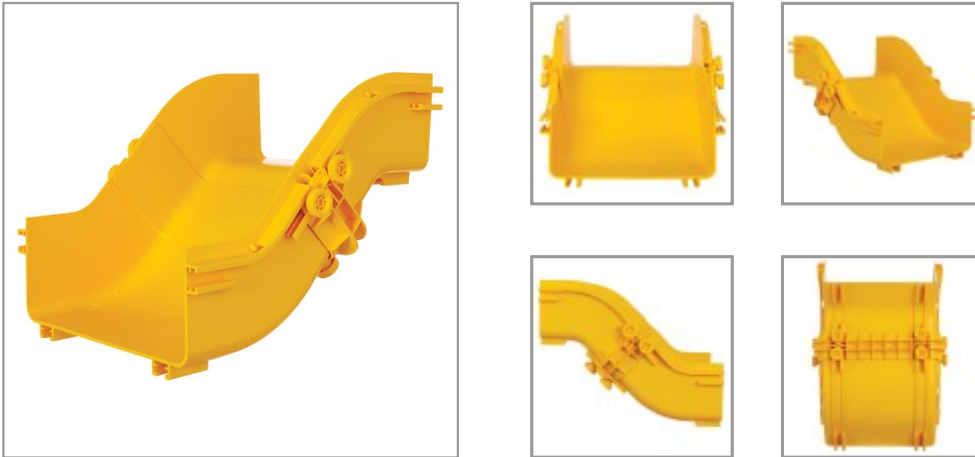

240 mm ramps raise or lower the level of a straight horizontal run in your fiber management system.

## Features

### High-Impact PVC Ramps Help You Create Custom Fiber Cable Routing Schemes

The SmartRack® SRFC10RAMP connects to straight channel sections or other fittings in your fiber routing system to raise or lower it to a different level. Two of SRFC10CPL10 couplers (sold separately) are required to complete your installation. Made from durable, lightweight PVC material, these ramps connect using the included hardware to help keep your fiber optic cable bundles neat and organized. Screws tighten by hand with no tools required to complete a professional, finished look in your data center, network closet or industrial space.

## Highlights

- Allows you flexibility in creating your custom fiber optic cable routing system
- Constructed from durable but lightweight PVC plastic
- Easy to install with your fiber routing system with no tools needed
- Requires 2 SRFC10CPL10 couplers (sold separately)

## Applications

- Create a fiber routing system along the wall or ceiling of your data center or network closet or across the tops of the rack enclosures

## System Requirements

- 2 x SRFC10CPL10 couplers (sold separately)

## Package Includes

- Down elbow, 45°
- Up elbow, 45°
- Coupler
- (8) Shank screws
- Installation guide

## Specifications

OVERVIEW	
UPC Code	037332240958
Product Type	Ramp
Accessory Type	Cable Management Accessories
Cable Management System Component Type	Ramp
PHYSICAL	
Color	Yellow
Shipping Dimensions (hwd / in.)	6.50 x 10.10 x 11.80
Shipping Weight (kg)	1.27
Unit Dimensions (hwd / in.)	4.645 x 18.740 x 14.840
Unit Dimensions (hwd / cm)	11.7983 x 47.5996 x 37.6936



Powering Business Worldwide



Unit Weight (lbs.)	1.2
Unit Weight (kg)	0.54
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	RoHS; EIA/ECA-310-E
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
<https://tripplite.eaton.com>

© 2024 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.