


## SmartRack Cable Gland Plate for NEMA-Rated Enclosure Cabinets, 3 Ports (2 in.)

MODEL NUMBER: SRGP2KO

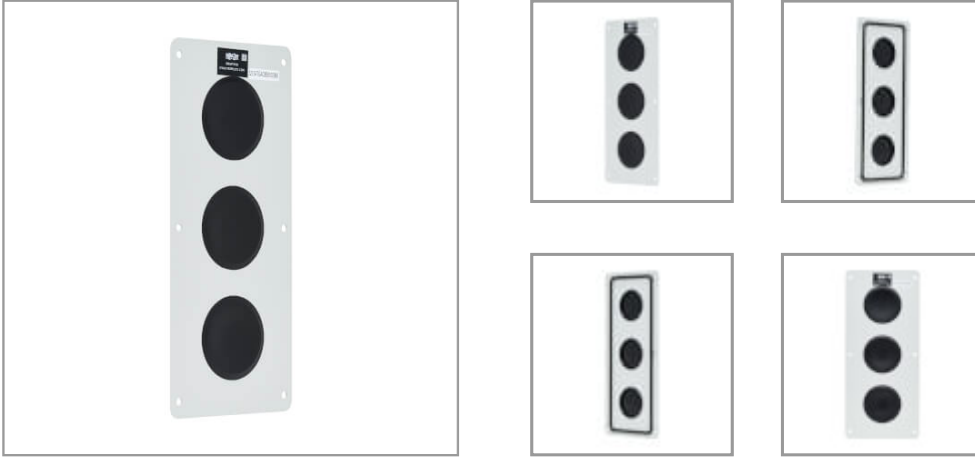

Cable entry plate covers entry/exit cable cutouts on SmartRack NEMA 3R and NEMA 4 industrial enclosures.

### Features

#### Gasketed Cable Entry Plate for NEMA-Rated Industrial Enclosures

This metal-reinforced gland plate covers cable entry and exit cutouts on SmartRack® NEMA 3R and NEMA 4 industrial enclosures, including the SRN and SRIN series. The SRGP2KO is sized to correspond to the enclosures' cable cutouts, making it quick and easy to install. Three two-inch (50 mm) ports accept user-supplied cable fittings or conduit. LDPE escutcheons protect unused ports against dust and moisture to protect the enclosure's NEMA 3R or NEMA 4 rating.

## Specifications

OVERVIEW	
UPC Code	037332262899
Accessory Type	Gland Plate
Accessory Class	Rack Accessories
PHYSICAL	
Total Number of Ports	3
Shipping Dimensions (hwd / in.)	1.43 x 8.31 x 15.81
Shipping Dimensions (hwd / cm)	3.65 x 21.12 x 40.17
Shipping Weight (lbs.)	1.60
Shipping Weight (kg)	0.73
Unit Dimensions (hwd / in.)	0.300 x 13.386 x 5.906

### Highlights

- Rugged gasketed cable gland plate with metal reinforcement for long life
- Features 3 two-inch (50 mm) ports for installing cable fittings or conduit
- Screw mounting maintains NEMA rating of SmartRack industrial enclosure
- Polyethylene (LDPE) escutcheons protect unused ports against dust and moisture

### System Requirements

SmartRack NEMA 3R and NEMA 4 industrial enclosures

### Package Includes

- SRGP2KO Cable Entry Plate
- (6) M5 screws
- Owner's manual

# TRIPP-LITE

by **EATON**

1000 Eaton Boulevard  
Cleveland, OH 44122  
United States

Unit Dimensions (hwd / cm)	0.76 x 34 x 15
Unit Weight (lbs.)	1.00
Unit Weight (kg)	0.45
<b>FEATURES &amp; SPECIFICATIONS</b>	
IP68 Rated	No
Outdoor Use	Yes
IP20 Rated	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Product Compliance	REACH; RoHS
<b>WARRANTY &amp; SUPPORT</b>	
Product Warranty Period (Worldwide)	2-year limited warranty

# TRIPP-LITE

by **EATON**

© 2022 Eaton. All Rights Reserved.  
Eaton is a registered trademark. All other trademarks  
are the property of their respective owners.